


110 Grooves/mm, 25mm Sq, Transmission Grating Beamsplitter

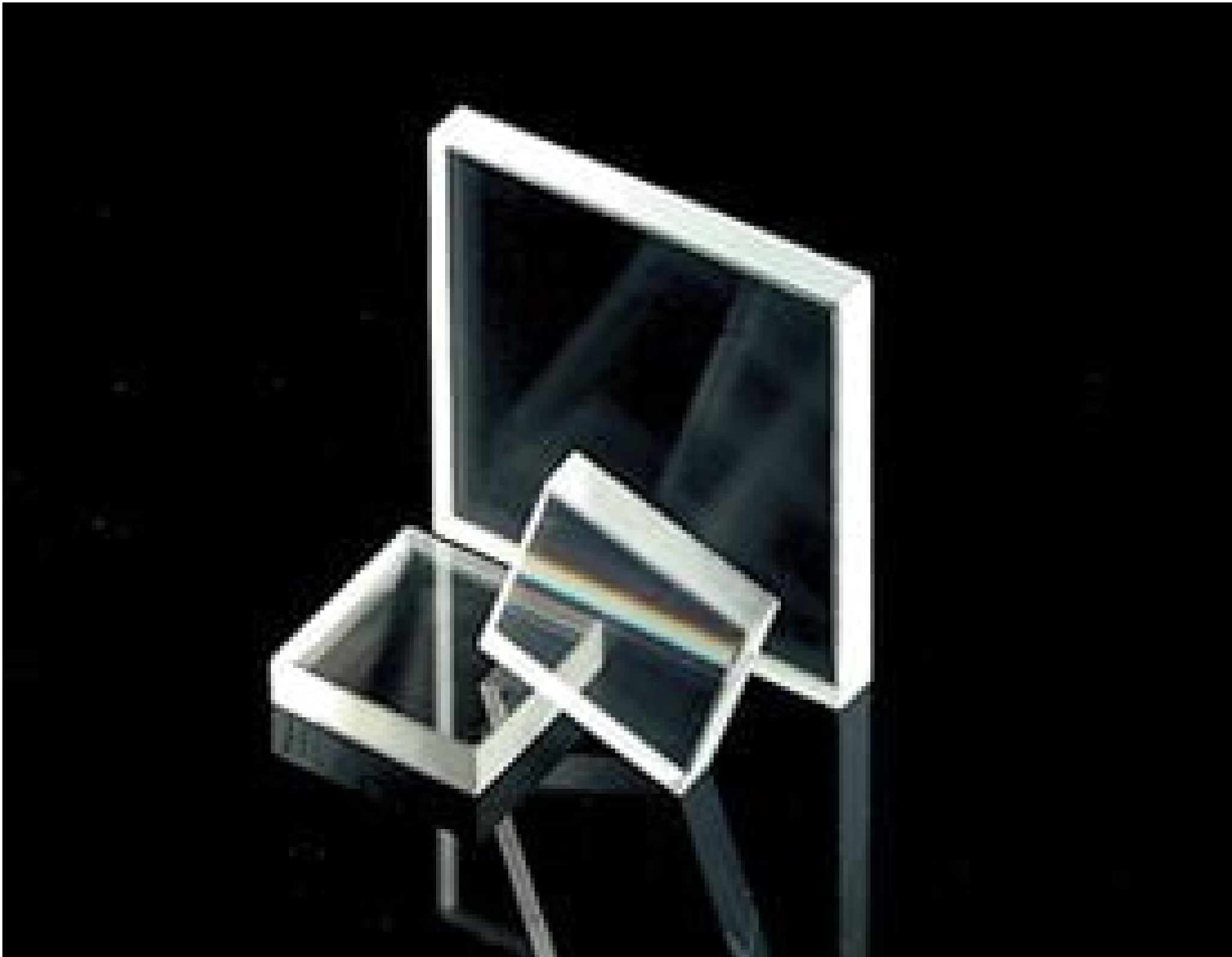

Stock #46-074 3-5 DAYS

- 1 +

A\$419.20

ADD TO CART

Qty 1-10
A\$419.20
Qty 11+
A\$377.60
Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
110

Design Wavelength DWL (nm):
632.8

Dimensions (mm):
25.0 x 25.0 ±0.5

Construction: Blazed Grating
Length (mm): 25.00
Substrate: ☐ B270
Thickness (mm): 3.00 ±0.5
Type: Transmission Diffraction Grating
Width (mm): 25.00

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View
