


TECHSPEC® 20mm Aperture, 300mm L Low NA, Hexagonal Light Pipe

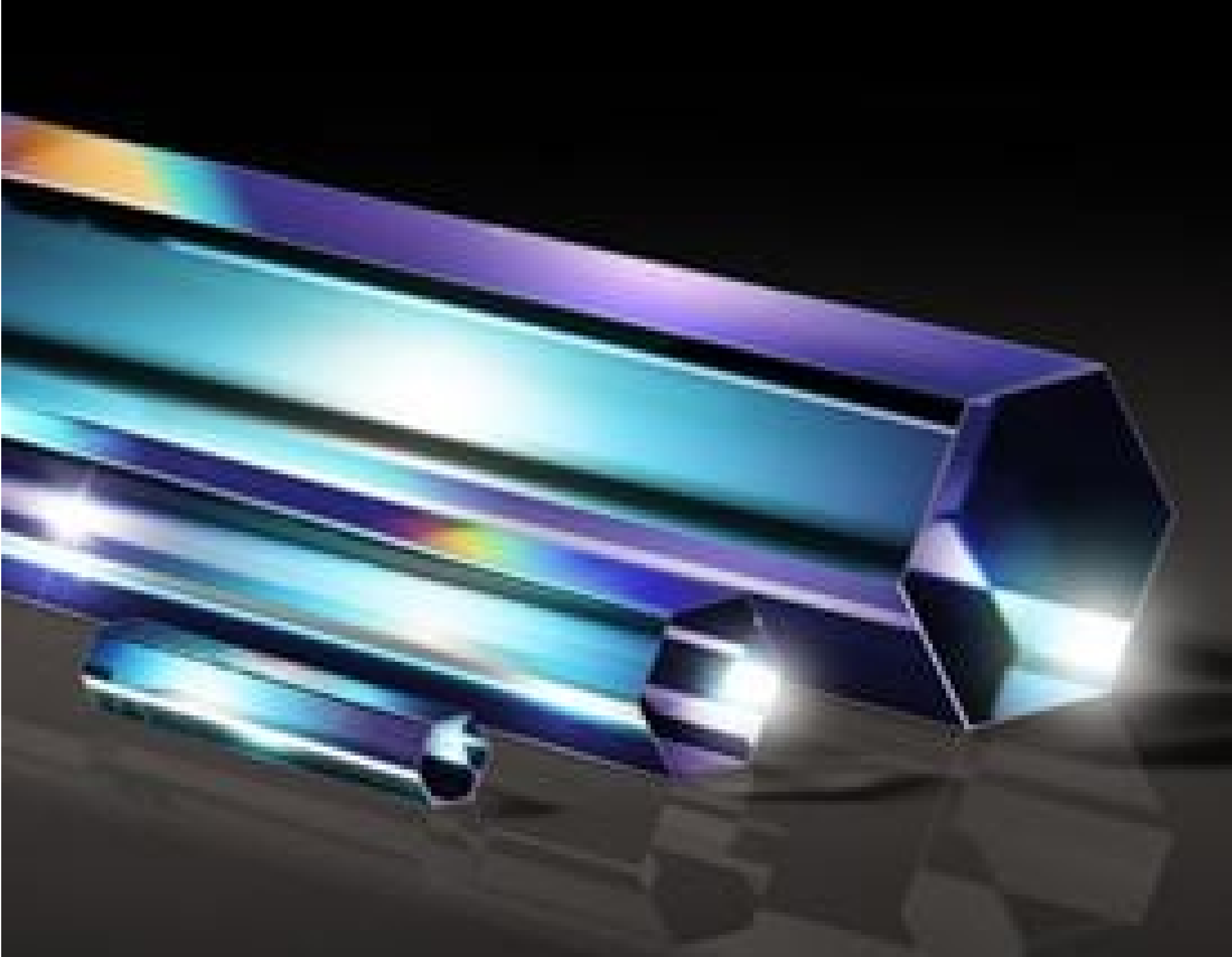

N-BK7 Light Pipe Homogenizing Rods



Stock **#84-537** 3-5 DAYS

- 1 +

A\$520.00

ADD TO CART

Qty 1-5
A\$520.00
Qty 6+
A\$416.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Uncoated

Substrate: N-BK7

Length (mm): 300.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 20.0
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 5λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View