
 


TECHSPEC®

2.5mm 2X, 100mm Length, Low NA Tapered Light Pipe

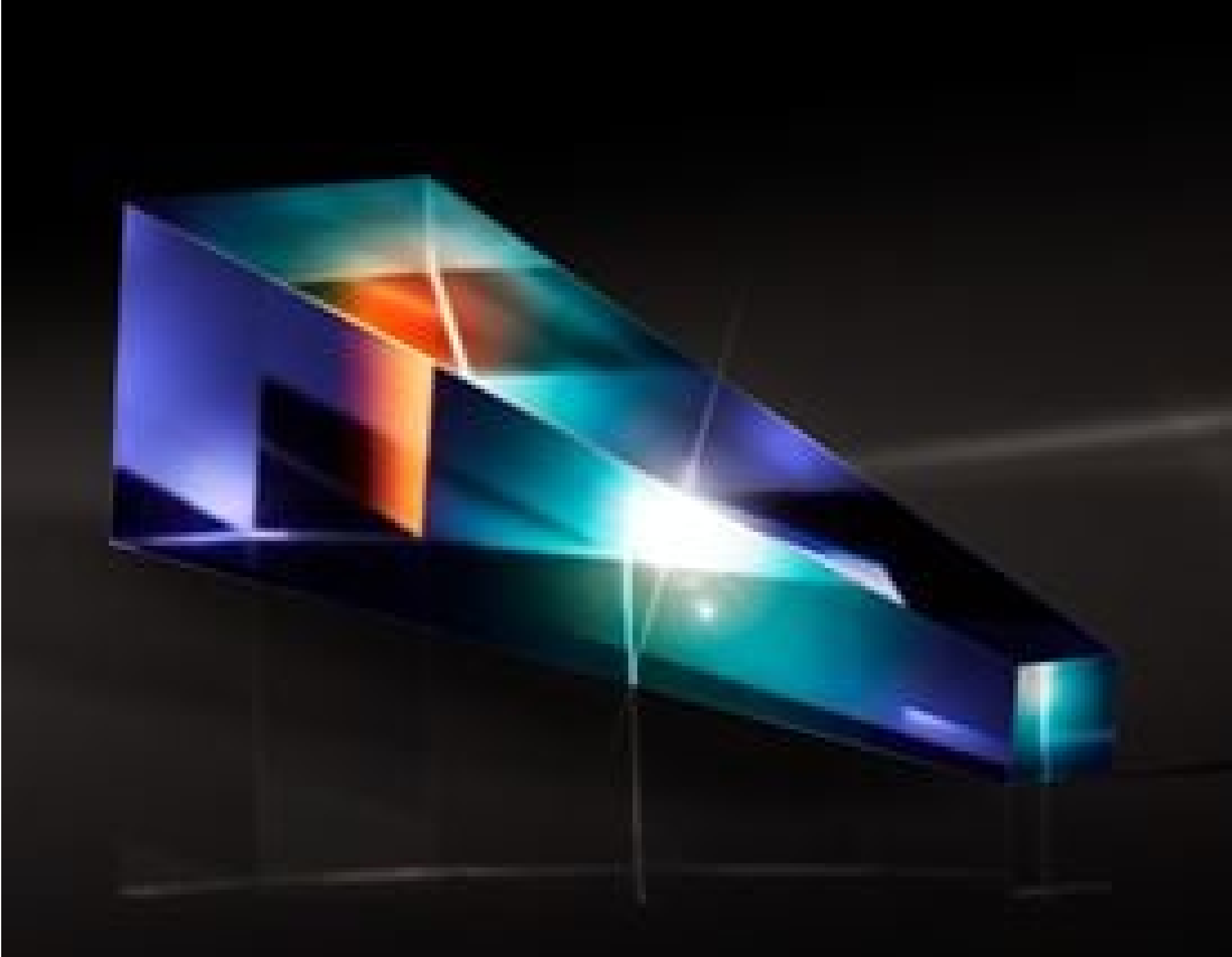

TECHSPEC® Tapered Light Pipe Homogenizing Rods



Stock **#65-840** 3-5 DAYS

- 1 +

A\$248.00

ADD TO CART

Qty 1-5

A\$248.00

Qty 6+

A\$198.40

Volume Pricing

[Request Quote](#)

Get Product Downloads



Coating:

Uncoated

Entrance Aperture (mm):

2.5 x 2.5

Exit Aperture (mm): 5 x 5
Substrate: ☐ N-BK7
Length (mm): 100.00
Magnification: 2X
Surface Quality: 60-40
Type: Light Pipe
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 1λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
