
 


TECHSPEC® 2.5mm 3X, 100mm Length, Low NA Tapered Light Pipe

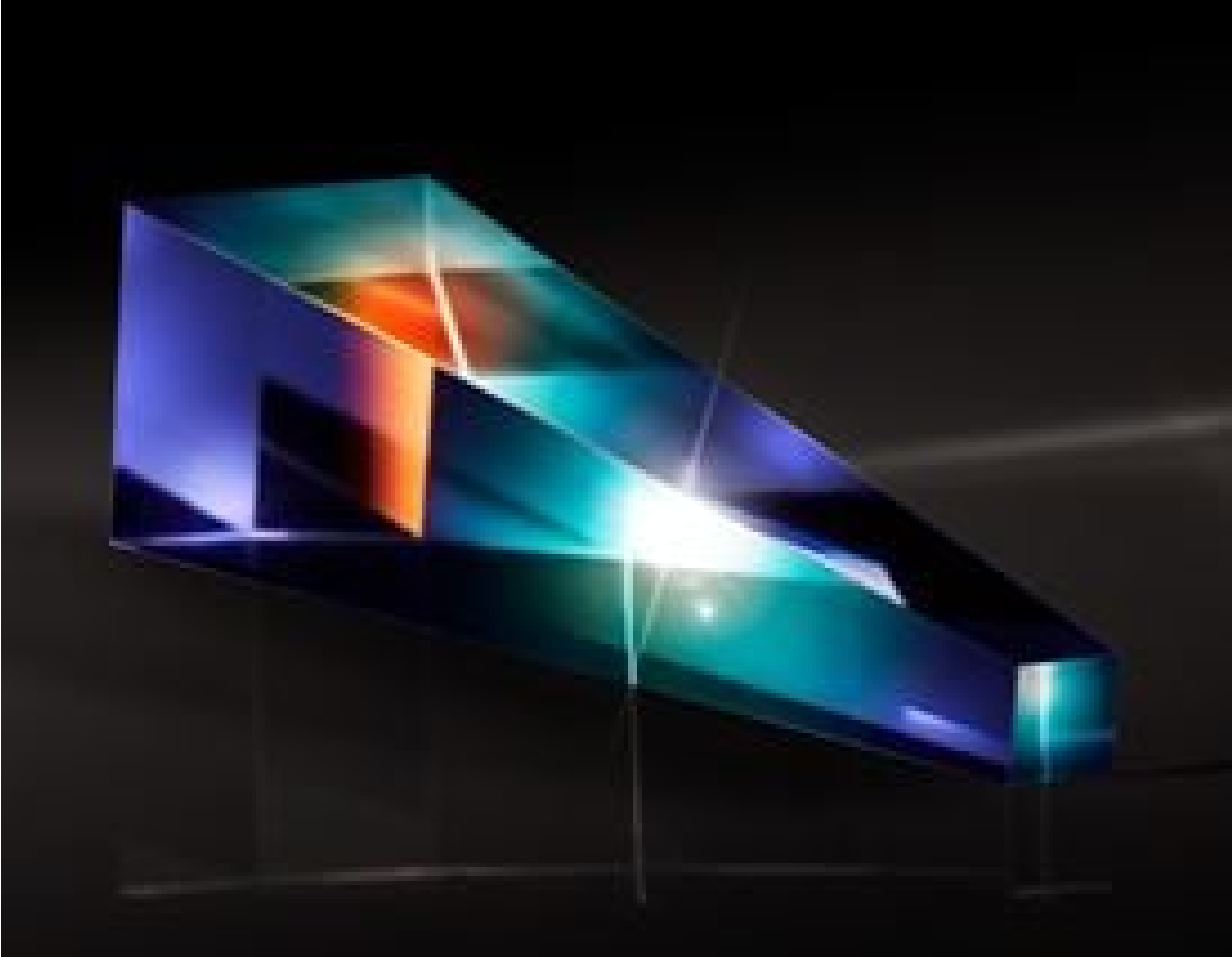

TECHSPEC® Tapered Light Pipe Homogenizing Rods



Stock **#65-841** 3-5 DAYS

- 1 +

A\$260.00

ADD TO CART

Qty 1-5
A\$260.00
Qty 6+
A\$208.00
Volume Pricing
Request Quote

Get Product Downloads



Coating:
Uncoated

Entrance Aperture (mm):
2.5 x 2.5

Exit Aperture (mm): 7.5 x 7.5
Substrate: ☐ N-BK7
Length (mm): 100.00
Magnification: 3X
Surface Quality: 60-40
Type: Light Pipe
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: Low
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 1λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View