


300 Grooves, 12.7mm Square, 1000nm NIR Ruled Grating

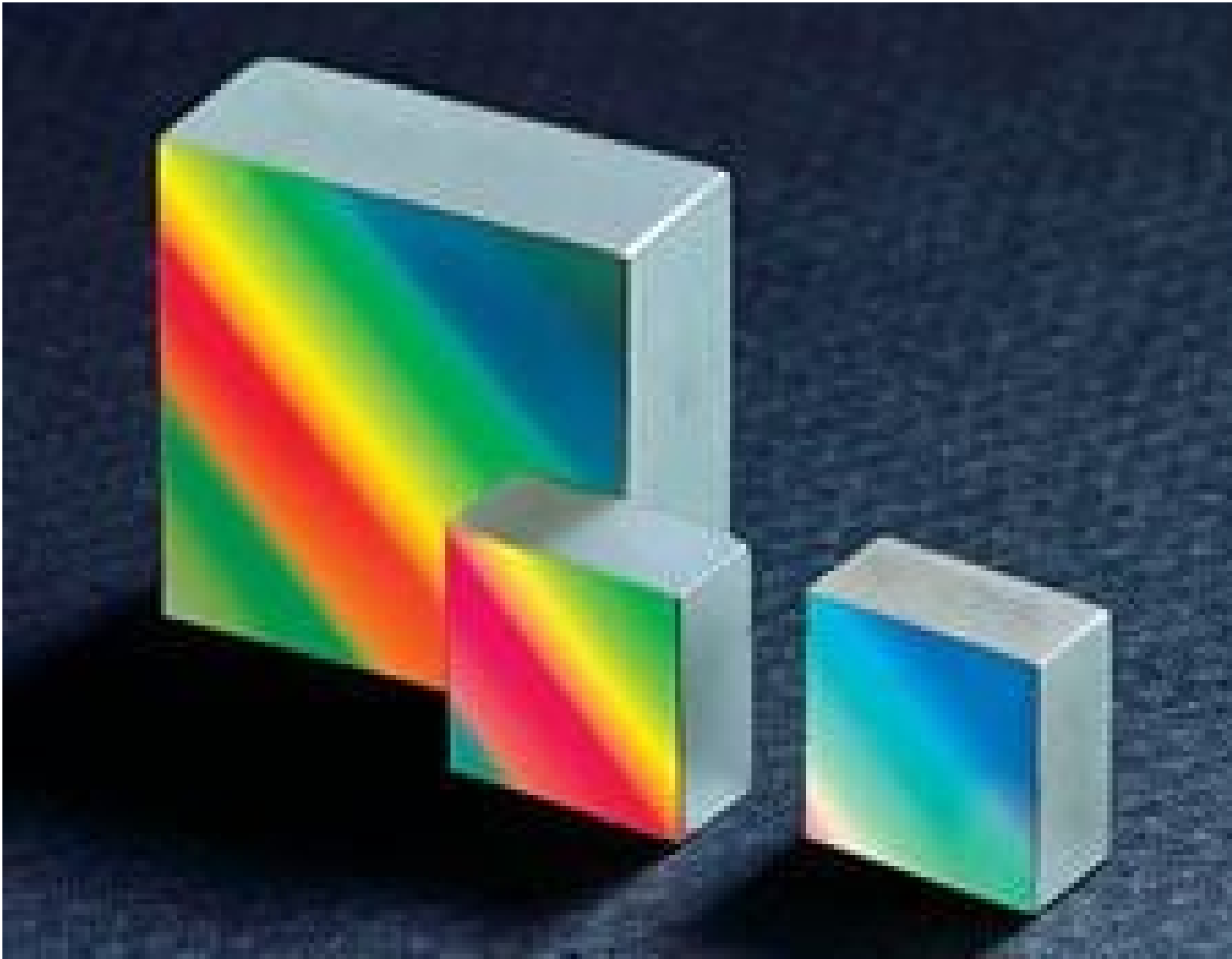

Stock **#49-569** [CONTACT US](#)

⊖ 1 ⊕ **A\$216.00**

ADD TO CART

Qty 1+
A\$216.00

Volume Pricing
Request Quote

Get Product Downloads



Groove Density (grooves/mm):
300

Wavelength Range (nm):
700 - 3000

Blaze Wavelength (nm):
1000

Blaze Angle (°):
8.60

Dimensions (mm):

12.7 x 12.7 ±0.5
Clear Aperture (%) : 90
Coating : Bare Gold
Construction : Ruled Grating
Direction of Grooves : Parallel to Short Dimension
Length (mm) : 12.70
Substrate :  Float Glass
Thickness (mm) : 6.00 ±0.5
Type : Reflective Diffraction Grating
Width (mm) : 12.70
Alignment of Grooves to Edge (°) : ±0.5

Regulatory Compliance

RoHS 2015 : Compliant
Reach 219 : Compliant
Certificate of Conformance : View