


TECHSPEC[®] 40mm Protected Gold Coated, N-BK7 Right Angle Mirror

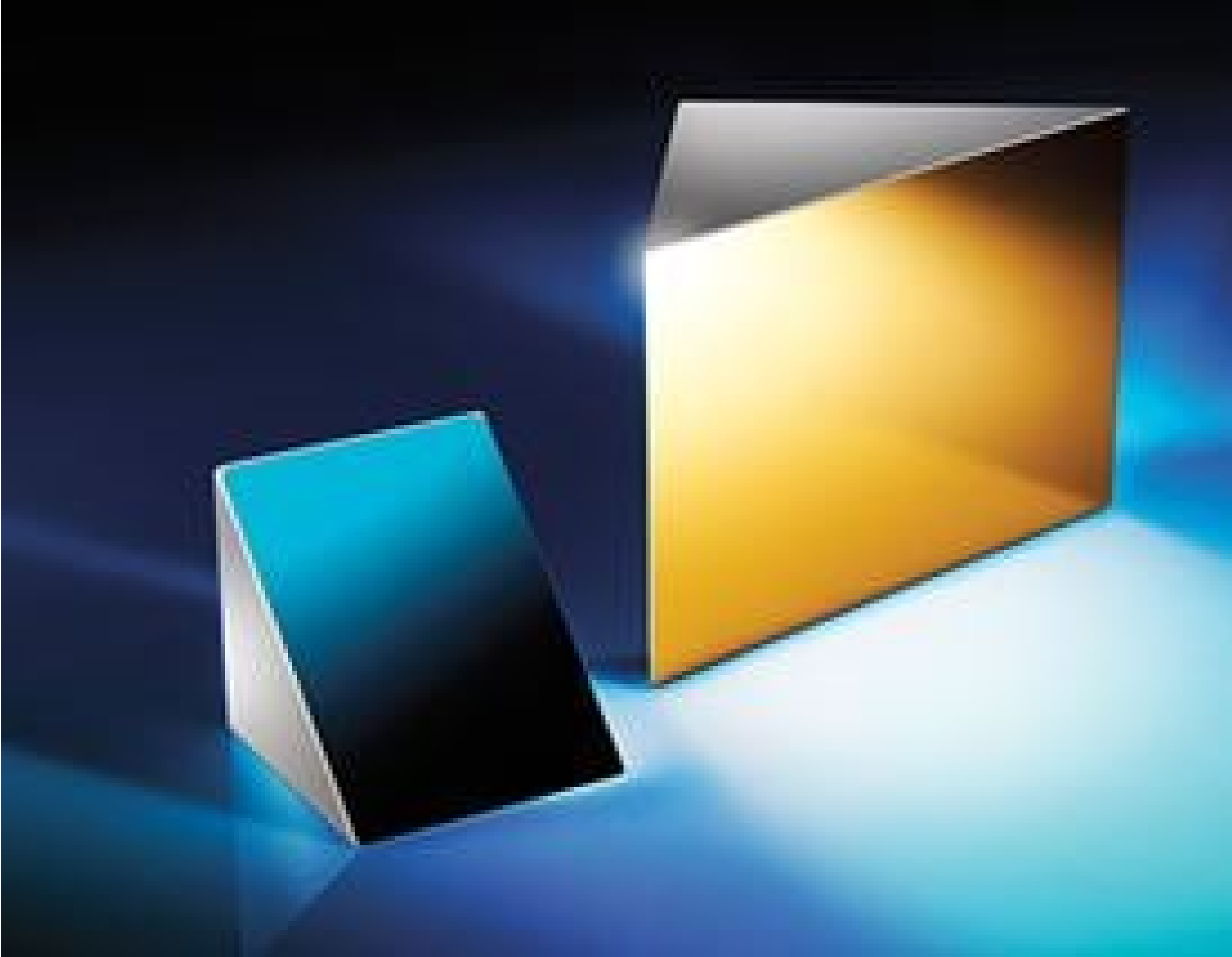

Stock #65-846 3-5 DAYS

-

1

+

A\$388.00

ADD TO CART

Qty 1-5
A\$388.00
Qty 6+
A\$310.40
Volume Pricing
Request Quote

Get Product Downloads



Substrate:

N-BK7

Surface Quality:
60-40

Length of Legs (mm):
40.00

Dimensional Tolerance (mm):

±0.1
Coating Specification: R _{avg} >96% @ 700 - 2000nm R _{avg} >96% @ 2000 - 10,000nm
Coating: Protected Gold (700-10000nm)
Coating Type: Metal
Angle Tolerance (arcmin): ±2
Bevel: Protective bevel as needed
Clear Aperture CA (mm): 50.91 x36.00
Length of Hypotenuse (mm): 56.60
Type: Right Angle Mirror
Wavelength Range (µm): 0.7 - 10
Wavelength Range (nm): 700 - 10000
Damage Threshold, Reference:  0.8 J/cm² @ 1064nm, 10ns
Power (fringes) @ 632.8nm: 1.25
Irregularity (fringes) @ 632.8nm: 0.50

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant