


TECHSPEC[®] 50mm Square 45°, Magenta Dichroic Filter

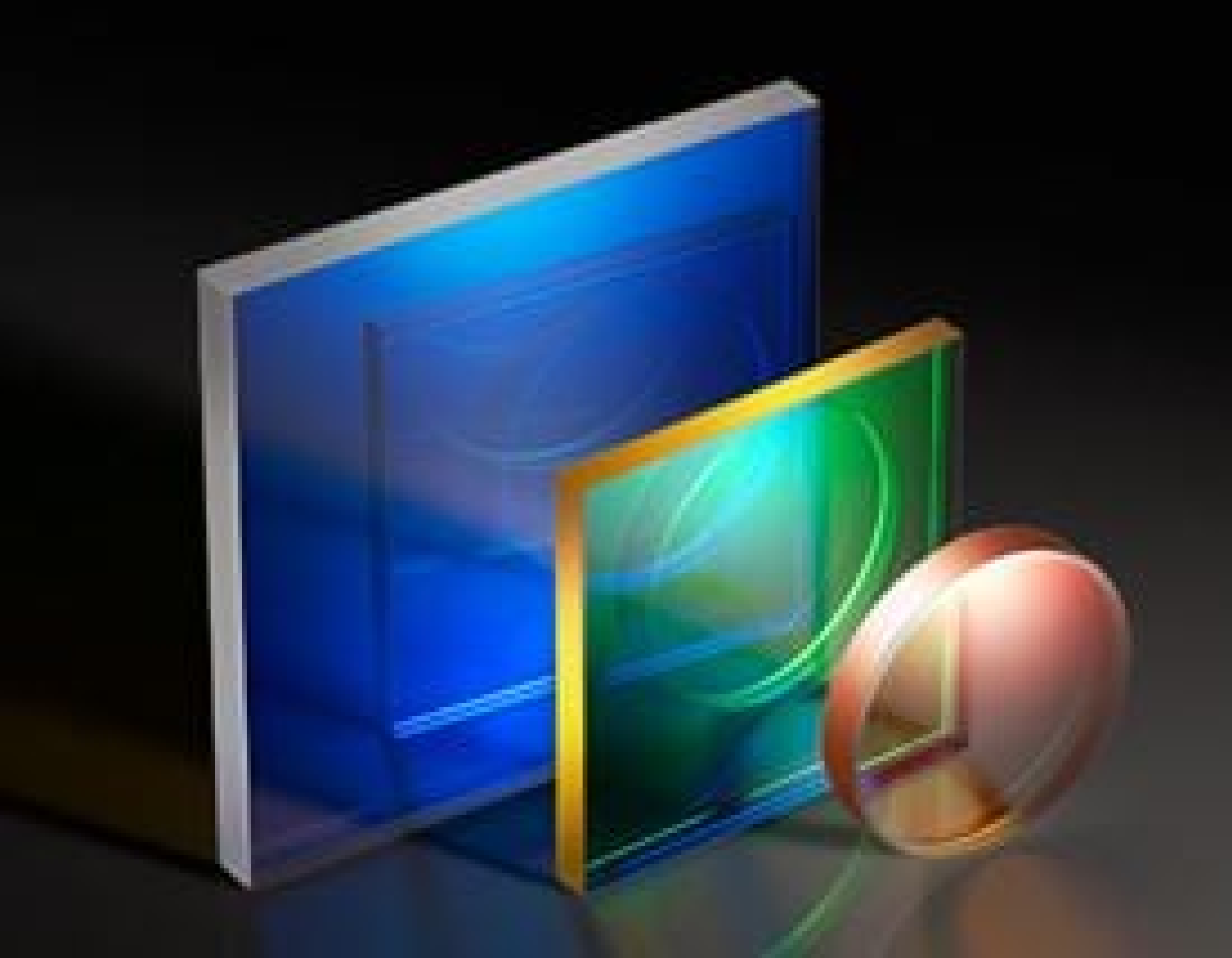

Stock #66-253 3-5 DAYS

-

1

+

A\$220.80

ADD TO CART

Qty 1-10

A\$220.80

Qty 11+

A\$187.68

Volume Pricing

[Request Quote](#)

Get Product Downloads



Dimensions (mm):
50.0 x 50.0

Angle of Incidence (°):
45.00

Cut-Off Wavelength (nm):
495.00

Cut-On Wavelength (nm):

605.00
Substrate: N-BK7
Length (mm): 50.00
Coating: Traditional Coated
Color: Magenta
Reflection (%): R _{abs} = 50% @ 495 & 605nm R _{avg} > 98% @ 400 - 465nm & 635 - 725nm
Reflection Wavelength (nm): 400 - 465 & 635 - 725
Surface Quality: 60-40
Thickness (mm): 4.00
Thickness Tolerance (mm): ±0.20
Transmission (%): 90.00
Transmission Wavelength (nm): 520 - 580
Type: Dichroic Filter
Width (mm): 50.00
Wavelength Tolerance (nm): ±15
Parallelism (arcmin): <1
Dimensional Tolerance (mm): ±0.25
Clear Aperture (%): 90.00
Coating Specification: Surface 1: Multi-Layer Dichroic Surface 2: Single Layer MgF ₂
Wavelength Range (nm): 400 - 725
Surface Flatness (P-V): λ/4

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant