


880nm w/ Barrel Mount, Brightfield/Darkfield LED Ring Light w/ Barrel Mount

See More by [Advanced Illumination](#)

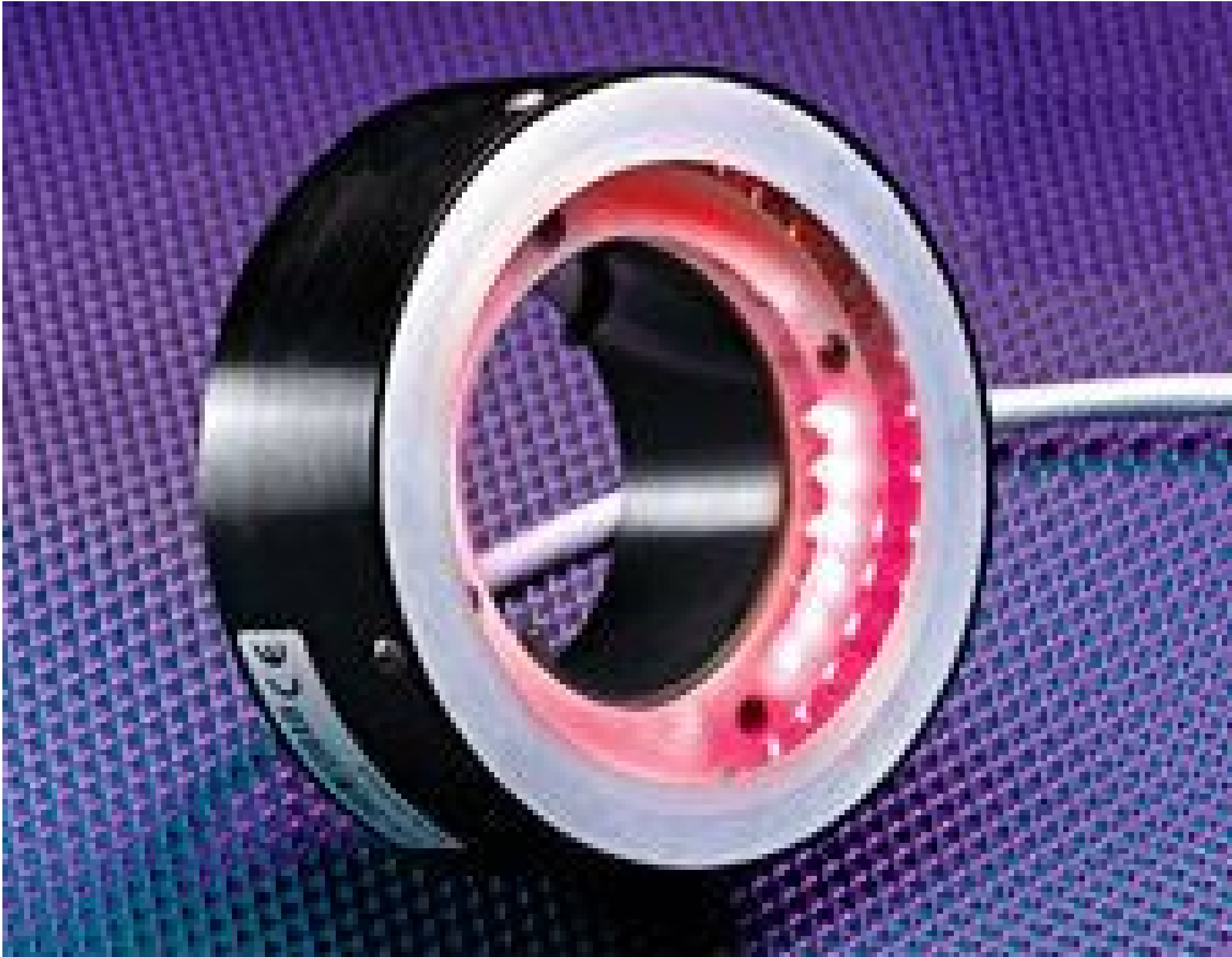

Stock **#66-789** [CONTACT US](#)

⊖ 1 ⊕ **A\$2,153.60**

ADD TO CART

Qty 1+

A\$2,153.60

Volume Pricing

[Request Quote](#)

Note: This item requires accessories for use | [Learn More](#)

Get Product Downloads

Color:
Infrared

Diameter (mm):
100.00

Height (mm):
33.7

Inner Diameter (mm):
55.5

Model Number: RL5064B-880-IC
Mount: Barrel Mount
Operating Temperature (°C): 0-65
Outer Diameter (mm): 100.00
Mounting Threads: M4 x4
Wavelength (nm): 880.00
Working Distance (mm): 6 - 64
LED Lifetime (hours): 50,000
Power Supply: Power Supply Required and Sold Separately. USA: #66-855 Europe: #66-855 Japan: #66-855 Korea: #33-773 China: #66-855
Number of LEDs: 64.00
Maximum Trigger Frequency (Hz): 30.00
Type of Illumination: LED Illuminator
Note: Optional Manual Intensity Adjustment #86-887 and #89-555 are Available
Manufacturer: Advanced Illumination
Geometry: Ring Light
Illumination Mode: Constant

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Contains SVHC(s)