


Green Fluorescent Filter (G9), 25mm Diameter

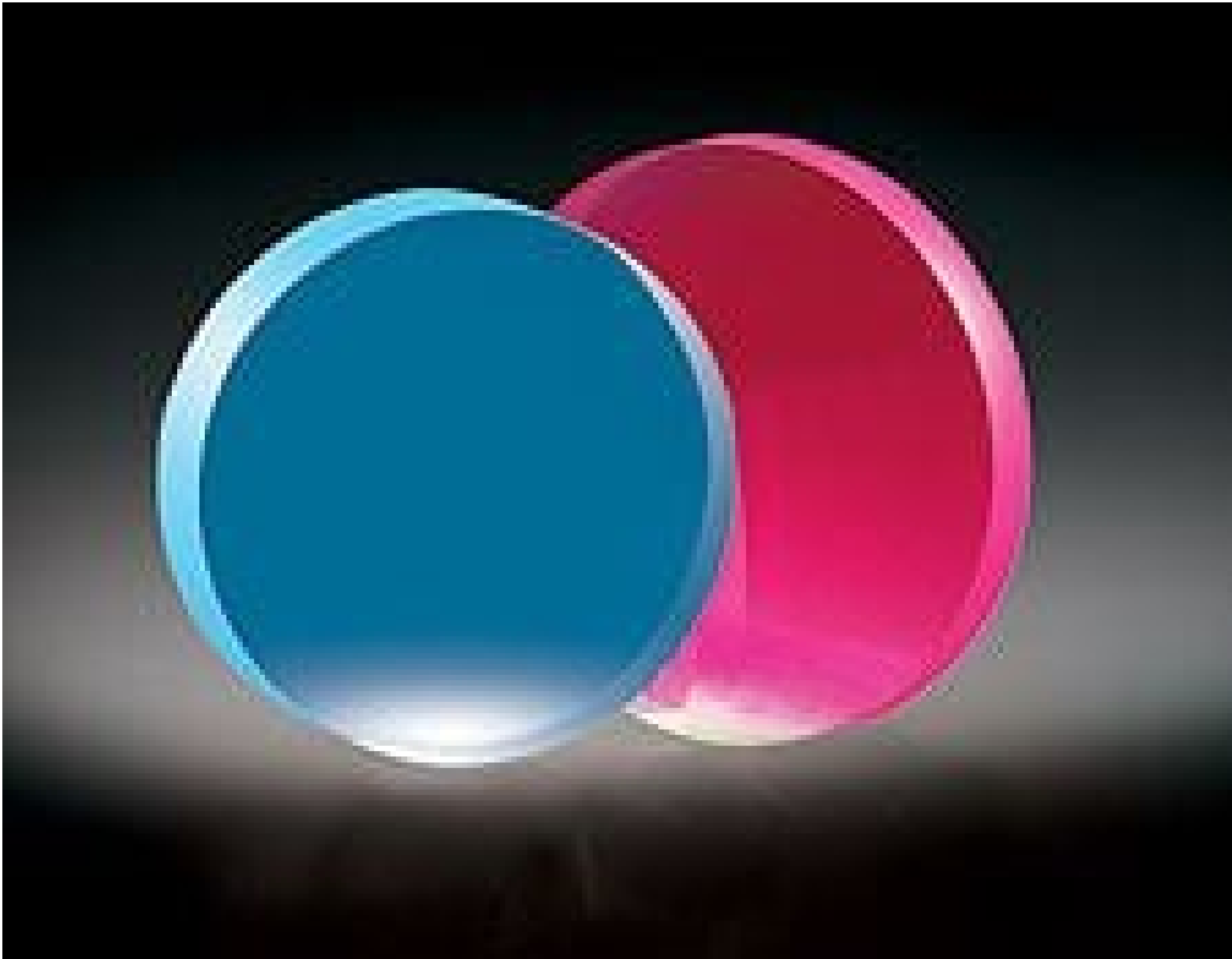

Stock #66-300 3-5 DAYS

-

1

+

A\$441.60

ADD TO CART

Qty 1-9
A\$441.60
Qty 10+
A\$390.40
Volume Pricing
Request Quote

Get Product Downloads

Diameter (mm):
25.00 ±0.10

Glass/Filter Number:
G9

Substrate: ☐
Lumilass

Coating: Uncoated
Color: Green
Index of Refraction n_d: 1.694
Transformation Temperature (°C): 660.00
Thickness (mm): 3.00 ±0.10
Type: Color Filter
Peak Emission Wavelength (nm): 540.00
Excitation Wavelength (nm): 200 - 390
Peak Excitation Wavelength (nm): 365.00
Minimum Sensitivity: ~1μW/cm²

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant