


0.7 OD 12.5mm Dia, Absorptive ND Filter

See More by [Hoya](#)

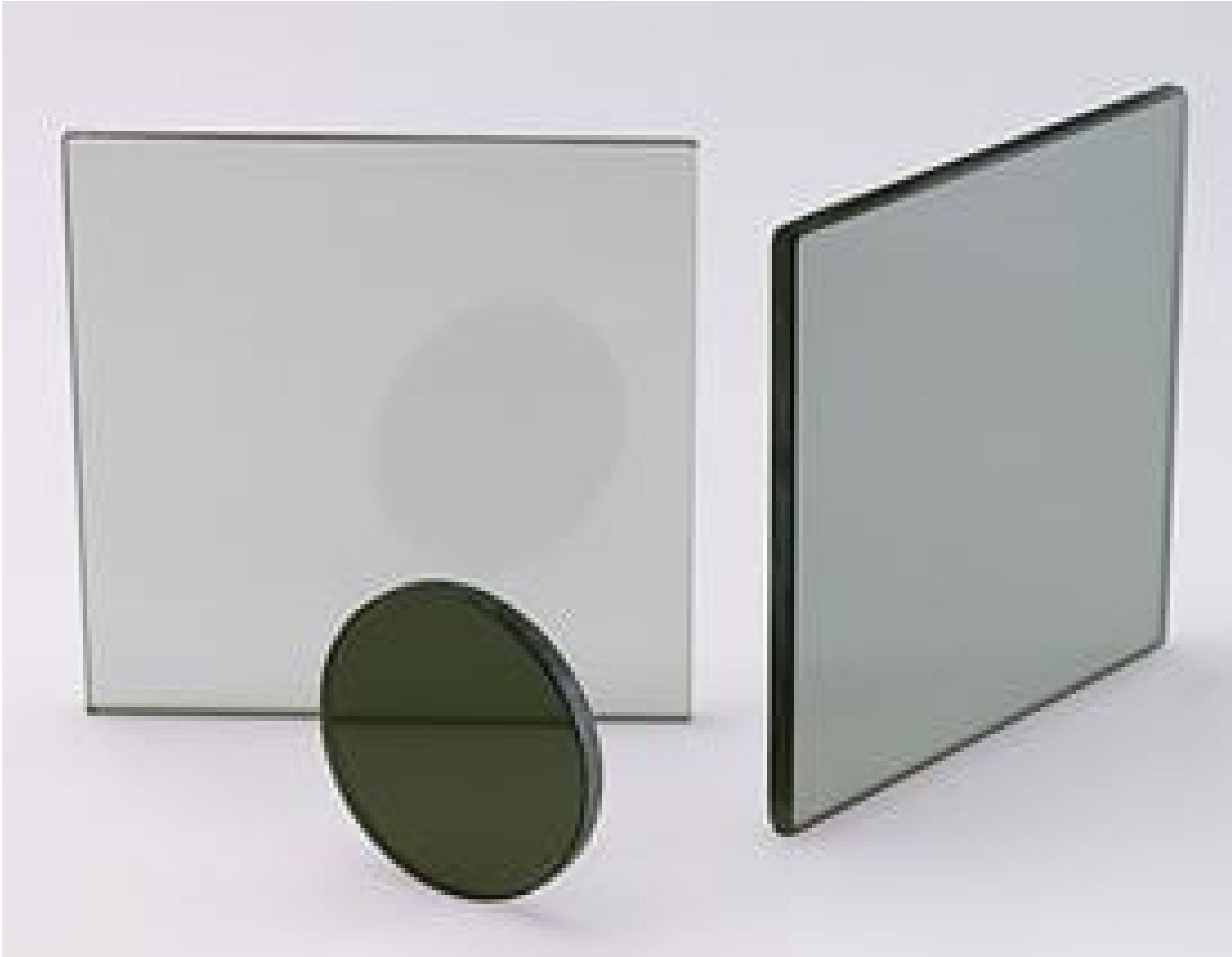

Stock **#63-458** 3-5 DAYS

- 1 +

A\$49.60

ADD TO CART

Qty 1-10
A\$49.60
Qty 11+
A\$44.80
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
12.50

Optical Density OD (Average):
0.7 ±0.05

Glass/Filter Number: Hoya ND-25
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.51
Surface Quality: 80-50
Transformation Temperature (°C): 535
Thickness (mm): 3.10
Thickness Tolerance (mm): ±0.5
Transmission (%): 20.0 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
REACH 201: Compliant
Certificate of Conformance: View