

# 100 x 100mm 600 Grit Ground Glass Diffuser



Stock **#38-791** **8 In Stock**

-

1

+

A\$86<sup>.40</sup>

ADD TO CART

| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-10       | <b>A\$86.40</b> each          |
| Qty 11+        | <b>A\$79.60</b> each          |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

| General                          |                             |
|----------------------------------|-----------------------------|
| Ground Glass Diffuser            | Type:                       |
| Sandblasted on first surface     | Note:                       |
| Physical & Mechanical Properties |                             |
| ±0.76                            | Dimensional Tolerance (mm): |
| 100.00 x 100.00                  | Dimensions (mm):            |

|        |                                |
|--------|--------------------------------|
| Seamed | Edges:                         |
| 600    | Grit: <input type="checkbox"/> |

|        |                 |
|--------|-----------------|
| 1.60   | Thickness (mm): |
| 100.00 | Width (mm):     |

|        |              |
|--------|--------------|
| 100.00 | Length (mm): |
|--------|--------------|

Optical Properties

|             |                                     |
|-------------|-------------------------------------|
| Uncoated    | Coating:                            |
| Float Glass | Substrate: <input type="checkbox"/> |

|            |                        |
|------------|------------------------|
| 350 - 2000 | Wavelength Range (nm): |
|------------|------------------------|

Regulatory Compliance

|           |                             |
|-----------|-----------------------------|
| Compliant | RoHS 2015:                  |
| View      | Certificate of Conformance: |

|           |            |
|-----------|------------|
| Compliant | Reach 247: |
|-----------|------------|

Product Details

• Available in Sizes Ranging from 5mm Diameter to 250mm Square

• Low Scatter Loss


• Evenly Ground Surface for Even Diffusion

• [Fused Silica Substrates](#) Available

Ground Glass Diffusers are comprised of high tolerance, quality ground glass making them ideal for a variety of industrial applications. The float glass substrate has excellent visible transmission and is ideal for general diffusing applications. A 120-grit, 220-grit or 600-grit (as noted) sandblast is used to create a diffuse surface on the glass. Ground Glass Diffusers have even diffusion across the entire surface from undergoing two orthogonal passes during this sandblast process. The scattering is a compromise of low scatter loss and medium diffusion. Typical applications include use in screens, illuminator diffusion, and targets.

Can't find what you need? Get a quick [custom quote](#).

Technical Information

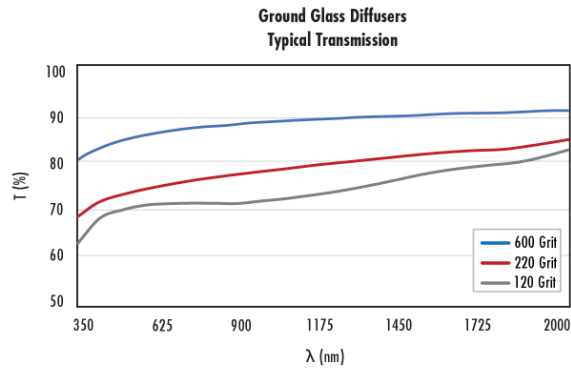

Quote Your Size

Compatible Mounts