


1064nm, 20mm Dia., Square Output, High Homogeneity Diffractive Diffuser

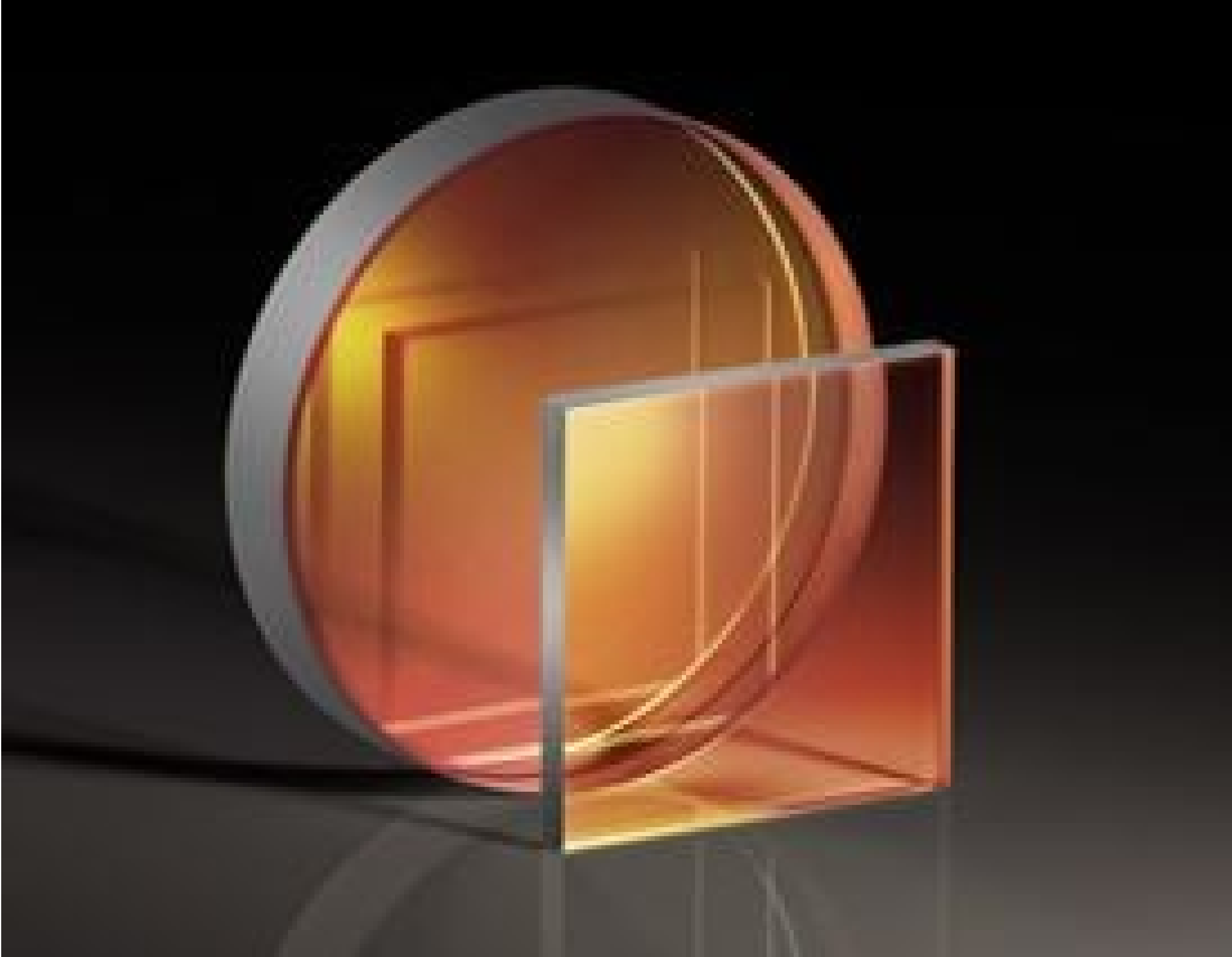

HOLO/OR Diffractive Diffusers

Stock #14-681 3-5 DAYS

-

1

+

A\$3,008.00

ADD TO CART

Qty 1+
A\$3,008.00
Volume Pricing
Request Quote

Get Product Downloads



Clear Aperture CA (mm):
18.00

Coating:
Laser V-Coat (1064nm)

Design Wavelength DWL (nm):
1064

Diameter (mm):
20.00 +0.05/-0.1

Substrate:

Fused Silica (Coming 7980)	
Thickness (mm):	3.00 ±0.1
Note:	High Homogeneity
Input Beam Mode:	SMor MM
Minimum Beam Diameter (mm):	5
Output Shape:	Square
Overall Efficiency (%):	72
Full Angle (°) :	2.75 x2.75
Damage Threshold, Reference: ☐ See Link for More Details	

Regulatory Compliance

RoHS 2015:	Compliant
Certificate of Conformance:	View
Reach 233:	Compliant