


10mm Dia., 1.5mm Thick, Calcium Fluoride (CaF₂) Diffuser

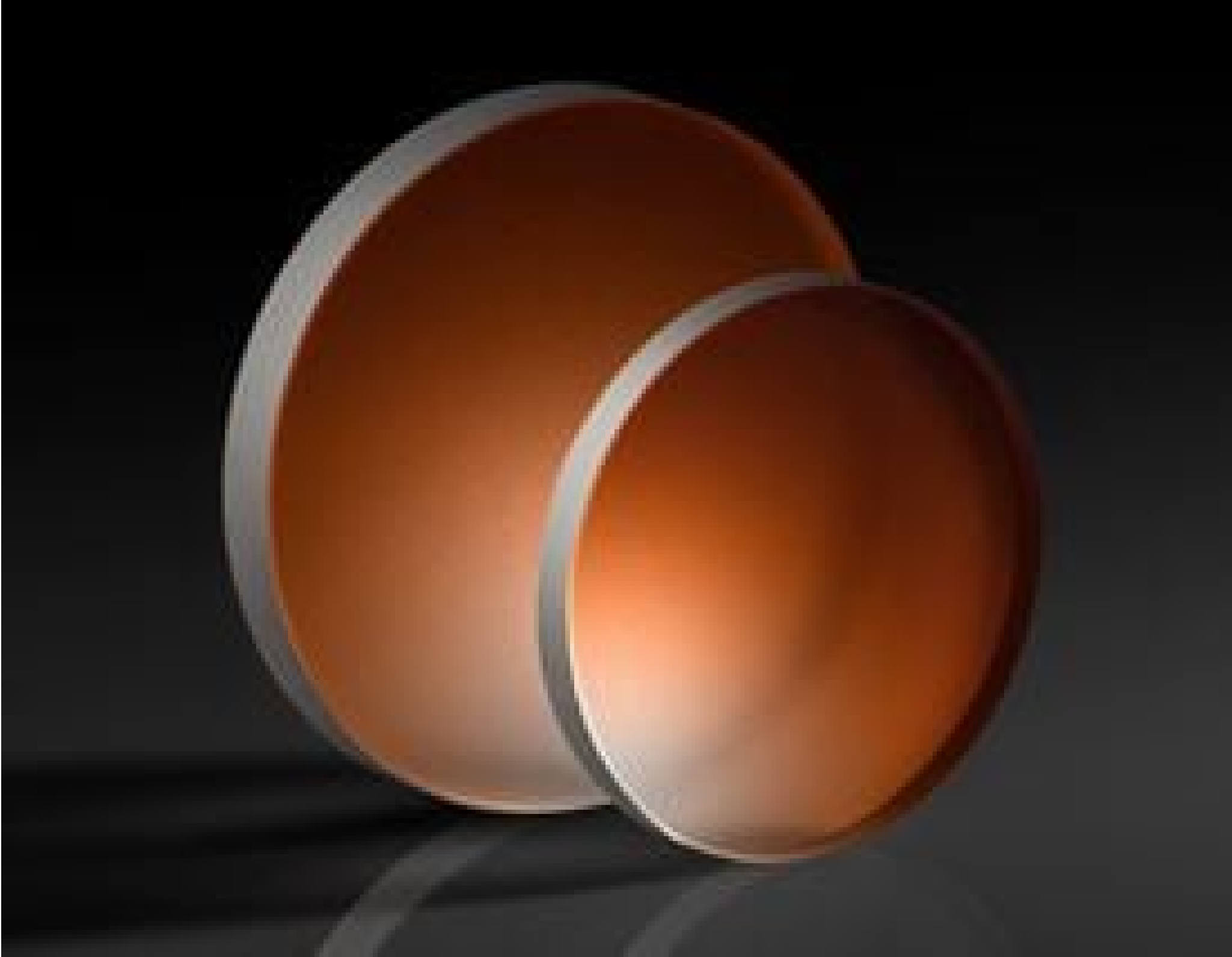

IR Calcium Fluoride (CaF₂) Diffusers

Stock #19-731 3-5 DAYS

-

1

+

A\$200.00

ADD TO CART

Qty 1-10

A\$200.00

Qty 11+

A\$180.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
10.00 +0.00/-0.10

Coating:
Uncoated

Edges:
Fine Grind

Substrate: ☐
Calcium Fluoride (CaF₂)

Thickness (mm):
1.50 ±0.10

Type:
IR Diffuser

Wavelength Range (nm):
300 - 7000

Note:
Fine Grind first surface with a roughness (Ra) of
☐0.75 microns

Regulatory Compliance

RoHS 2015:
[Compliant](#)

Certificate of Conformance:
[View](#)