


TECHSPEC® 10mm Dia. X 10mm FL Uncoated, Double Sided Aspheric Lens

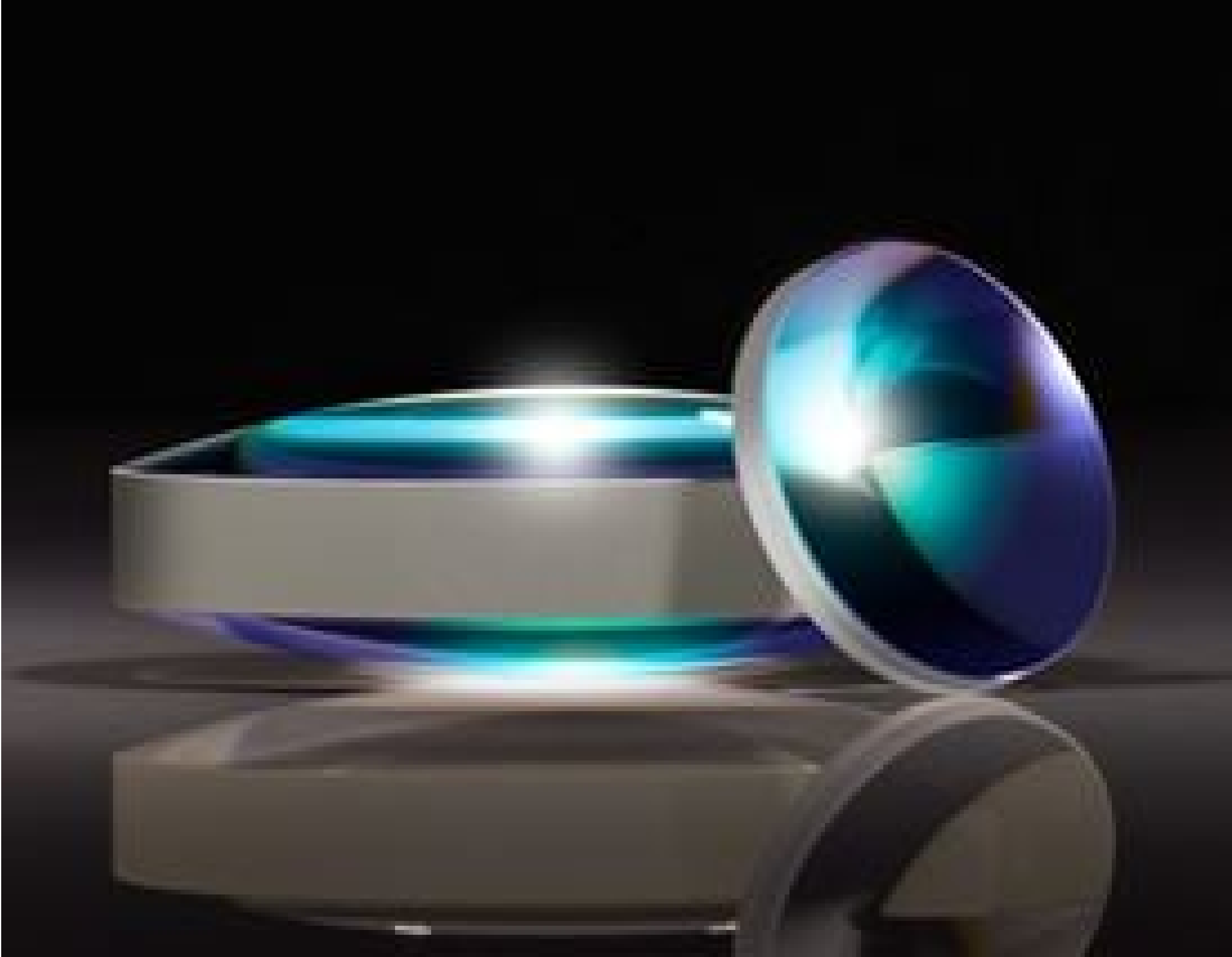

Stock #18-414 3-5 DAYS

- 1 + **A\$448.00**

ADD TO CART

Qty 1-5
A\$448.00
Qty 6+
A\$358.40
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
10.00 +0.0/-0.025

Effective Focal Length EFL (mm):
10.00

Back Focal Length BFL (mm):
7.06

Substrate:

[N-BK7](#)

Aspheric Design Wavelength (nm):
587.6

Asphere Figure Error, RMS @ 632.8nm:
0.4λ RMS and 2λ PV

Coating:
Uncoated

Centering (arcmin):
3

Surface Quality:
40-20

Clear Aperture CA (mm):
9

Edge Thickness ET (mm):
5

Center Thickness CT (mm):
7.60 ±0.1

f#:
1.00

Bevel:
None

Type:
Aspheric Lens

Wavelength Range (nm):
330 - 2400

Radius R₁=R₂ (mm):
8.818

Power (diopters):
100.00

Regulatory Compliance

RoHS:
[Compliant](#)

Certificate of Conformance:
[View](#)