


# 10X Loupe w/ 5 Scales Set



Linear Scale

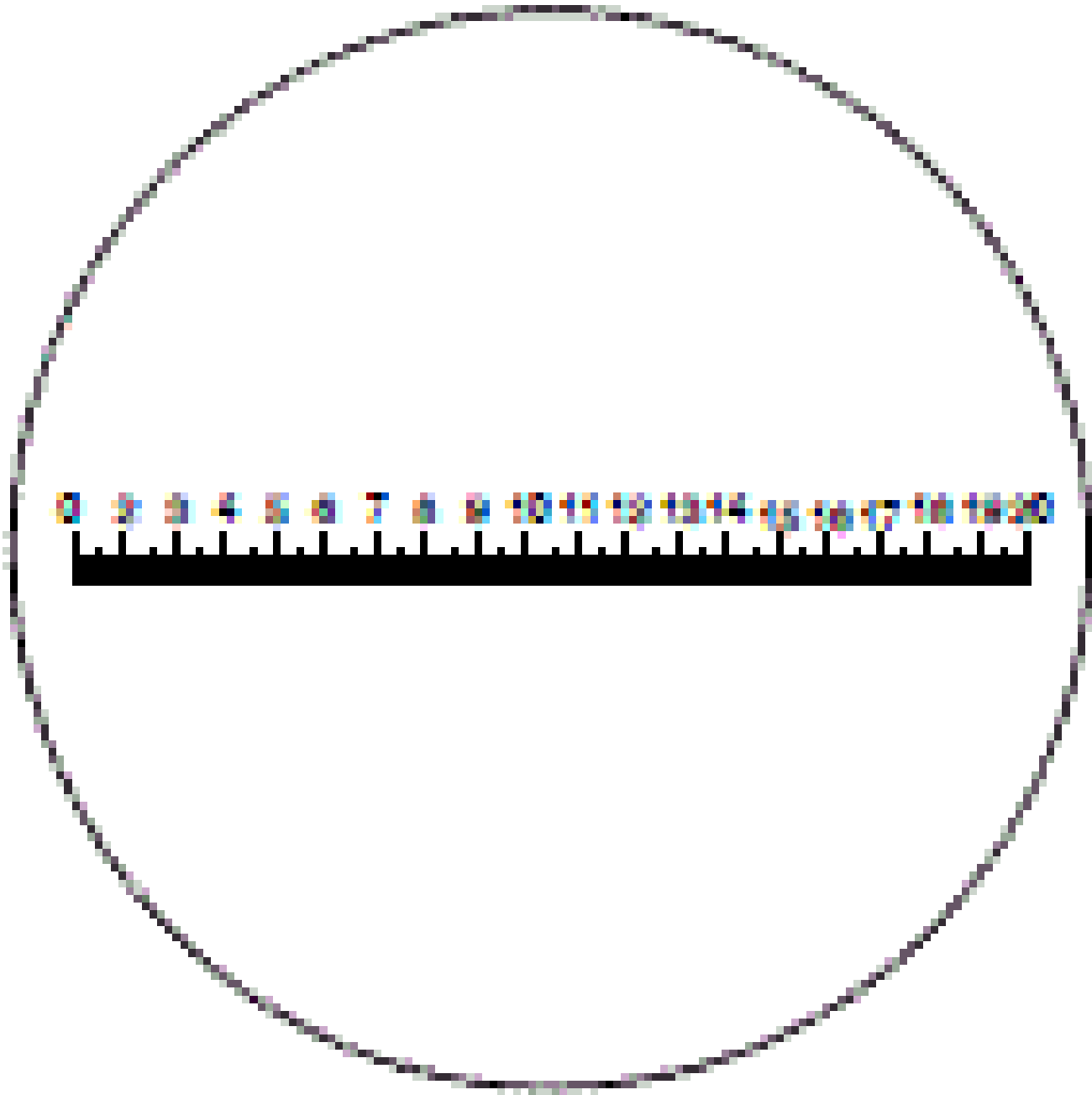

Stock **#39-098** **3 In Stock**

⊖ 1 ⊕ **A\$371<sup>20</sup>**

**ADD TO CART**

### Volume Pricing

Qty 1-4	<b>A\$371.20</b> each
Qty 5-9	<b>A\$324.48</b> each
Qty 10+	<b>A\$285.44</b> each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

### Physical & Mechanical Properties

Field of View (inches):  
1.00

Diameter of Included Lens (inches):  
0.75

Diameter of Compatible Reticle (mm):  
35.00

1.75 **Height (inches):**

## Optical Properties

10X **Magnification:**

0.65 **Working Distance (inches):**

## Regulatory Compliance

[View](#) **Certificate of Conformance:**

## Product Details

### Loupe with 5 Scales Set

Each set comes with 5 individual reticle scales (26mm diameter for 7X, 35mm diameter for 10X) in a hard-shell vinyl storage case. The 7X or 10X focusing magnifier is a multi-element design with a removable clear acrylic base. Set includes [Linear Scale](#), [Multi-Scale](#), [Counting Grid](#), [Thickness Scale](#), and [Thread Size](#) reticles.

- 7X and 10X Magnifications Available
- Choose from Loupe, Illuminated Loupe and Loupe Sets
- Reticle Included with Each Option

Peak 7X or 10X Measuring Loupes come with a removable glass reticle scale placed in direct contact with the work to be measured for precise comparison. Additional [reticles](#) are also available. All models feature smooth-helicoid twist focus and fully coated achromatic lens systems for color correct flat field viewing. Peak 7X or 10X Measuring Loupes are offered in with a singular loupe, an illuminated loupe, and loupe sets. The included lens features a 0.75" diameter.