


TECHSPEC[®] 12.5mm Aperture, 75mm L High NA, Hexagonal Light Pipe

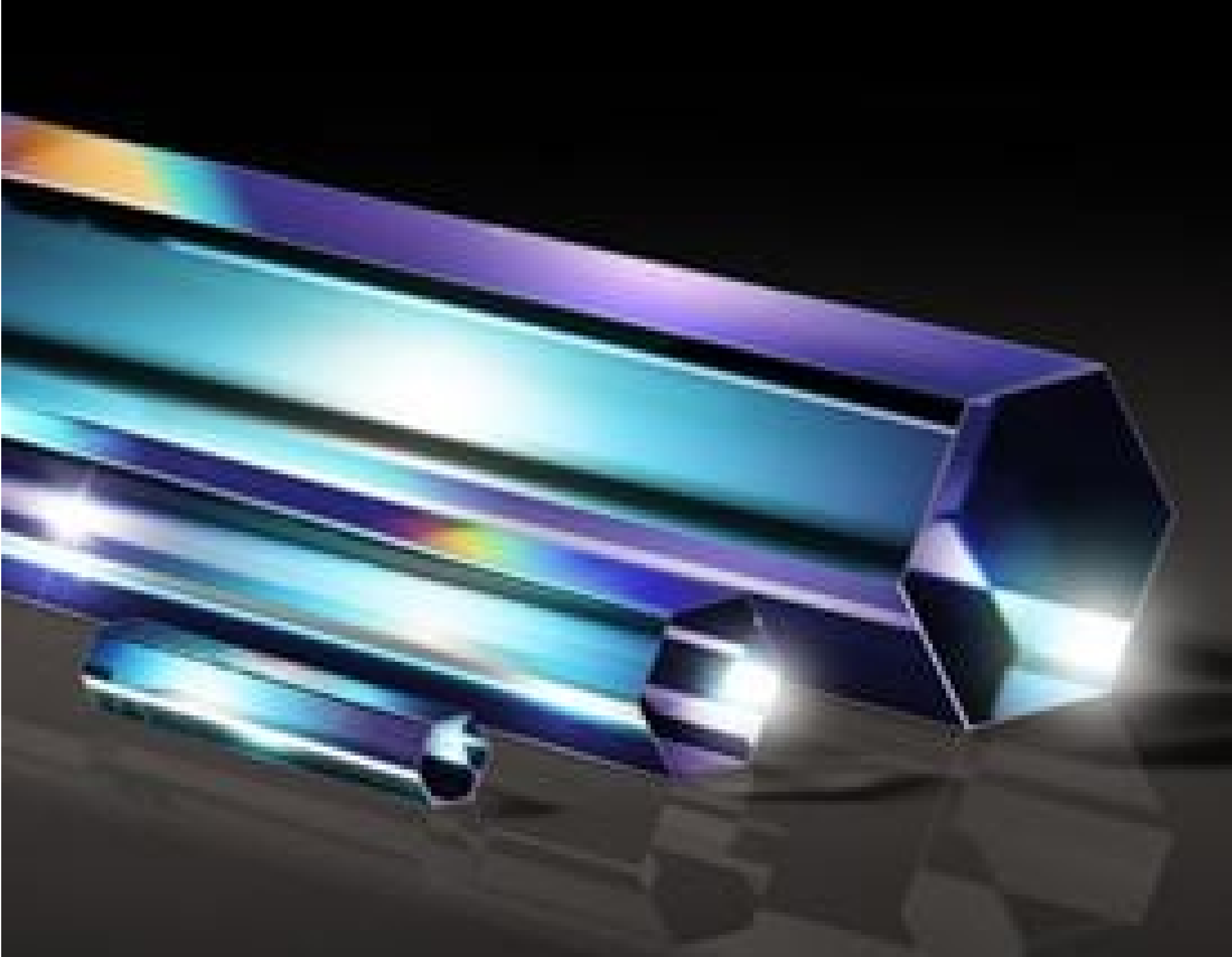

N-BK7 Light Pipe Homogenizing Rods



Stock **#84-529** [CONTACT US](#)

-

1

+

A\$244.00

ADD TO CART

Qty 1-5

A\$244.00

Qty 6+

A\$195.20

Volume Pricing

[Request Quote](#)

Get Product Downloads



Coating:

Uncoated

Substrate: ☐

[N-BK7](#)

Length (mm): 75.00
Surface Quality: 60-40
Type: Light Pipe
Entrance and Exit Aperture (mm): 12.5
Parallelism (arcmin): 5.00
Length Tolerance (mm): ±0.3
Aperture Tolerance (mm): ±0.10
Image Orientation: Light Homogenization
Light Source NA: High
Wavelength Range (nm): 350 - 2200
Surface Flatness (P-V): 3λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 211: Compliant
Certificate of Conformance: View