


TECHSPEC® 125mm, Center Drive, Thru-Hole, Metric Micrometer Stage

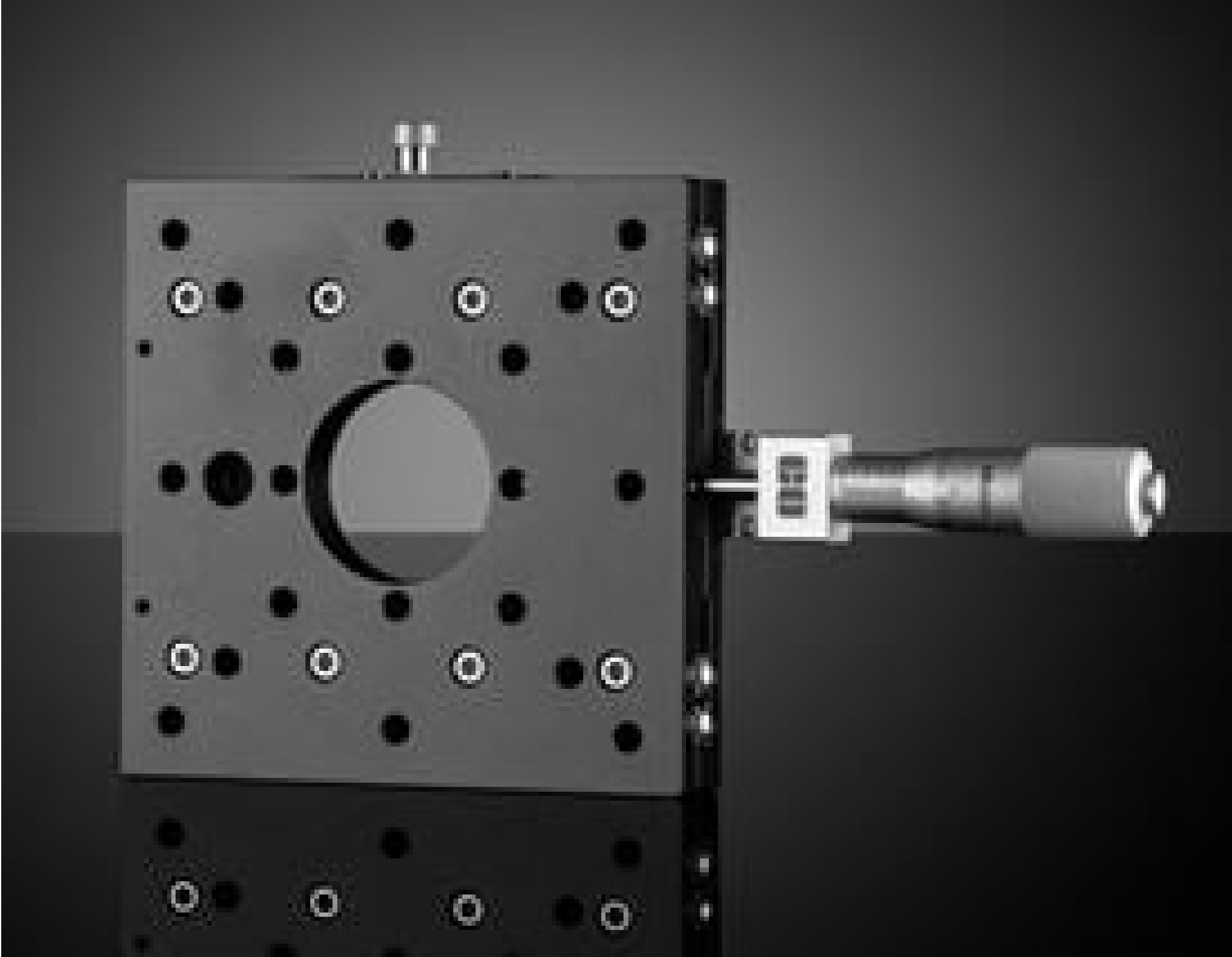

Stock #66-469 3-5 DAYS

- 1 + **A\$992.00**

ADD TO CART

Qty 1-2
A\$992.00
Qty 3+
A\$869.44
Volume Pricing
Request Quote

Get Product Downloads

Type of Movement:
Linear (X)

Guide System:
Crossed Roller Bearing

Type of Drive:
Metric Micrometer

Drive Orientation:
Center Drive

Type: Metric
Stage Size (mm): 125 x 125
Travel (mm): 25
Center Hole: M42 x 0.75
Construction: Aluminium Stage
Leadscrew Pitch (mm): 0.5
Load Capacity (kg): 20
Mounting Threads: (1) M42 x 0.75, (20) M6 x 1
Stage Size (inches): 4.92 x 4.92
Straight Line Accuracy (µm): 2
Pitch (arcsec): 30
Yaw (arcsec): 25

Regulatory Compliance

RoHS 2015: Exempt
Certificate of Conformance: View
Reach 233: Contains SVHC(s)
