


TECHSPEC[®] 12.5mm Dia. Laser Mirror Substrate

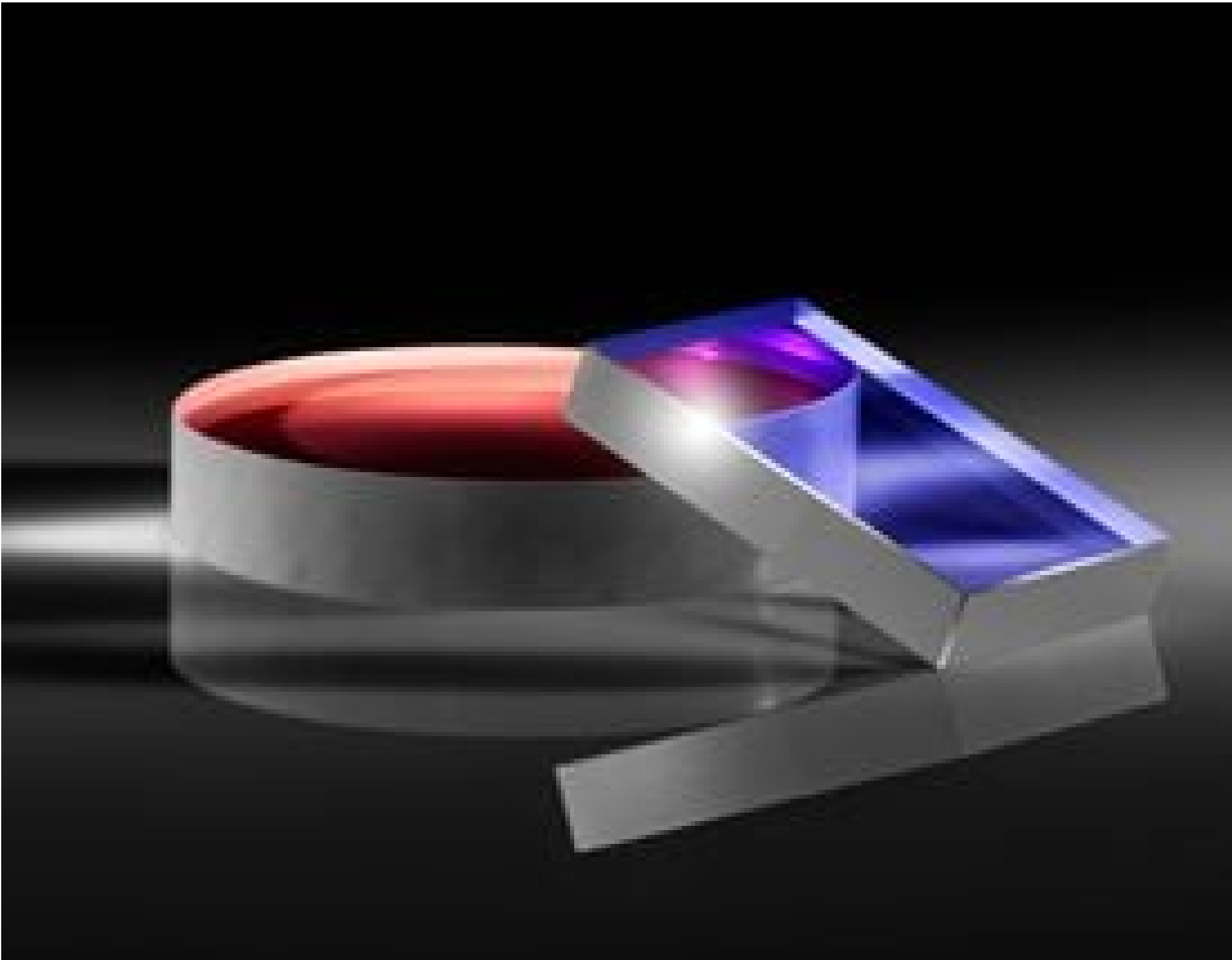

TECHSPEC[®] Laser Mirror Substrates

Stock #47-017 3-5 DAYS



1



A\$123.20

ADD TO CART

Qty 1-10

A\$123.20

Qty 11+

A\$107.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Surface Quality:
10-5

Type:
Laser Mirror Substrate

Parallelism (arcmin):
<3

Clear Aperture (%):

90
Back Surface: Ground
Surface Flatness (P-V): λ/10
Coating: Uncoated
Diameter (mm): 12.50 +0.00/-0.20
Thickness (mm): 6.00 ±0.20
Substrate: Fused Silica (Corning 7980)

Regulatory Compliance

RoHS 2015: Compliant
Reach 197: Compliant
Certificate of Conformance: View