


TECHSPEC® 12.5mm Diameter 3-12µm AR, Zinc Sulfide Multispectral Window

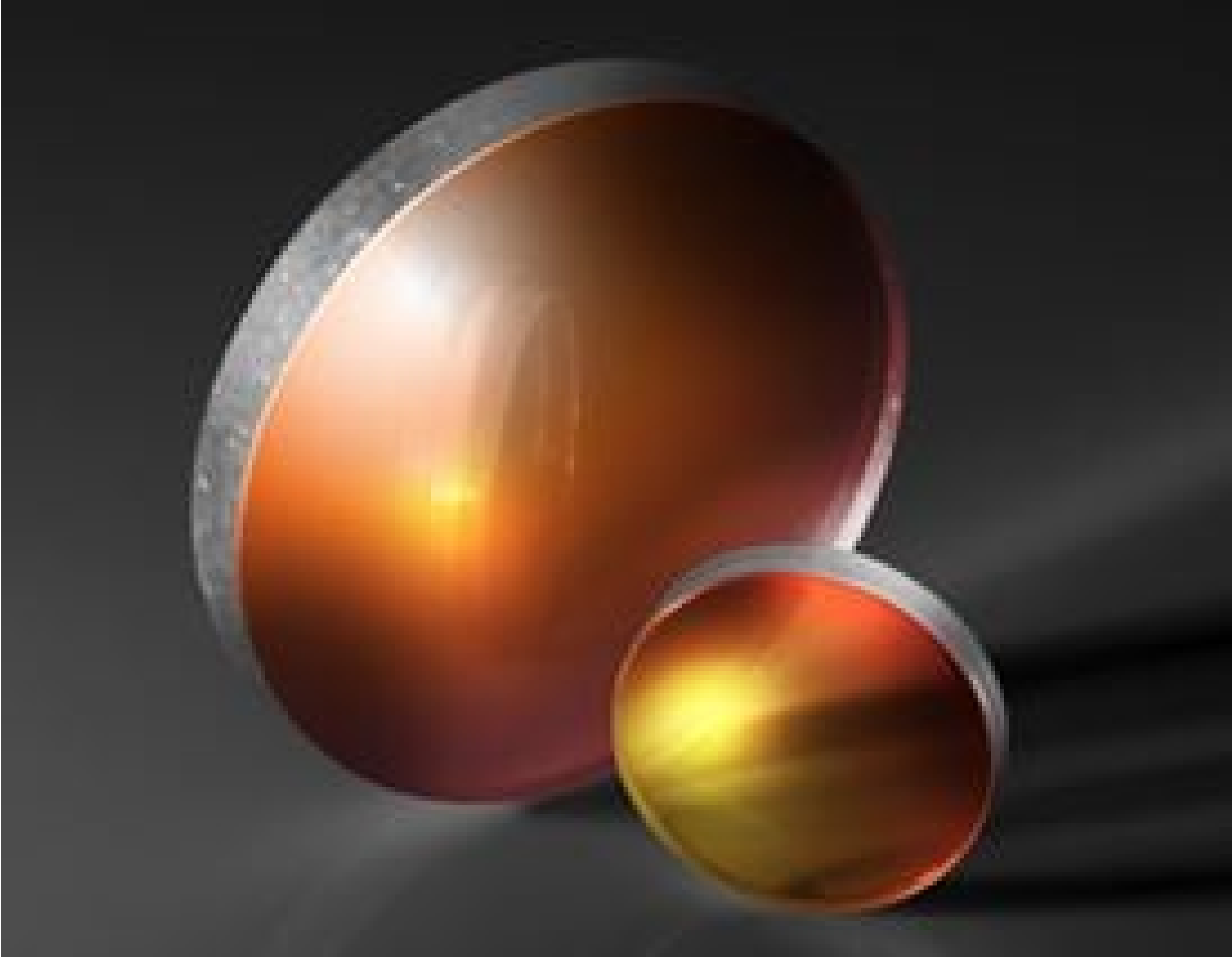

TECHSPEC® Zinc Sulfide Multispectral Windows

Stock **#64-144** 3-5 DAYS

⊖ 1 ⊕ **A\$468.00**

ADD TO CART

Qty 1-10

A\$468.00

Qty 11+

A\$421.60

Volume Pricing

[Request Quote](#)

Get Product Downloads



Bevel:
Protective as needed

Clear Aperture (%):
90.00

Clear Aperture CA (mm):
11.25

Diameter (mm): 12.50 +0.0/-0.1
Thickness (mm): 2.00 ±0.1
Coating: BBAR (3000-12000nm)
Coating Specification: R_{avg} <5.0% @ 3 - 12µm
Coefficient of Thermal Expansion CTE (10⁻⁶/°C): 6.8
Density (g/cm³): 4.08
Edges: Fine Ground
Index of Refraction n_d: 2.371
Knoop Hardness (kg/mm²): 210
Parallelism (arcmin): <1
Poisson's Ratio: 0.27
Substrate: Zinc Sulfide Multispectral
Surface Flatness (P-V): λ/10 @ 10.6µm
Surface Quality: 60-40
Type: Protective Window
Wavelength Range (nm): 3000 - 12000
Young's Modulus (GPa): 74.5

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View