


**TECHSPEC® 12.7 x 12.7mm Laser Mirror Substrate**

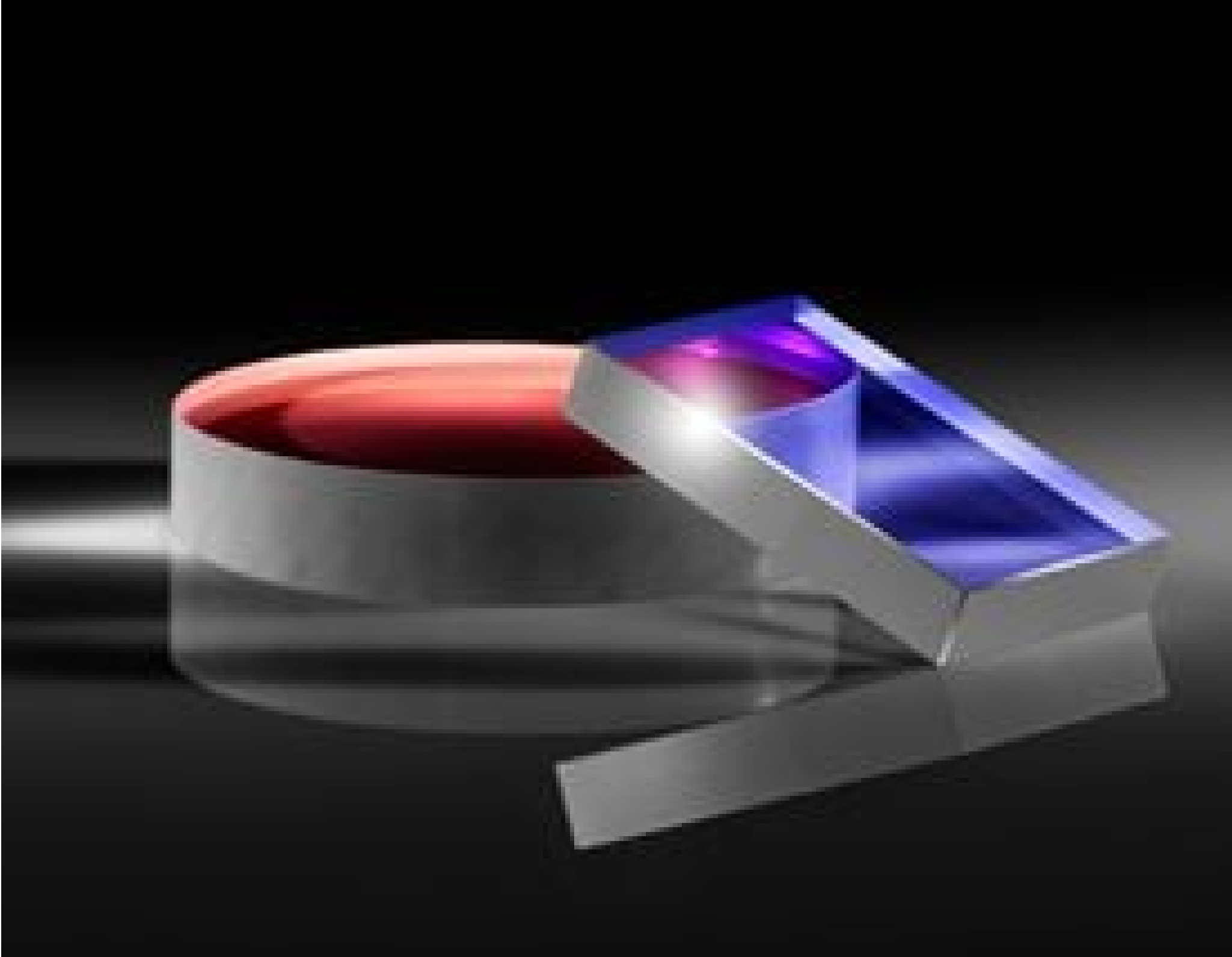

TECHSPEC® Laser Mirror Substrates

Stock **#37-724** 3-5 DAYS

- 1 +

**A\$156.80**

ADD TO CART

Qty 1-10

**A\$156.80**

Qty 11+

**A\$140.80**

Volume Pricing

[Request Quote](#)

Get Product Downloads

**Surface Quality:**  
10-5

**Type:**  
Laser Mirror Substrate

**Parallelism (arcmin):**  
<3

**Clear Aperture (%):**

|                                                                  |
|------------------------------------------------------------------|
| 85                                                               |
| <b>Back Surface:</b><br>Commercial Polish                        |
| <b>Surface Flatness (P-V):</b><br>λ/10                           |
| <b>Coating:</b><br>Uncoated                                      |
| <b>Dimensions (mm):</b><br>12.7 x 12.7 +0.00/-0.10               |
| <b>Thickness (mm):</b><br>6.35 ±0.20                             |
| <b>Substrate:</b><br><a href="#">Fused Silica</a> (Corning 7980) |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 209:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |