


**TECHSPEC® 12mm Dia x 72mm FL Uncoated, UV Plano-Convex Lens**

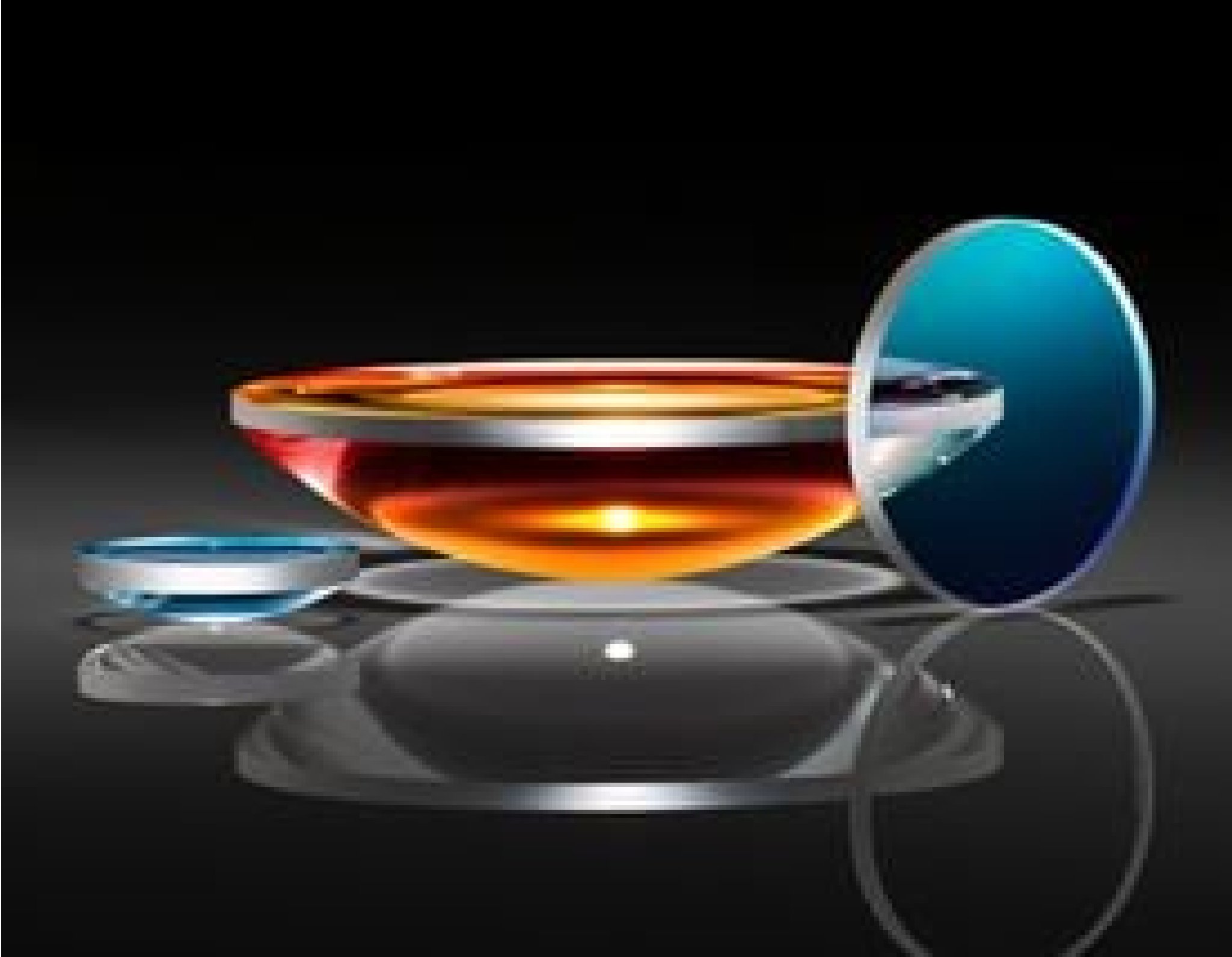

UV Fused Silica Plano-Convex (PCX) Lenses



Stock **#36-684** 3-5 DAYS

[Other Coating Options](#)

⊖ 1 ⊕

**A\$176.00**

ADD TO CART

Qty 1-5

A\$176.00

Qty 6+

A\$140.80

Volume Pricing

[Request Quote](#)

Get Product Downloads



**Diameter (mm):**  
12.00 +0.0/-0.025

**Effective Focal Length EFL (mm):**

|                                                               |
|---------------------------------------------------------------|
| 72.00 @ 587.6nm                                               |
| <b>Back Focal Length BFL (mm):</b><br>70.29                   |
| <b>Coating:</b><br>Uncoated                                   |
| <b>Substrate:</b> <a href="#">Fused Silica</a> (Corning 7980) |
| <b>Surface Quality:</b><br>40-20                              |
| <b>Power (P-V) @ 632.8nm:</b><br>1.5λ                         |
| <b>Irregularity (P-V) @ 632.8nm:</b><br>λ/4                   |
| <b>Focal Length Tolerance (%):</b><br>±1                      |
| <b>Centering (arcmin):</b><br><1                              |
| <b>Center Thickness CT (mm):</b><br>2.50 ±0.05                |
| <b>Edge Thickness ET (mm):</b><br>1.95                        |
| <b>Radius R<sub>1</sub> (mm):</b><br>33.01                    |
| <b>Clear Aperture CA (mm):</b><br>11                          |
| <b>f/#:</b><br>6                                              |
| <b>Numerical Aperture NA:</b><br>0.08                         |
| <b>Type:</b><br>Plano-Convex Lens                             |
| <b>Bevel:</b><br>Protective bevel as needed                   |
| <b>Wavelength Range (nm):</b><br>200 - 2200                   |

### Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 219:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |