


15mm Dia x 15mm Focal Length, Spherical Mirror

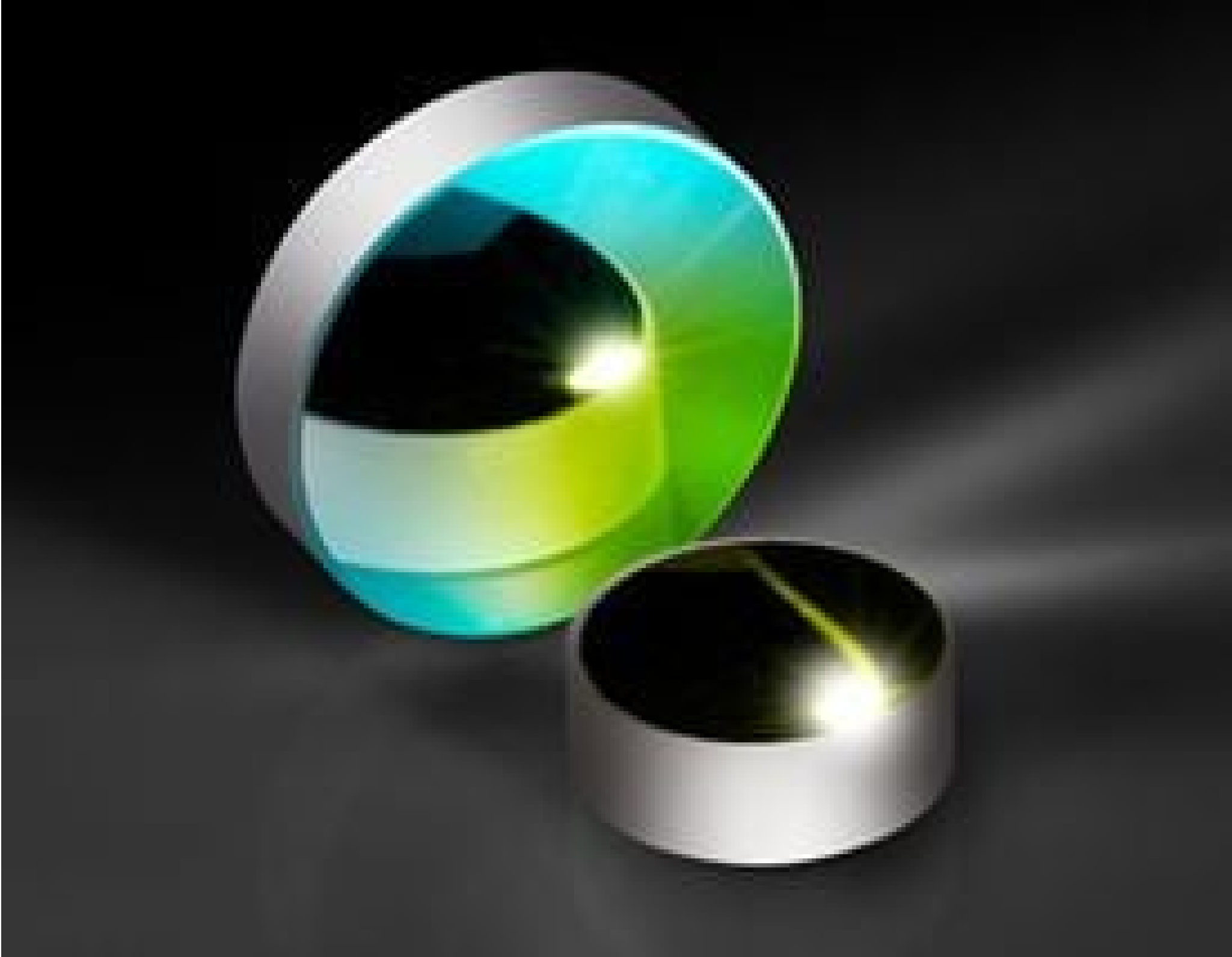

Stock **#46-234** 3-5 DAYS

- 1 +

A\$69.60

ADD TO CART

Qty 1-49
A\$69.60
Qty 50+
A\$62.40
Volume Pricing
Request Quote

Get Product Downloads

Substrate: [N-BK7](#)

Focal Length Tolerance (%): ±2

Surface Quality: 60-40

Surface Accuracy: λ/4

Diameter (mm): 15.00 +0.00/-0.30
Effective Focal Length EFL (mm): 15.00
Radius of Curvature (mm): 30.00
Aperture (f/#): f/1
Coating: Protected Aluminum (400-2000nm)
Coating Specification: R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm
Coating Type: Metal
Back Surface: Ground
Center Thickness CT (mm): 3.00
Center Thickness Tolerance (mm): ±0.30
Edge Thickness ET (mm): 5.01
Edges: Ground
Radius R (mm): 30.0
Type: Spherical Mirror
Wavelength Range (nm): 400 - 2000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant