


2.0 OD, 25mm Dia., IR Neutral Density Filter

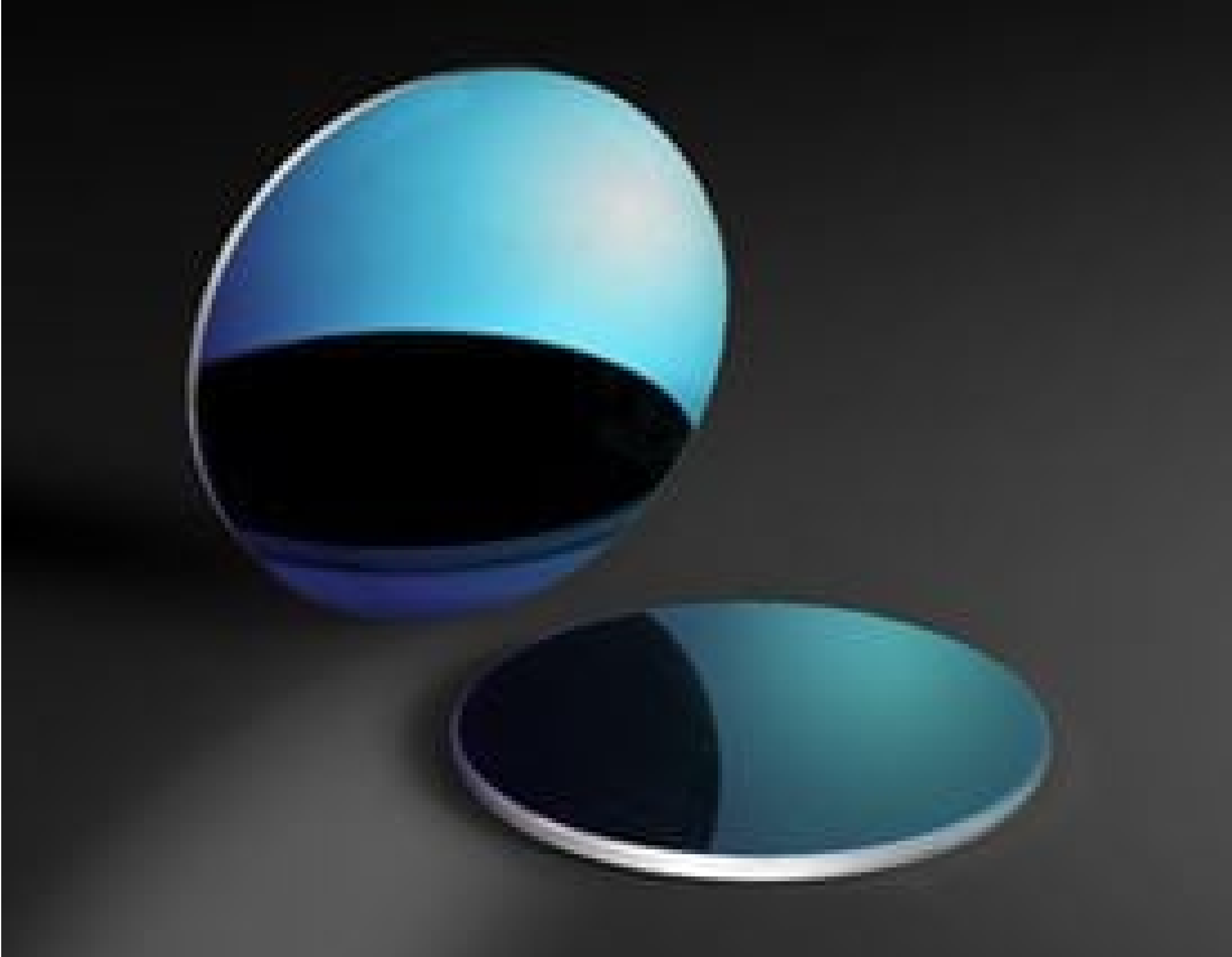

Infrared (IR) Neutral Density (ND) Filters

Stock **#64-356** 3-5 DAYS

- 1 + **A\$614.40**

ADD TO CART

Qty 1-10

A\$614.40

Qty 11+

A\$551.84

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

25.00 ±0.2

Optical Density OD (Average):

2.0

Substrate: ☐

Germanium (Ge)

Coating:

Metallic Based ND
Surface Quality: 80-50
Thickness (mm): 1.00 ±0.2
Transmission (%): 1.0
Transmission Tolerance (%): ±0.25
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 2000 - 14,000
Parallelism (arcmin): <10
Clear Aperture (%): 90
Wavelength Range (µm): 2 - 14
Surface Flatness (P-V): 3 - 5λ

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant