


TECHSPEC® 20mm 50R/50T NIR Cube Beamsplitter

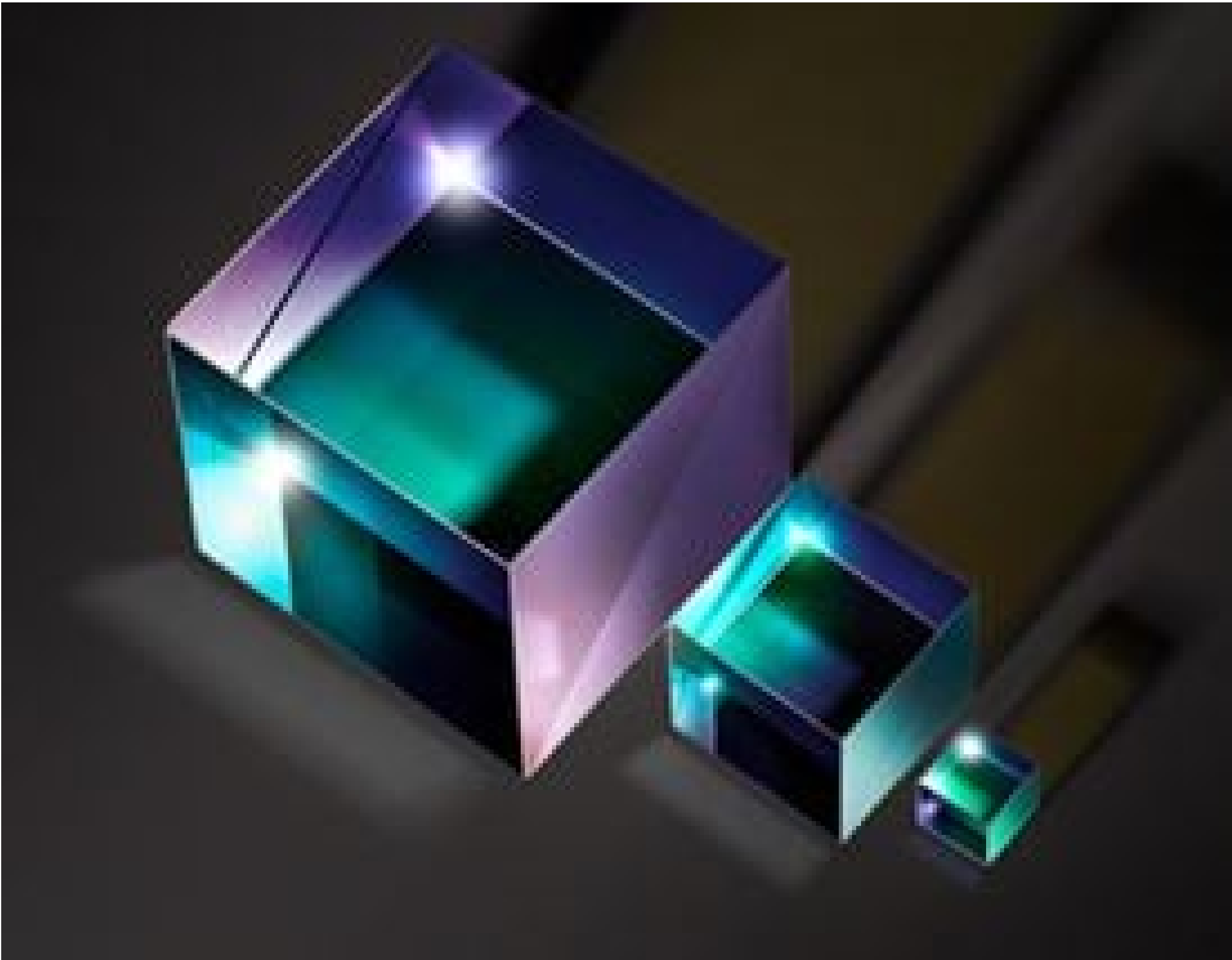

Stock #14-642 3-5 DAYS

- 1 + **A\$350.40**

ADD TO CART

Qty 1-5
A\$350.40
Qty 6+
A\$280.00
Volume Pricing
Request Quote

Get Product Downloads



Beam Deviation (arcmin):
±3

Bevel:
Protective bevel as needed

Coating:
λ/4 MgF₂ @ 900nm on Faces
Multilayer Dielectric on Hypotenuse

Construction: Cube
Dimensions (mm): 20.0 x 20.0 x 20.0 ±0.10
Reflection/Transmission Ratio (R/T): 50/50
Reflection/Transmission Tolerance (%): ±5
Substrate: ☐ N-BK7
Surface Flatness (P-V): λ/4
Surface Quality: 40-20
Type: Standard Beamsplitter
Wavelength Range (nm): 700 - 1100
Power (fringes) @ 632.8nm: 1.25
Irregularity (fringes) @ 632.8nm: 0.25

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View