


20mm Dia x 80mm Focal Length, Spherical Mirror

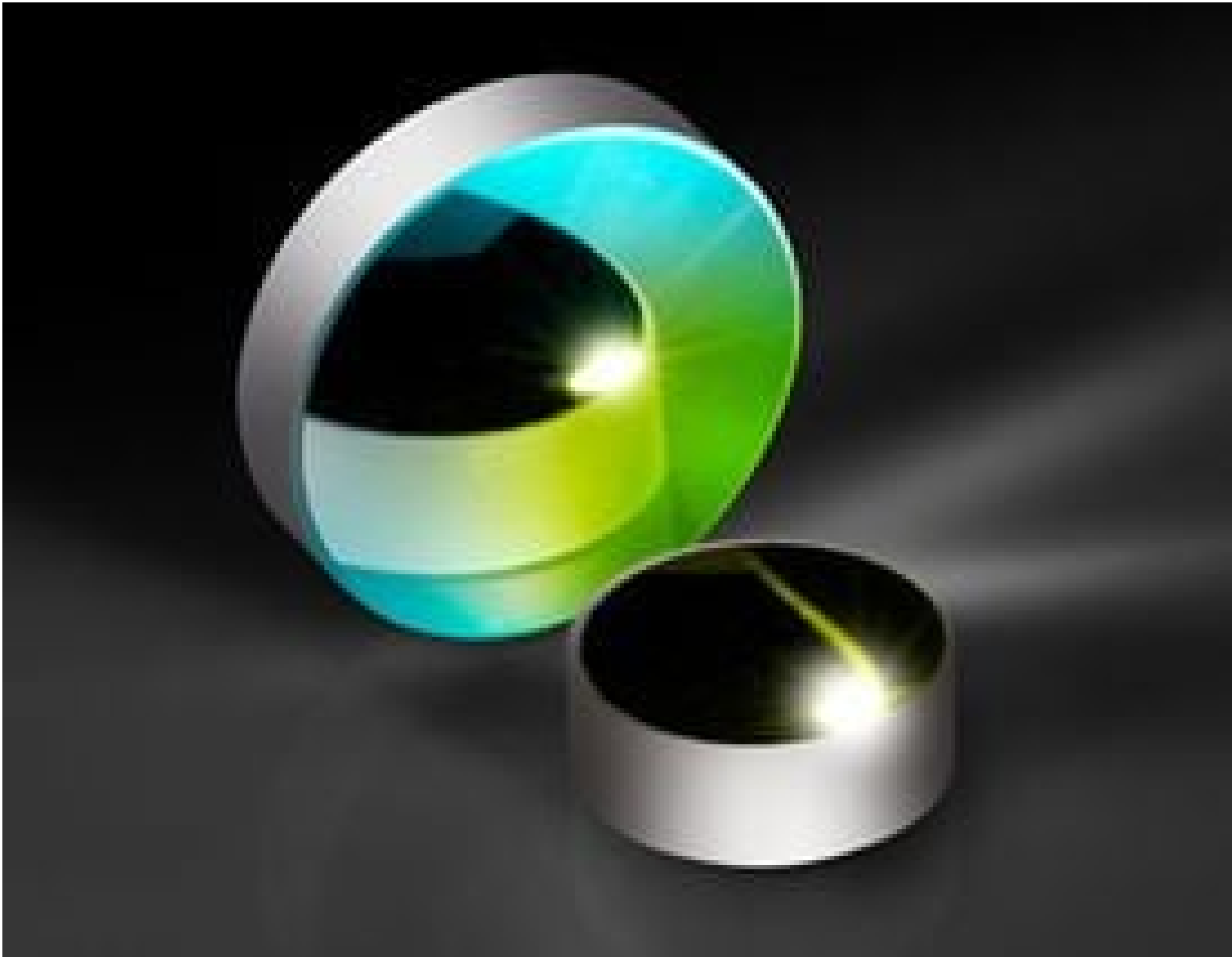

Stock #46-239 3-5 DAYS

⊖ 1 ⊕

A\$74.40

ADD TO CART

Qty 1-49

A\$74.40

Qty 50+

A\$67.20

Volume Pricing

[Request Quote](#)

Get Product Downloads

Substrate: [N-BK7](#)

Focal Length Tolerance (%):
±2

Surface Quality:
60-40

Surface Accuracy:
λ/4

Diameter (mm): 20.00 +0.00/-0.30
Effective Focal Length EFL (mm): 80.00
Radius of Curvature (mm): 160.00
Aperture (f/#): f/4
Coating: Protected Aluminum (400-2000nm)
Coating Specification: R _{avg} >85% @ 400 - 700nm R _{avg} >90% @ 400 - 2000nm
Coating Type: Metal
Back Surface: Ground
Center Thickness CT (mm): 3.00
Center Thickness Tolerance (mm): ±0.30
Edge Thickness ET (mm): 3.31
Edges: Ground
Radius R (mm): 160.0
Type: Spherical Mirror
Wavelength Range (nm): 400 - 2000

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant