


20mm Diameter, Optical Cast Plastic Window

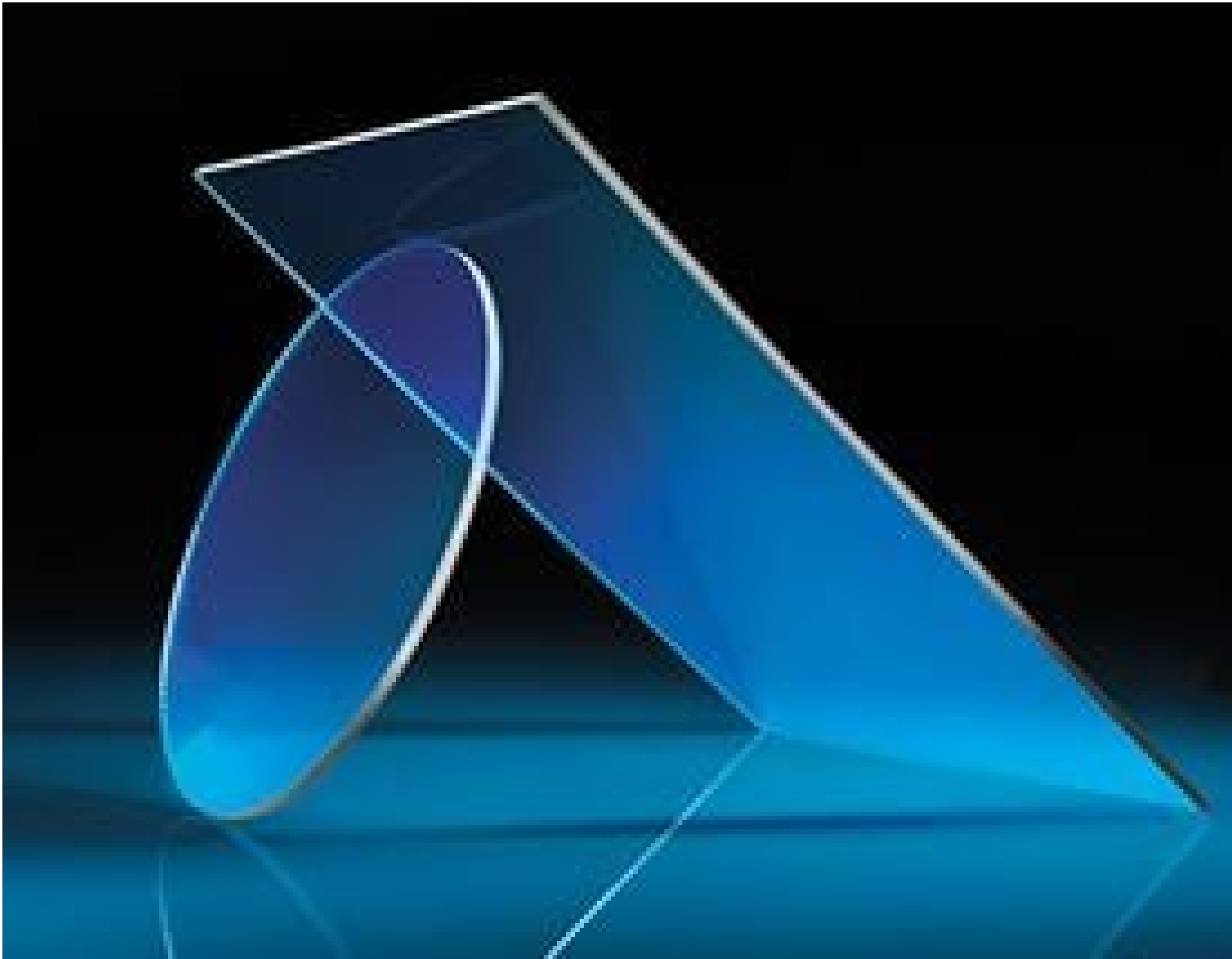

Stock #19-825

3-5 DAYS

-

1

+

A\$30.40

ADD TO CART

Qty 1-49

A\$30.40

Qty 50+

A\$24.40

Volume Pricing

[Request Quote](#)

Get Product Downloads



Abbe Number (v_d):
57.00

Diameter (mm):
20.00 $\pm$ 0.3

Diameter (inches):
0.79

Thickness (mm):

1.50 ±0.15
Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View