


10-25nm, 50.8mm Dia, EUV/IR Dichroic Filter

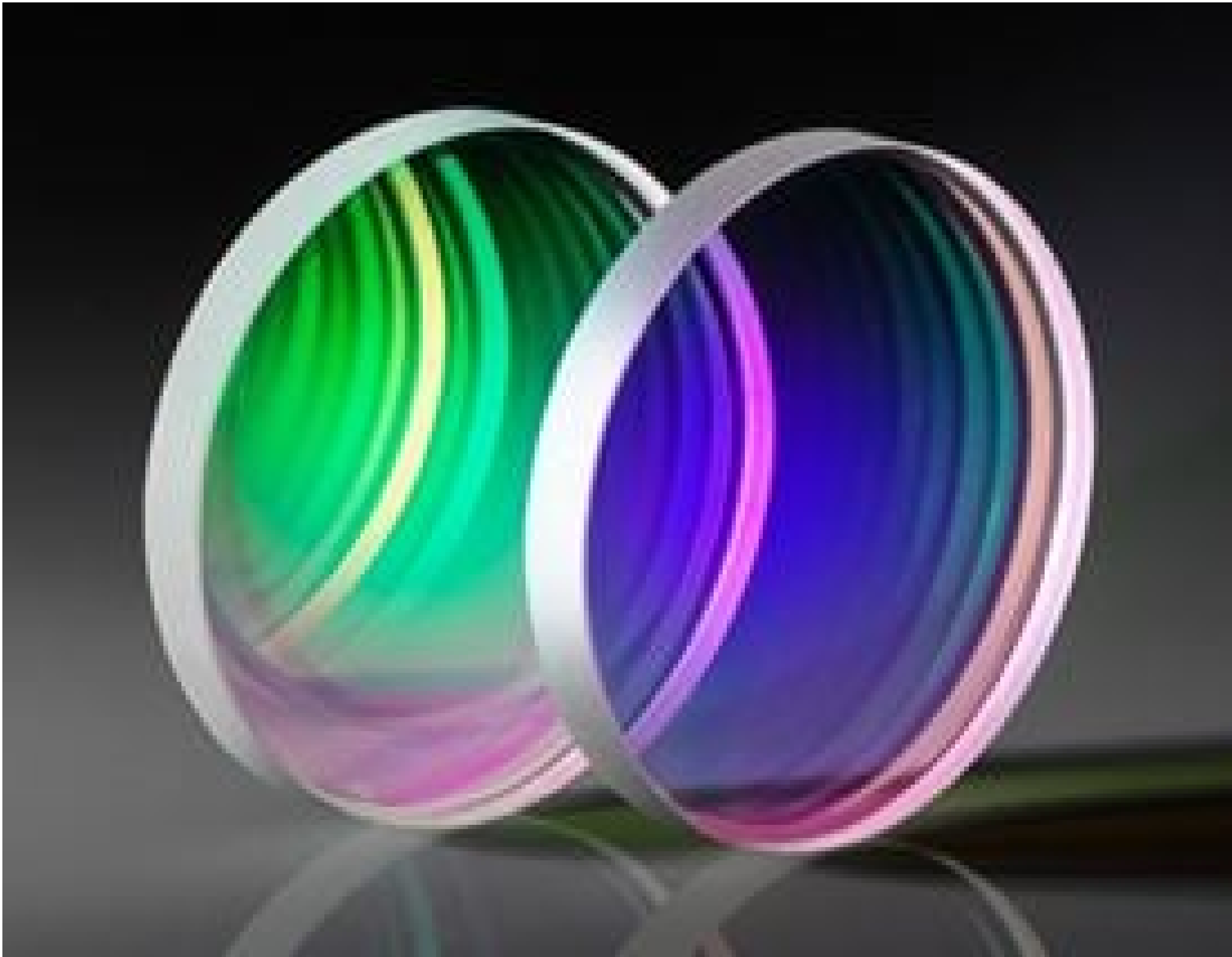

Extreme Ultraviolet (EUV) Dichroic Filters

Stock #18-279 3-5 DAYS

⊖ 1 ⊕

A\$7,920.00

ADD TO CART

Qty 1+
A\$7,920.00
Volume Pricing
Request Quote

Get Product Downloads

Diameter (mm): 50.80
Angle of Incidence (°): 78
Substrate: ☐ Fused Silica (Coming 7980)
Coating: Dielectric Multilayer AR
Reflection (%): >35

Surface Quality:	20-10
Thickness (mm):	5.08 ±0.1
Type:	Dichroic Filter
Parallelism (arcmin):	<5
Dimensional Tolerance (mm):	+0.0/-0.2
Wavelength Range (nm):	10 - 25
Surface Figure, RMS:	<N10 @ 633nm

Regulatory Compliance

RoHS:	Compliant
Certificate of Conformance:	View