


TECHSPEC® 25.4 x 25.4mm Enhanced Aluminum, 4-6λ Mirror

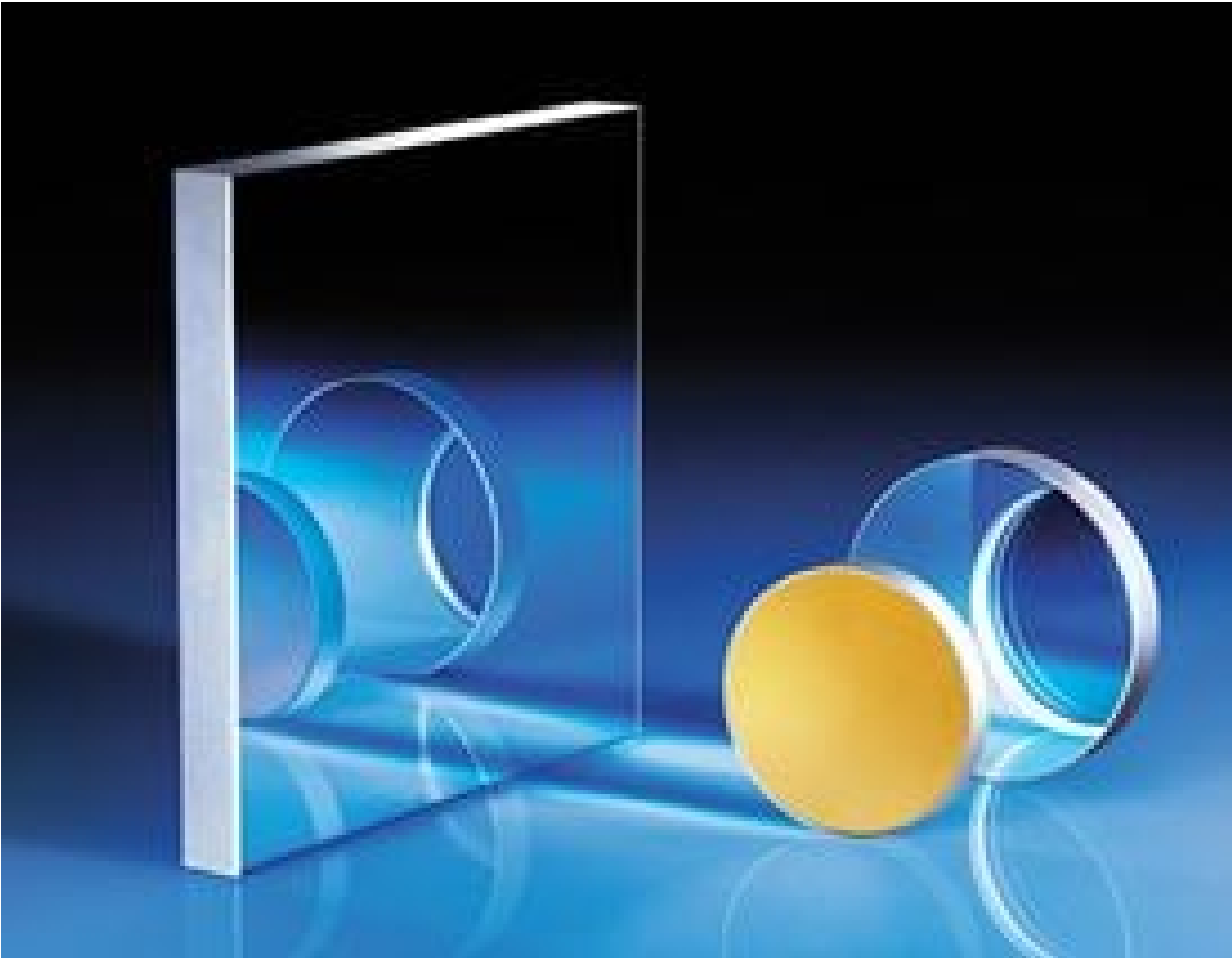

Stock **#83-486** 3-5 DAYS

- 1 +

A\$41.60

ADD TO CART

Qty 1-5
A\$41.60
Qty 6+
A\$33.60
Volume Pricing
Request Quote

Get Product Downloads

Surface Flatness (P-V):
4 - 6λ

Substrate: ☐
Float Glass

Surface Quality:
60-40

Dimensions (mm):
25.4 x 25.4

Dimensional Tolerance (mm): ±0.25
Coating Specification: R_{avg} ≥95% @450 - 650nm @45°
Coating: Enhanced Aluminum (450-650nm)
Coating Type: Metal
Clear Aperture CA (mm): 24.13 x 24.13
Edges: Seamed, 0.5mm Maximum Edge Chip
Thickness (mm): 3.00
Type: Flat Mirror
Wavelength Range (nm): 450 - 650
Length (mm): 25.40
Width (mm): 25.40
Damage Threshold, By Design: 0.2 J/cm² @ 532nm, 10ns

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant