


25.4mm Diameter, Optical Cast Plastic Window

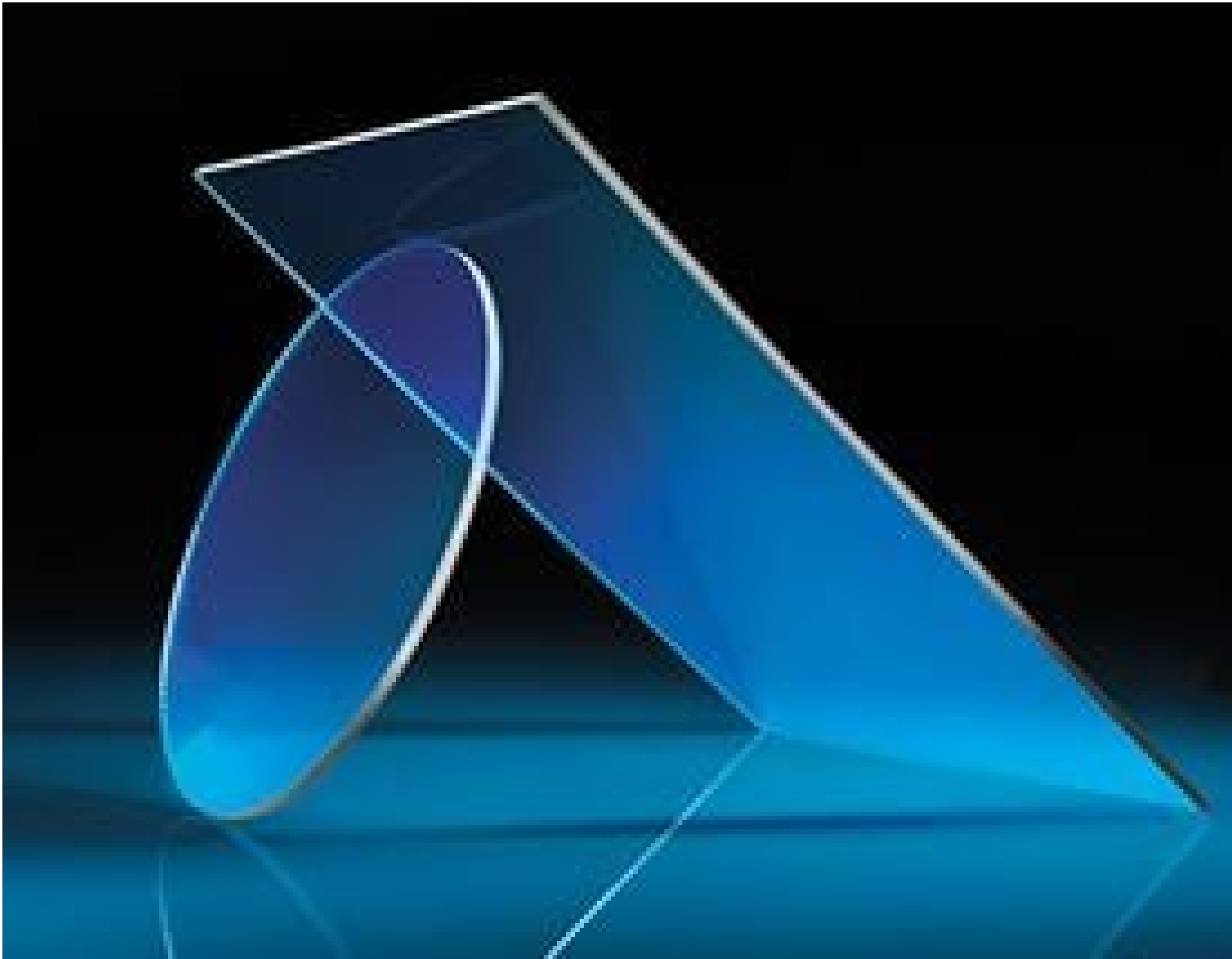

Stock #19-827 3-5 DAYS

- 1 +

A\$35.20

ADD TO CART

Qty 1-49
A\$35.20
Qty 50+
A\$28.00
Volume Pricing
Request Quote

Get Product Downloads



Abbe Number (v_d):
57.00

Diameter (mm):
25.40 ±0.3

Diameter (inches):
1.00

Thickness (mm):

1.50 ±0.15
Coating: Uncoated
Density (g/cm³): 1.320
Index of Refraction n_d: 1.501
Operating Temperature (°C): 100 Continuous, 130 for 1 hour
Substrate: Thermoset ADC (CR-39®)
Transmission (%): >90 (typical)
Type: Protective Window
Wavelength Range (nm): 400 - 1500

Regulatory Compliance

RoHS 2015: Compliant
Reach 223: Compliant
Certificate of Conformance: View