 



**TECHSPEC® 25mm Dia., NIR Broadband Dielectric,  $\lambda$ /10 Stemmed Mirror**

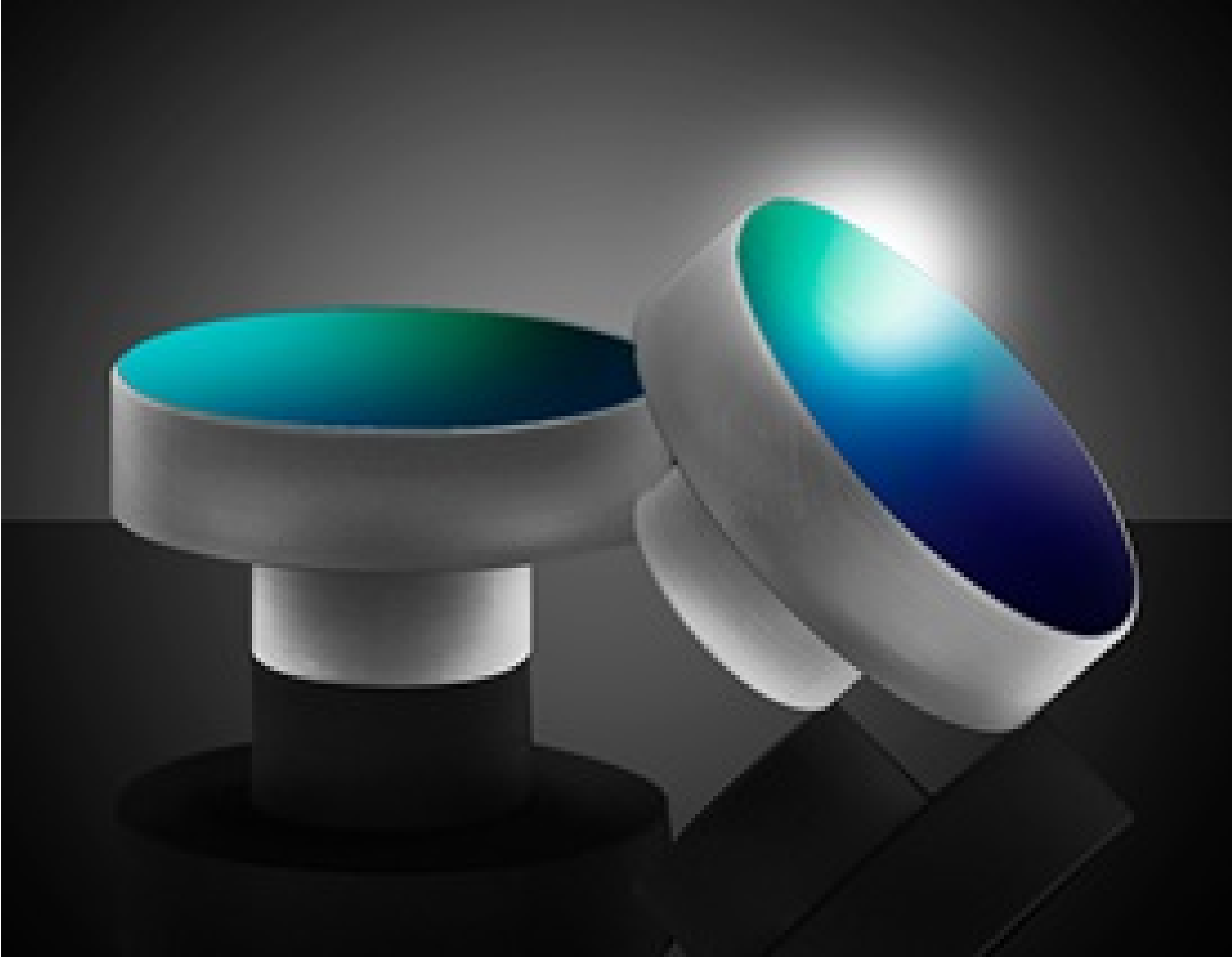

Stock #16-736 3-5 DAYS

- 1 + **A\$252.80**

ADD TO CART

|                               |
|-------------------------------|
| Qty 1-5                       |
| A\$252.80                     |
| Qty 6+                        |
| A\$202.40                     |
| Volume Pricing                |
| <a href="#">Request Quote</a> |

Get Product Downloads



Diameter (mm):  
25.00 +0.00/-0.10

Surface Flatness (P-V):  
 $\lambda$ /10

|                                                                                                                                                                                          |
|------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------------|
| <div><div>Substrate: </div><div><a href="#">Fused Silica</a> (Coming 7980)</div></div>                   |
| <div><div>Back Surface:</div><div>Commercial Polish</div></div>                                                                                                                          |
| <div><div>Surface Quality:</div><div>20-10</div></div>                                                                                                                                   |
| <div><div>Coating Specification:</div><div>R<sub>avg</sub> ≥98% @ 750 - 1100nm (0 - 45°, All Polarizations)<br/>R<sub>avg</sub> ≥99% @ 750 - 110nm (0 - 45°, S-Polarization)</div></div> |
| <div><div>Coating:</div><div>Dielectric Mirror (750-1100nm)</div></div>                                                                                                                  |
| <div><div>Coating Type:</div><div>Dielectric</div></div>                                                                                                                                 |
| <div><div>Clear Aperture (%):</div><div>90.00</div></div>                                                                                                                                |
| <div><div>Edges:</div><div>Ground, protective bevel as needed</div></div>                                                                                                                |
| <div><div>Thickness (mm):</div><div>13.00 ±0.20</div></div>                                                                                                                              |
| <div><div>Type:</div><div>Stemmed Mirror</div></div>                                                                                                                                     |
| <div><div>Wavelength Range (nm):</div><div>750 - 1100</div></div>                                                                                                                        |
| <div><div>Compatible Kinematic Mount:</div><div><a href="#">#58-853</a></div></div>                                                                                                      |
| <div><div>Stem Diameter (mm):</div><div>12.50 +0.00/-0.10</div></div>                                                                                                                    |
| <div><div>Stem Length (mm):</div><div>6.50 ±0.20</div></div>                                                                                                                             |
| <div><div>Damage Threshold, Reference: </div><div>1J/cm<sup>2</sup>, 20ns, 20Hz @ 1064nm</div></div>  |

## Regulatory Compliance

|                                                                                  |
|----------------------------------------------------------------------------------|
| <div><div>RoHS:</div><div><a href="#">Compliant</a></div></div>                  |
| <div><div>Certificate of Conformance:</div><div><a href="#">View</a></div></div> |