


TECHSPEC[®] 25mm Dia. Wire Grid Polarizing Film

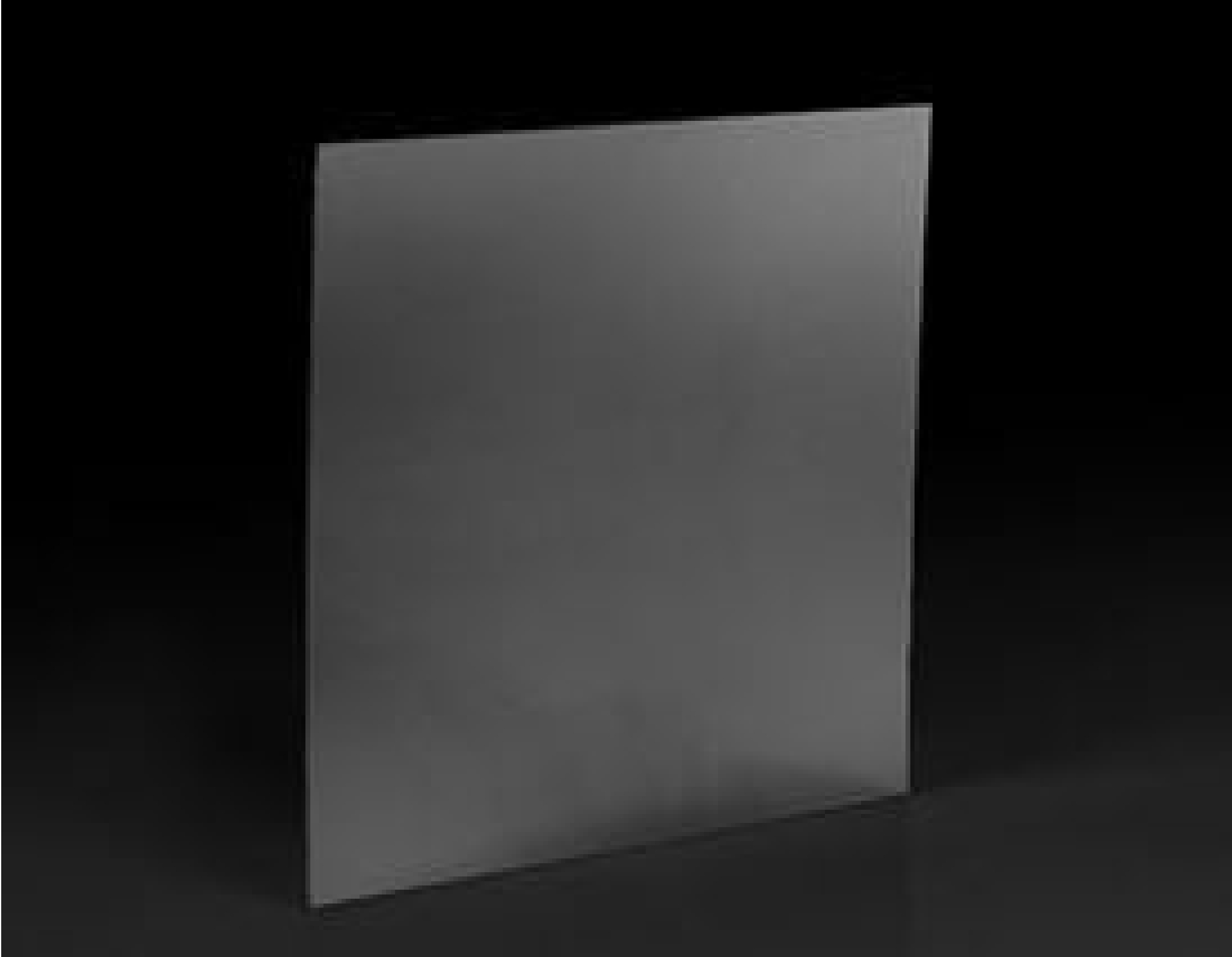

TECHSPEC[®] Wire Grid Polarizing Film

Stock **#34-254** CLEARANCE 3-5 DAYS

-

1

+

A\$68.72

ADD TO CART

Qty 1+

A\$68.72

Volume Pricing

[Request Quote](#)

Get Product Downloads



Angle of Incidence (°):
0 - 45

Diameter (mm):
25.00

Extinction Ratio:
>4,250:1 @ 550nm

Substrate: ☐
[Aluminum Wires on TAC Film](#)

Operating Temperature (°C): 60 Max @ 90% RH 105 in dry conditions
Thickness (mm): 0.08
Transmission (%): 85 (for p-polarized light @ 550nm)
Type: Linear Polarizer
Dimensional Tolerance (mm): +0/-0.3
Construction: Wire Grid
Wavelength Range (nm): 400 - 1200
Axis Orientation: 0° ± 1.5°, marked by Notch

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Contains SVHC(s)