

[See all 6 Products in Family](#)

## 25mm Dia. x 200mm FL Uncoated, DCX N-K5 Lens



Stock #32-902 CLEARANCE 20+ In Stock

⊖ 1 ⊕ A\$33<sup>.52</sup>

ADD TO CART

### Volume Pricing

Qty 1+	A\$33.52 each
Need More?	<a href="#">Request Quote</a>

### Product Downloads

#### General

Double-Convex Lens **Type:**

#### Physical & Mechanical Properties

25.00 +0.00/-0.10 **Diameter (mm):**

<1 **Centering (arcmin):**

5.00 ±0.10 **Center Thickness CT (mm):**

**Edge Thickness ET (mm):**

4.25

24 Clear Aperture CA (mm):

Protective as needed Bevel:

## Optical Properties

200.00 @ 587.6nm Effective Focal Length EFL (mm):

198.35 Back Focal Length BFL (mm):

Uncoated Coating:

N-K5 Substrate:

40-20 Surface Quality:

1.5λ Power (P-V) @ 632.8nm:

λ/4 Irregularity (P-V) @ 632.8nm:

±1 Focal Length Tolerance (%):

8.00 f#:

0.06 Numerical Aperture NA:

330 - 2500 Wavelength Range (nm):

## Regulatory Compliance


[View](#) Certificate of Conformance:

## Product Details

- N-K5 Substrate
- Various Anti-Reflection (AR) Coatings
- PCX and DCX Options Available

N-K5 Lenses are available in various diameters, focal lengths, as well as Plano-Convex and Double-Convex form factors. Anti-reflective coatings covering the VIS to NIR make these ideal for multiple applications.

## Technical Information

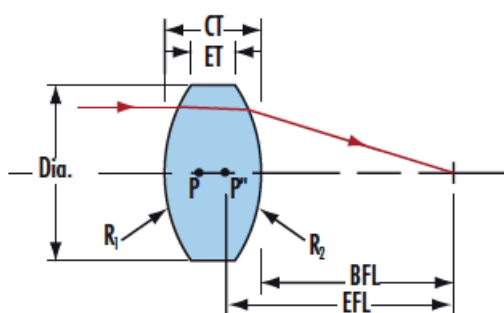

## Compatible Mounts