


TECHSPEC[®] 25mm Dia x 25mm FL Acylinder Lens, MgF₂ Coated

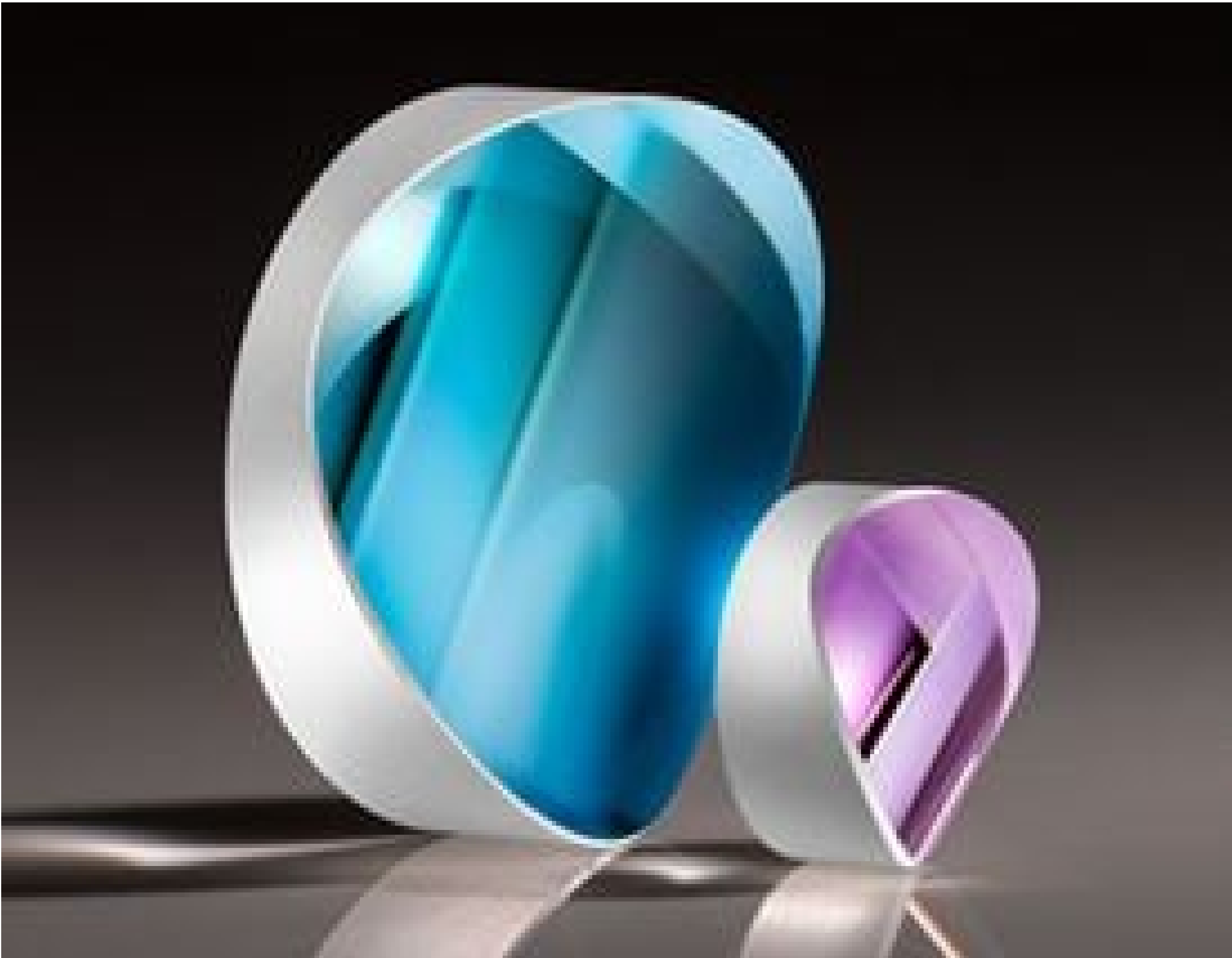

TECHSPEC Acylinder Lenses

Stock #86-037 3-5 DAYS



1



A\$1,368.00

ADD TO CART

Qty 1-5

A\$1,368.00

Qty 6+

A\$1,094.40

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
25.00 +0.0/-0.1

Effective Focal Length EFL (mm):
25.00

Substrate: [N-SF5](#)

f/#:

1.00
Numerical Aperture NA: 0.50
Coating: MgF ₂ (400-700nm)
Type: Acyliner Lens
Wavelength Range (nm): 400 - 700
Back Focal Length BFL (mm): 20.2
Center Thickness CT (mm): 8.00
Center Thickness Tolerance (mm): ±0.1
Clear Aperture (%): 90.00
Coating Specification: R _{avg} ≤1.75% @ 400 - 700nm
Edge Thickness ET (mm): 3.1
Focal Length Specification Wavelength (nm): 587.6
Surface Accuracy, RMS (µm): 1.0
Surface Quality: 60-40

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant