


TECHSPEC® 25mm Diameter 45°, Cyan Dichroic Filter

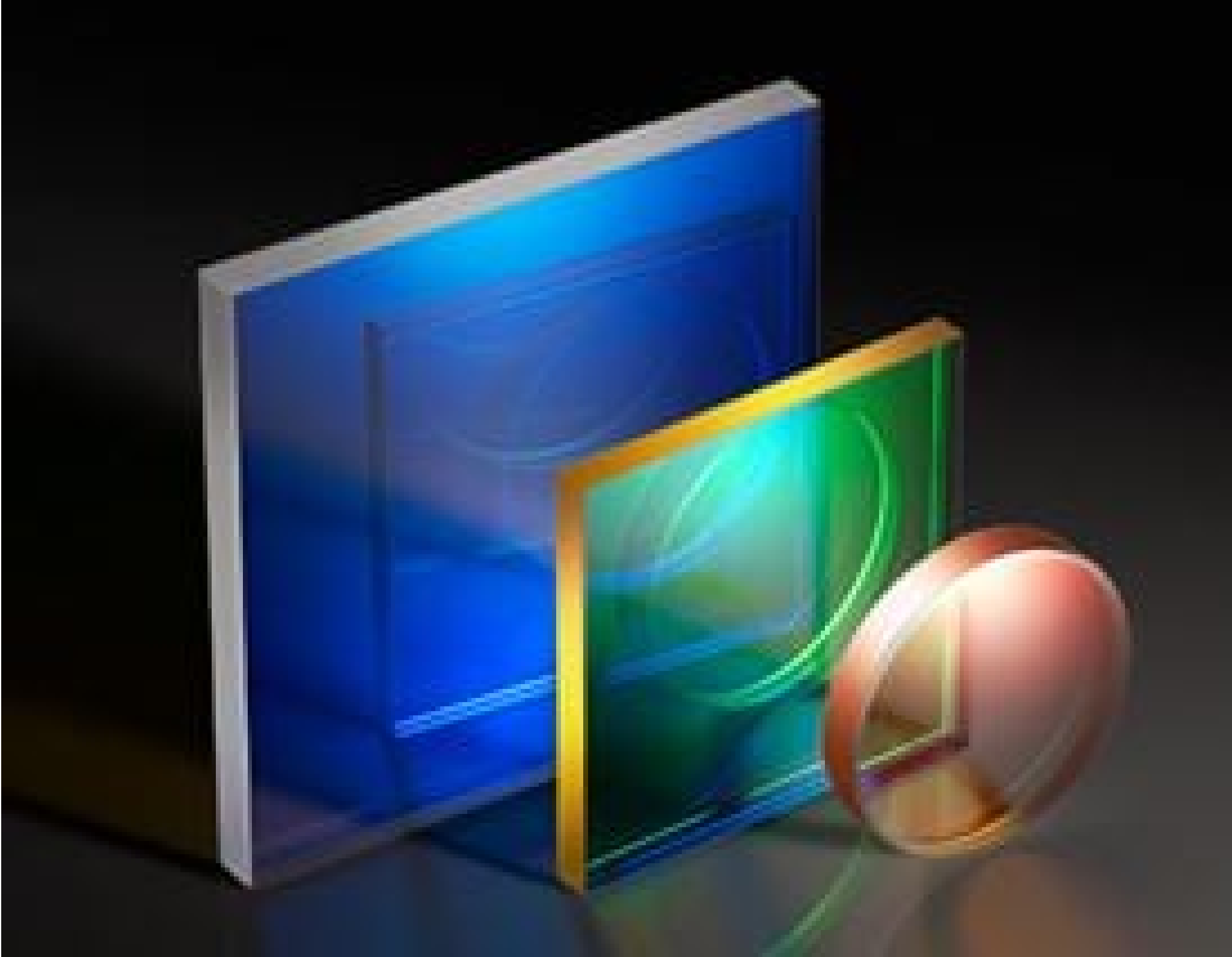

Stock #66-245 3-5 DAYS

- 1 + **A\$116.80**

ADD TO CART

Qty 1-10
A\$116.80
Qty 11+
A\$99.20
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
25.00

Angle of Incidence (°):
45.00

Cut-Off Wavelength (nm):
590.00

Substrate:

N-BK7
Coating: Traditional Coated
Color: Cyan
Reflection (%) : R _{abs} = 50% @ 590nm R _{avg} > 98% @ 400 - 565nm
Reflection Wavelength (nm) : 400 - 565
Surface Quality : 60-40
Thickness (mm) : 4.00
Thickness Tolerance (mm) : ±0.20
Transmission (%) : 90.00
Transmission Wavelength (nm) : 625 - 725
Type : Dichroic Filter
Wavelength Tolerance (nm) : ±15
Parallelism (arcmin) : <1
Dimensional Tolerance (mm) : ±0.25
Clear Aperture (%) : 90.00
Coating Specification : Surface 1: Multi-Layer Dichroic Surface 2: Single Layer MgF ₂
Wavelength Range (nm) : 400 - 725
Surface Flatness (P-V) : λ/4

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 235: Compliant