


27mm Diameter, Metric Thickness Gauge, Contact Reticle

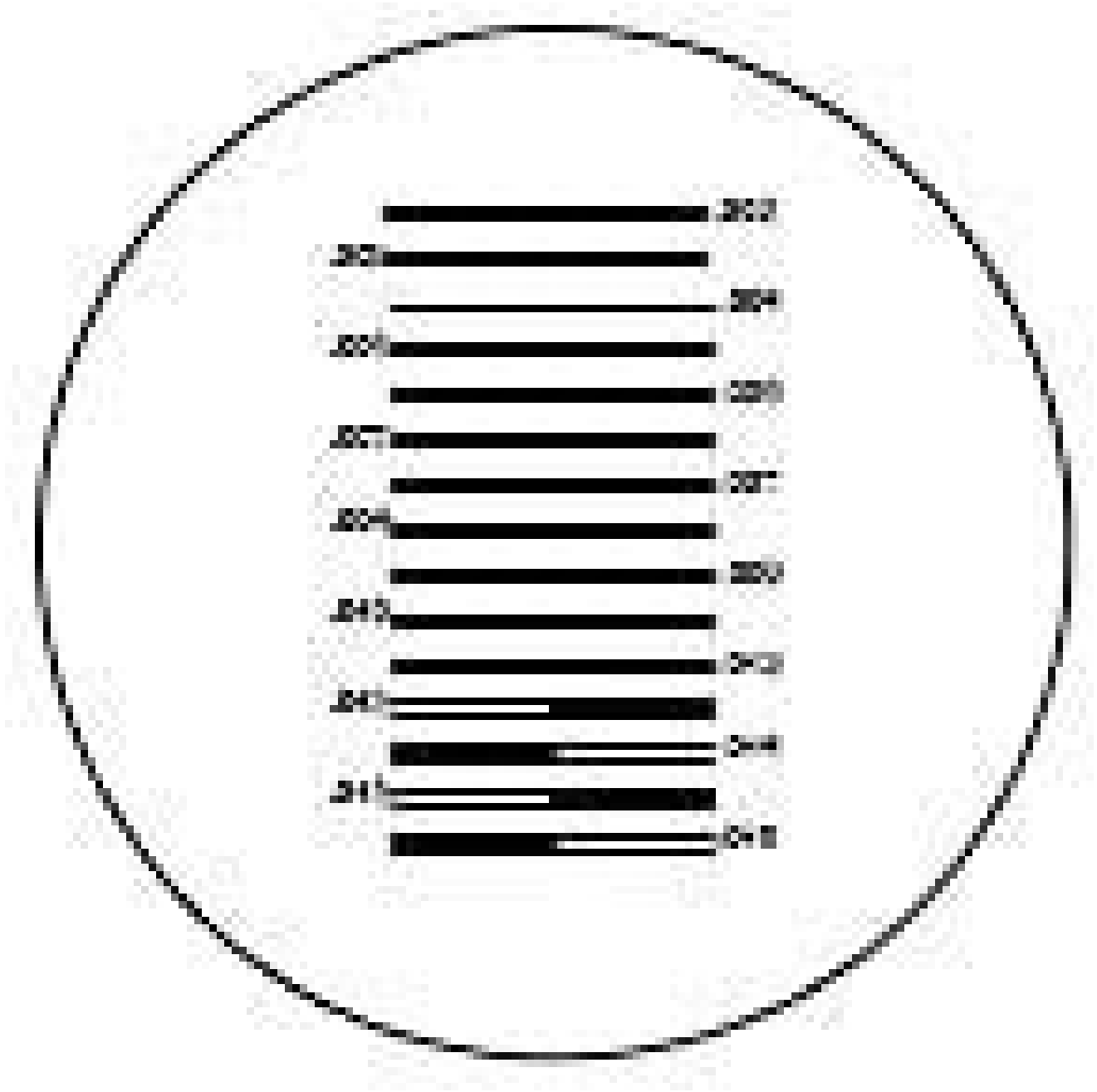

Thickness Gauge

Stock #30-586 3-5 DAYS



1



A\$107.20

ADD TO CART

Qty 1-4

A\$107.20

Qty 5+

A\$100.64

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
27.00 ±0.05

Angle Tolerance (arcsec):
±1

Line Thickness (µm):
25.00

Surface Quality:

60-40
Thickness (mm): 2.28
Thickness Tolerance (mm): ±0.127
Type: Metric Thickness Gauge
Line to Line Accuracy (µm): ±2
Bevel: Protective bevel as needed
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View