


TECHSPEC®

2mm Aperture x 50mm L Standard NA, Fused Silica Light Pipe

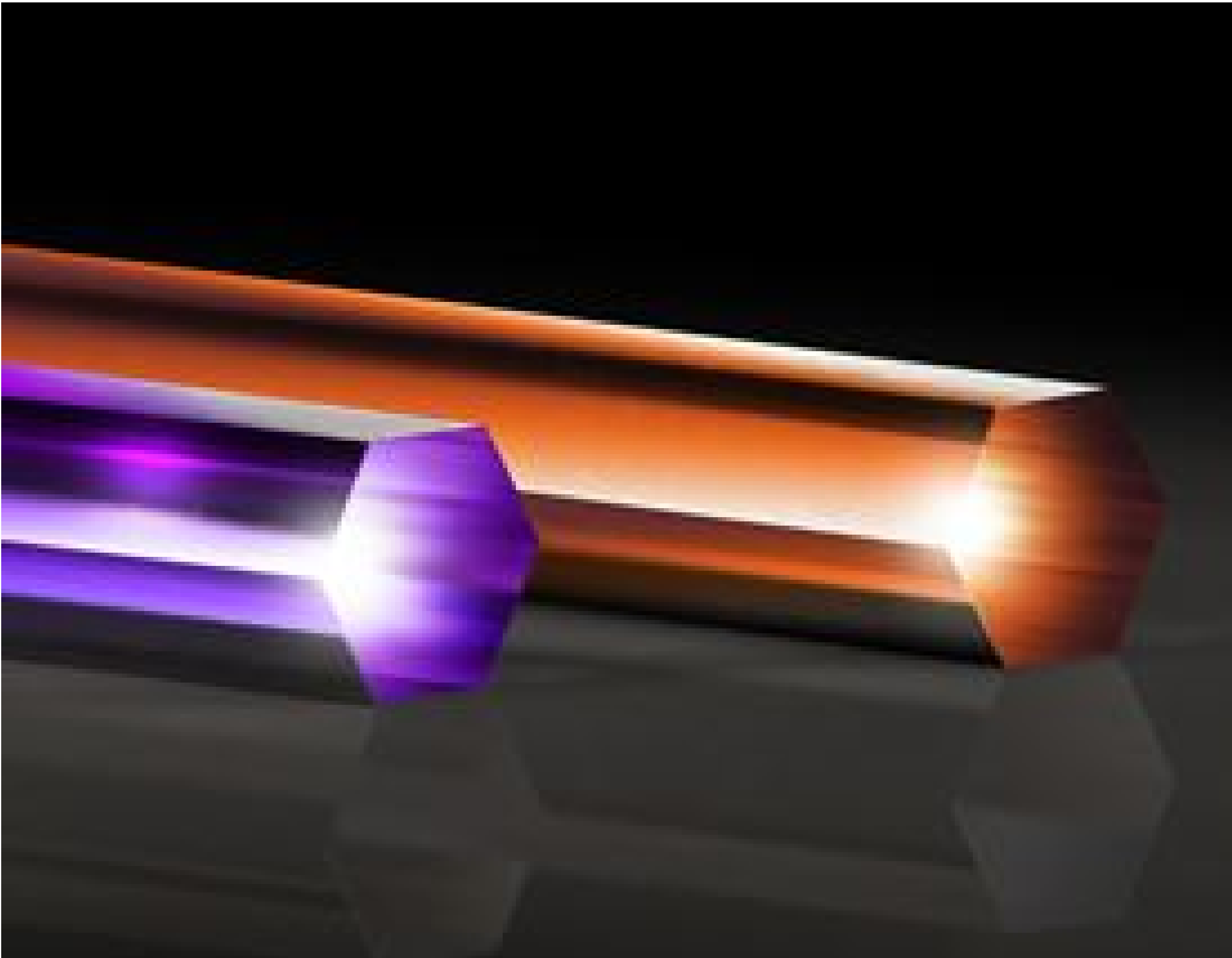

Fused Silica Light Pipe Homogenizing Rods



Stock #65-828 3-5 DAYS

-

1

+

A\$320.00

ADD TO CART

Qty 1-5

A\$320.00

Qty 6+

A\$256.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Coating:

Uncoated

Substrate:

[Fused Silica](#) (Corning 7980)

|                                                   |
|---------------------------------------------------|
| <b>Length (mm):</b><br>50.00                      |
| <b>Surface Quality:</b><br>60-40                  |
| <b>Type:</b><br>Light Pipe                        |
| <b>Entrance and Exit Aperture (mm):</b><br>2.00   |
| <b>Parallelism (arcmin):</b><br>5.00              |
| <b>Length Tolerance (mm):</b><br>±0.3             |
| <b>Aperture Tolerance (mm):</b><br>±0.10          |
| <b>Image Orientation:</b><br>Light Homogenization |
| <b>Light Source NA:</b><br>Standard               |
| <b>Wavelength Range (nm):</b><br>200 - 2200       |
| <b>Surface Flatness (P-V):</b><br>1λ              |
| <b>#Sorting:</b><br>4.00                          |

Regulatory Compliance

|                                                            |
|------------------------------------------------------------|
| <b>RoHS 2015:</b><br><a href="#">Compliant</a>             |
| <b>Reach 209:</b><br><a href="#">Compliant</a>             |
| <b>Certificate of Conformance:</b><br><a href="#">View</a> |