


3.0 OD 50mm Dia, Absorptive ND Filter

See More by [Hoya](#)

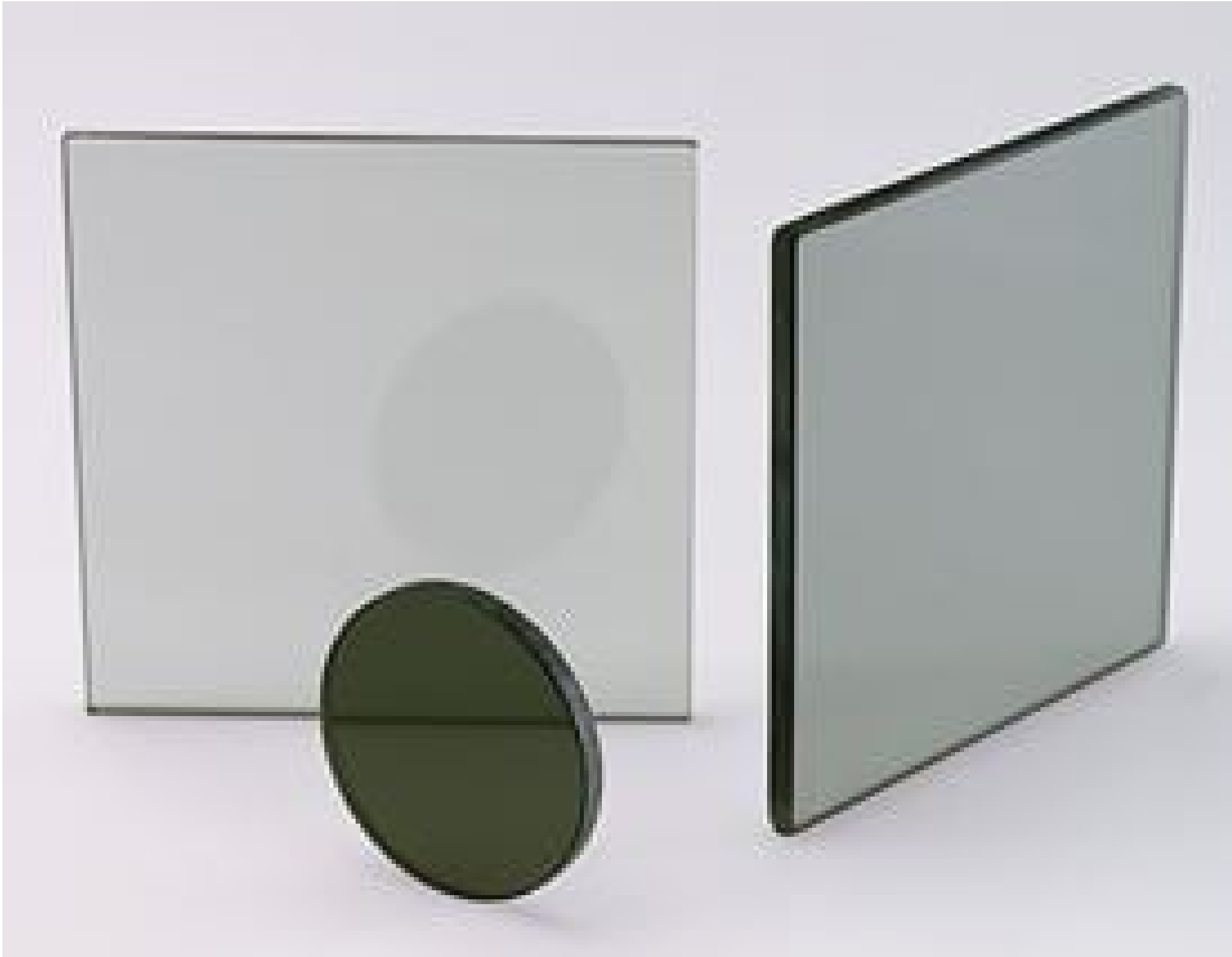

Stock #65-822 3-5 DAYS

- 1 +

A\$152.00

ADD TO CART

Qty 1-10
A\$152.00
Qty 11+
A\$134.40
Volume Pricing
Request Quote

Get Product Downloads



Diameter (mm):
50.00

Optical Density OD (Average):
3.0 ±0.3

Glass/Filter Number: Hoya ND-0.3
Substrate: ☐ ND Filter Glass
Coating: Uncoated
Index of Refraction n_d: 1.514
Surface Quality: 80-50
Transformation Temperature (°C): 490
Thickness (mm): 3.00
Thickness Tolerance (mm): ±0.5
Transmission (%): 0.1 (average)
Type: Neutral Density Filter
Blocking Wavelength Range (nm): 400 - 700
Dimensional Tolerance (mm): ±0.1
Parallelism (mm): <0.02

Regulatory Compliance

RoHS 2015: Compliant
Reach 224: Compliant
Certificate of Conformance: View