

**TECHSPEC® 30mm, 40mm Radius, English Goniometer**



30mm, 40mm Radius, English Goniometer

Stock **#66-520** **1 In Stock**

⊖ 1 ⊕ **A\$656<sup>00</sup>**

**ADD TO CART**

Volume Pricing	
Qty 1-2	<b>A\$656.00</b> each
Qty 3+	<b>A\$572.32</b> each
Need More?	<a href="#">Request Quote</a>

Product Downloads

**General**



English **Type:**  
5 **Resolution (arcmin):**

**Physical & Mechanical Properties**

Goniometer **Type of Movement:**  
**Stage Size (mm):**



30mm Goniometers

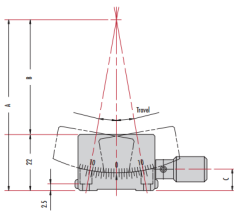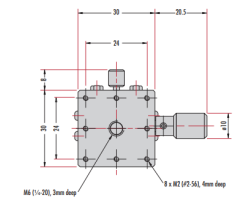

Ø (mm)	English Stage	Metric Stage	A (mm)	B (mm)	C (mm)	D (mm)
40	PH6-520	PH6-523	45	23	7.4	7
50	PH6-521	PH6-524	47	45	8.4	9
62	PH6-522	PH6-525	49	47	8.4	9