

[See all 18 Products in Family](#)

TECHSPEC®

30mm, 60mm Radius, English Goniometer



TECHSPEC® Goniometers



+1

Stock #66-521 5 In Stock

-

1

+

A\$748<sup>00</sup>

ADD TO CART



| Volume Pricing |                               |
|----------------|-------------------------------|
| Qty 1-2        | A\$748.80 each                |
| Qty 3+         | A\$652.96 each                |
| Need More?     | <a href="#">Request Quote</a> |

Product Downloads

| General                          |         |
|----------------------------------|---------|
| Type:                            | English |
| Resolution (arcmin):             | 5       |
| Physical & Mechanical Properties |         |
| Type of Movement:                |         |



30mm Goniometers

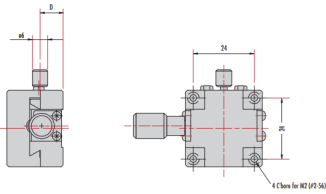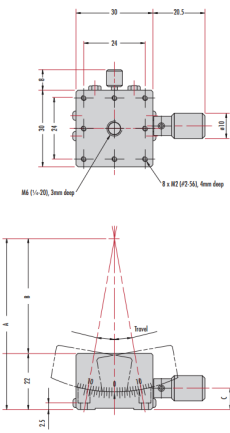

| Model | English Stage | Metric Stage | A (mm) | B (mm) | C (mm) | D (mm) |
|-------|---------------|--------------|--------|--------|--------|--------|
| 40    | 40A-320       | 40A-320      | 45     | 23     | 7.4    | 7      |
| 45    | 45A-321       | 45A-321      | 47     | 45     | 8.4    | 9      |
| 82    | 82A-322       | 82A-322      | 89     | 47     | 8.4    | 9      |