

**TECHSPEC® 30mm, Center Drive, Standard Top, 0.5" Travel, English Micrometer**



Stock **#66-387** **2 In Stock**

⊖ 1 ⊕ **A\$700<sup>00</sup>**

**ADD TO CART**

Volume Pricing

Qty 1-2	<b>A\$700.80</b> each
Qty 3+	<b>A\$611.20</b> each
Need More?	<a href="#">Request Quote</a>

Product Downloads

**General**

English **Type:**

**Physical & Mechanical Properties**


Linear (X) **Type of Movement:**

Crossed Roller Bearing **Guide System:**


Center Drive **Drive Orientation:**




**30mm Standard-Top Stages - Center Drive**

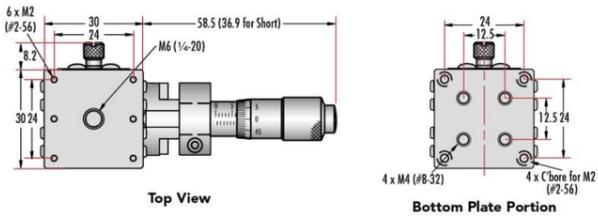


**30mm Standard-Top Stages - Side Drive**

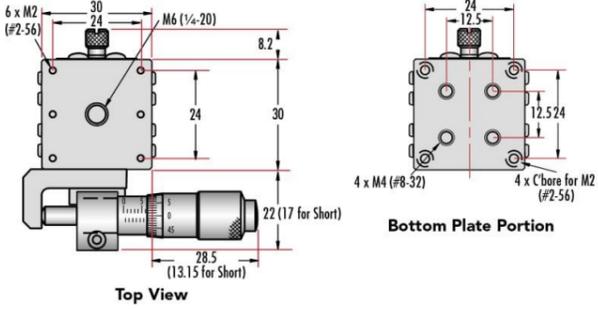


**40mm Standard-Top Stages - Center Drive**

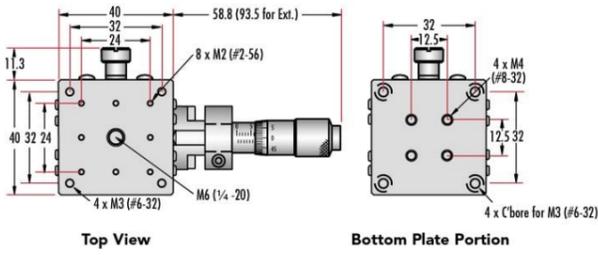


**40mm Standard-Top Stages - Side Drive**

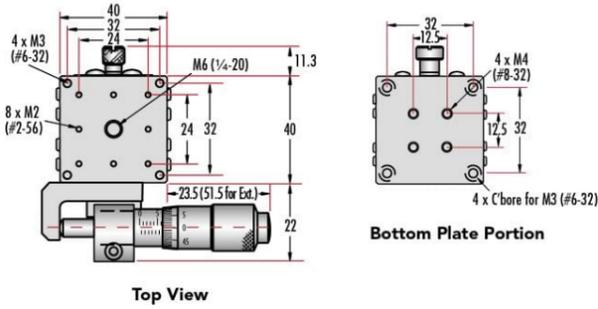


**70mm Standard-Top Stages - Center Drive**

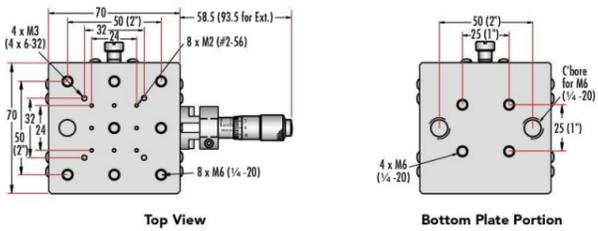

**70mm Standard-Top Stages - Side Drive**

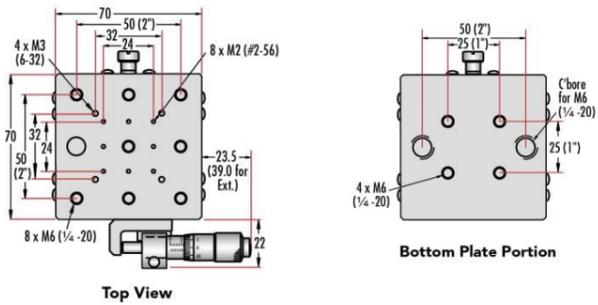

**125mm Standard-Top Stages - Center Drive**

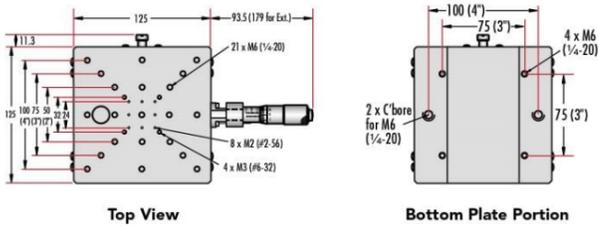

**125mm Standard-Top Stages - Side Drive**

