


TECHSPEC® 30mm Dia. x 120mm FL Uncoated, UV Plano-Convex Lens

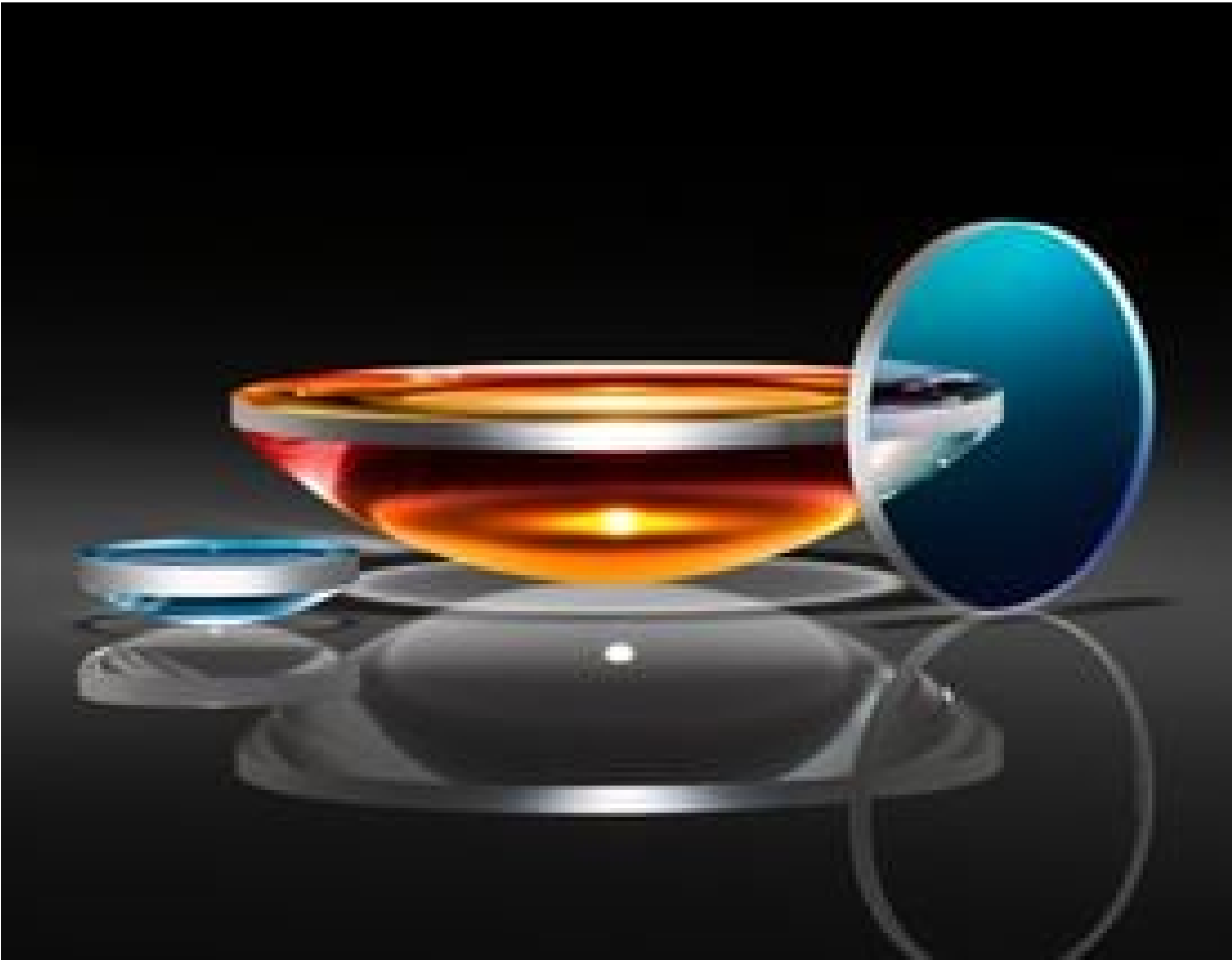

UV Fused Silica Plano-Convex (PCX) Lenses



Stock **#84-285** 3-5 DAYS

[Other Coating Options](#)

⊖ 1 ⊕

A\$260.00

ADD TO CART

Qty 1-5

A\$260.00

Qty 6+

A\$208.00

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
30.00

Effective Focal Length EFL (mm):

120.00 @587.6nm
Back Focal Length BFL (mm): 116.57
Coating: Uncoated
Substrate: Fused Silica (Corning 7980)
Surface Quality: 40-20
Power (P-V) @ 632.8nm: 1.5λ
Irregularity (P-V) @ 632.8nm: λ/4
Focal Length Tolerance (%): ±1
Centering (arcmin): <1
Center Thickness CT (mm): 5.00 ±0.10
Edge Thickness ET (mm): 2.92
Radius R₁ (mm): 55.02
Clear Aperture CA (mm): 29
f/#: 4
Numerical Aperture NA: 0.13
Type: Plano-Convex Lens
Bevel: Protective bevel as needed
Wavelength Range (nm): 200 - 2200

Regulatory Compliance

RoHS 2015: Compliant
Reach 219: Compliant
Certificate of Conformance: View