

TECHSPEC®

30mm, Side Drive, Standard Top, 0.25" Travel, English Micrometer



Stock

#83-504

5 In Stock

-

1

+

A\$700⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	A\$700.80 each
Qty 3+	A\$611.20 each
Need More?	Request Quote

Product Downloads

General

Type:

English


Physical & Mechanical Properties

Type of Movement:

Linear (X)

Guide System:


Crossed Roller Bearing

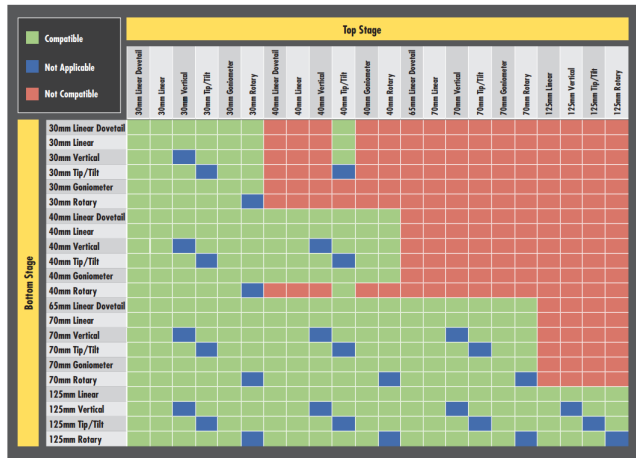


30mm Standard-Top Stages - Center Drive




30mm Standard-Top Stages - Side Drive

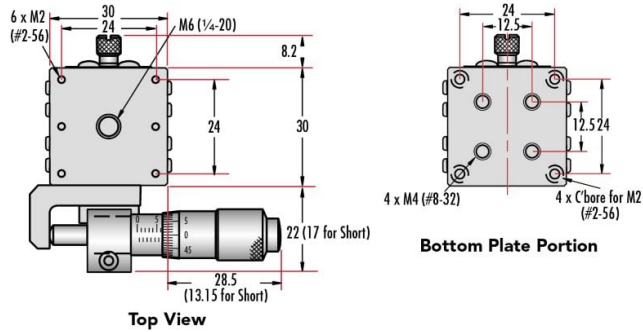

40mm Standard-Top Stages - Center Drive

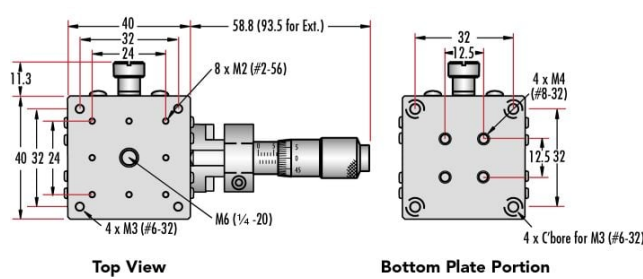


40mm Standard-Top Stages - Side Drive

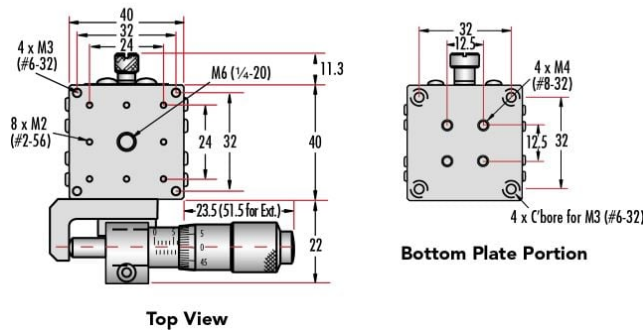

70mm Standard-Top Stages - Center Drive



70mm Standard-Top Stages - Side Drive

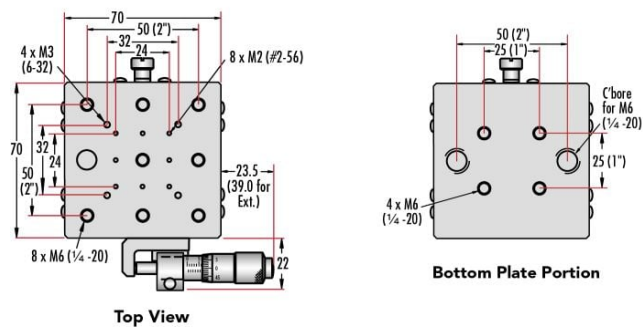

125mm Standard-Top Stages - Center Drive



125mm Standard-Top Stages - Side Drive

