


**TECHSPEC® 3.2mm Diameter x 4.0mm Length, N-LASFN9 Drum Lens**

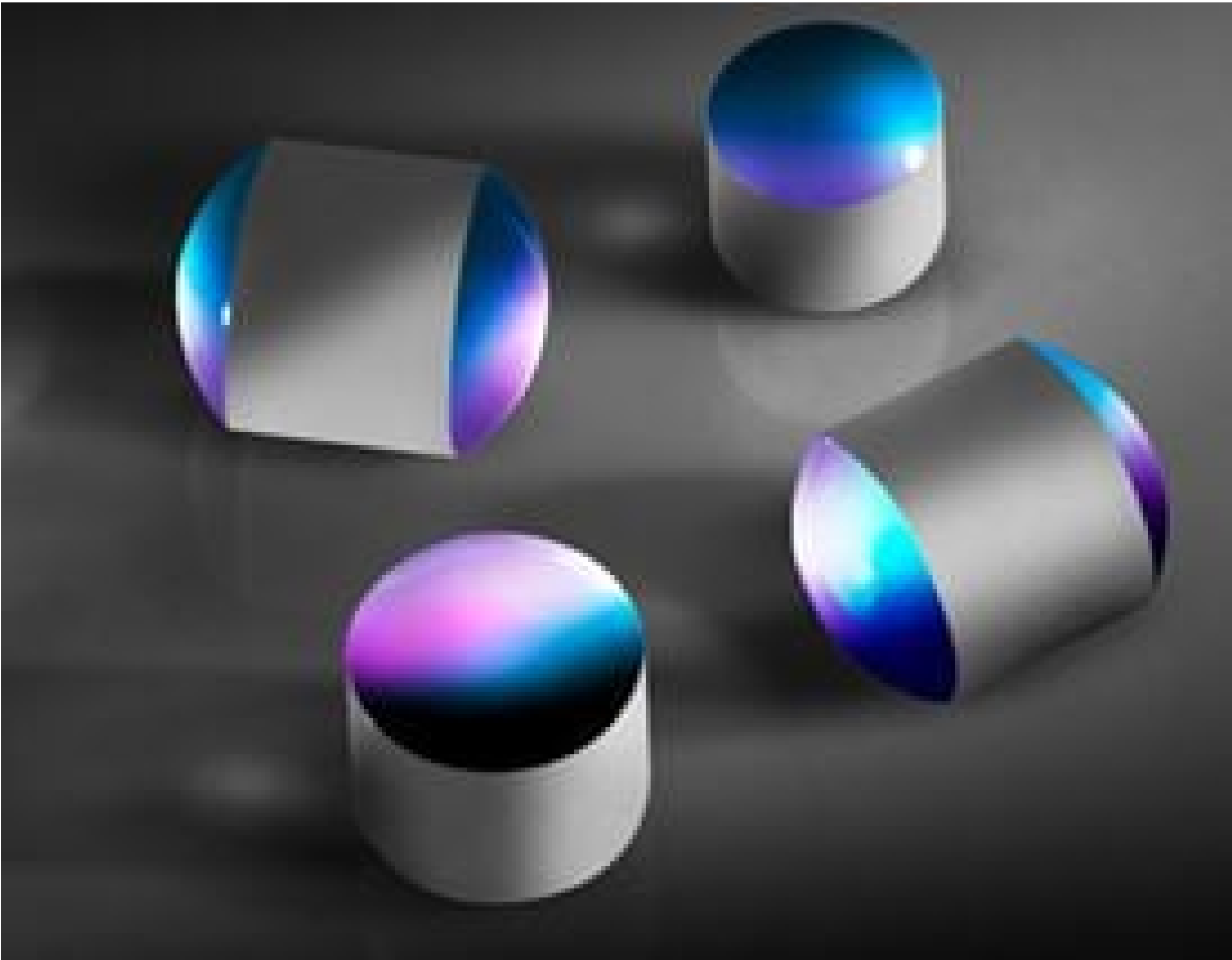

Stock **#45-665** CLEARANCE 3-5 DAYS

- 1 +

**A\$31.92**

ADD TO CART

Qty 1+

**A\$31.92**

Volume Pricing

[Request Quote](#)

Get Product Downloads



**Diameter (mm):**  
3.20

**Substrate:** ☐  
[N-LASFN9](#)

**Coating:**  
Uncoated

**Type:**  
Drum Lens

**Wavelength Range (nm):**  
380 - 2500

|                                                                                       |
|---------------------------------------------------------------------------------------|
| <div>Index of Refraction <math>n_d</math>:</div> <div>1.850</div>                     |
| <div>Length (mm):</div> <div>4.00</div>                                               |
| <div>Length Tolerance (<math>\mu\text{m}</math>):</div> <div><math>\pm 3</math></div> |
| <div>Radius R (mm):</div> <div>2.00</div>                                             |
| <div>Radius Tolerance (<math>\mu\text{m}</math>):</div> <div>+0/-1.5</div>            |
| <div>Surface Quality:</div> <div>40-20</div>                                          |
| <div>Diameter Tolerance (<math>\mu\text{m}</math>):</div> <div>+0/-50</div>           |

## Regulatory Compliance

|                                                                        |
|------------------------------------------------------------------------|
| <div>RoHS:</div> <div>Compliant</div>                                  |
| <div>Certificate of Conformance:</div> <div><a href="#">View</a></div> |