


34.70mm Diameter, Metric Crossed, Contact Reticle

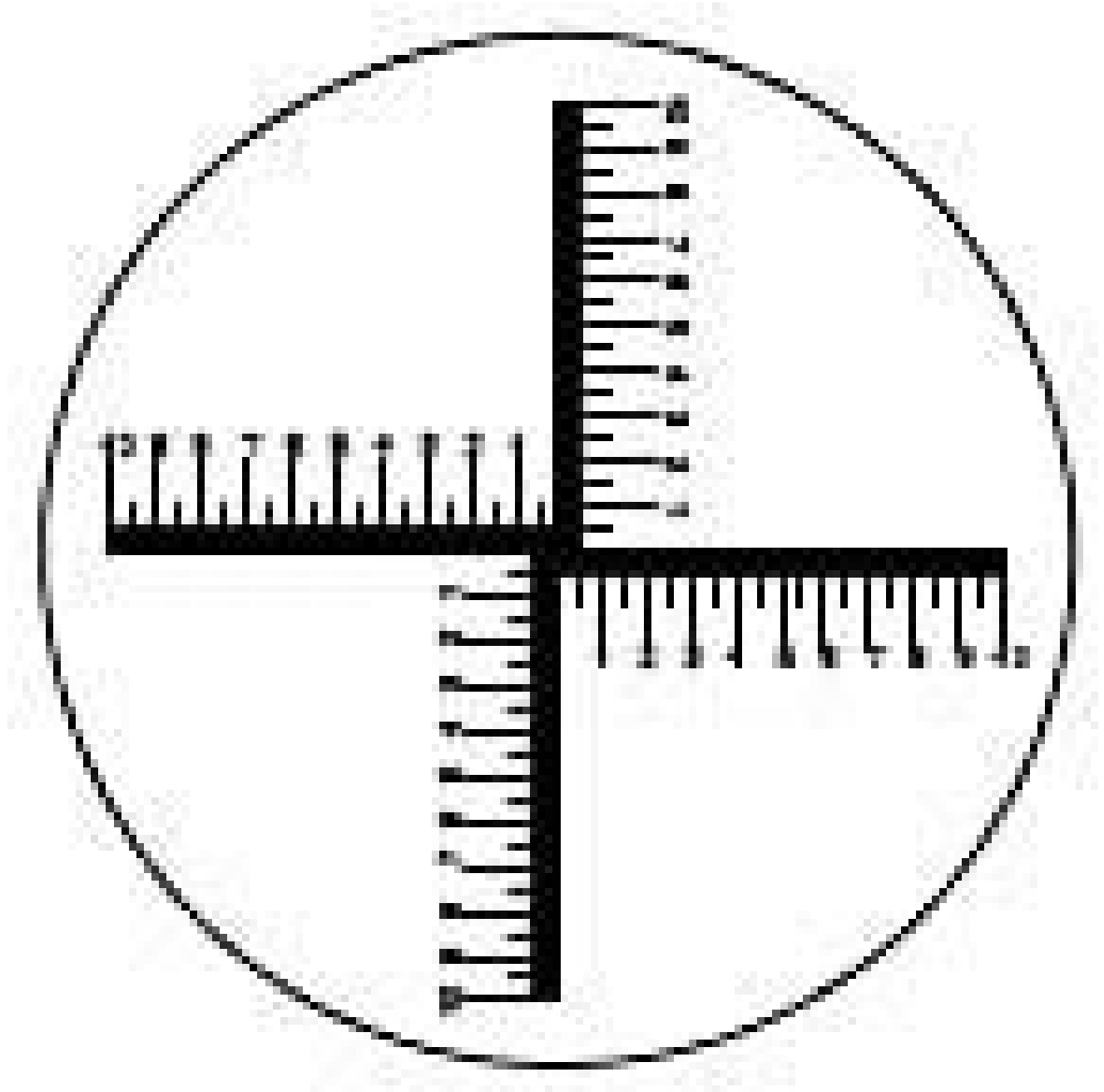

Crossed Scales

Stock **#62-261** 3-5 DAYS



1



A\$107.20

ADD TO CART

Qty 1-4

A\$107.20

Qty 5+

A\$100.64

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):

34.70 ±0.125

Angle Tolerance (arcsec):

±1

Line Thickness (µm):

25.00

Surface Quality:

60-40
Thickness (mm): 1.50
Thickness Tolerance (mm): ±0.10
Type: Metric Crossed Scales
Line to Line Accuracy (µm): ±2
Parallelism (arcsec): <30
Centering (mm): 0.25
Line Thickness Tolerance (µm): ±13
Surface Flatness (P-V): 3 - 4λ

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View
