

34mm Diameter, UV Cut-Off Filter



Stock **#54-049** CLEARANCE **5 In Stock**

-

1

+

A\$23^{.92}

ADD TO CART

Volume Pricing	
Qty 1+	A\$23.92 each
Need More?	Request Quote

Product Downloads

General

UV Cut-Off Filter	Type:
-------------------	-------

Physical & Mechanical Properties

34.00 +0.0/-0.2	Diameter (mm):
2.00 ±0.2	Thickness (mm):

Optical Properties


	Cut-On Wavelength (nm):
--	-------------------------

390.00	
L-39	Glass/Filter Number:
Hoya L-39	Substrate: ☐
AR Coating	Coating:
Clear, Green Tint	Color:
80-50	Surface Quality:
>80 (avg)	Transmission (%):
350 - 2200	Wavelength Range (nm):
4 - 6λ	Surface Flatness (P-V):
Environmental & Durability Factors	
-15 to 70	Operating Temperature (°C):
Regulatory Compliance	
View	Certificate of Conformance:

Product Details

- Ideal for UV Applications
- For use with Longpass and Bandpass Filters
- Various Sizes Available

Technical Information

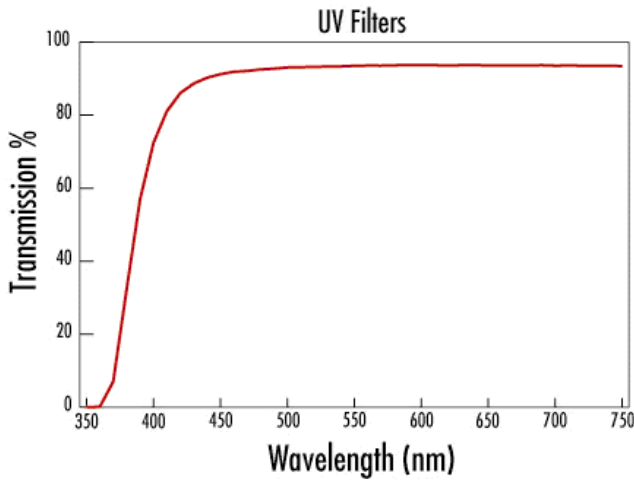

Compatible Mounts