


360° Protractor, 19mm Dia. Eyepiece Reticle

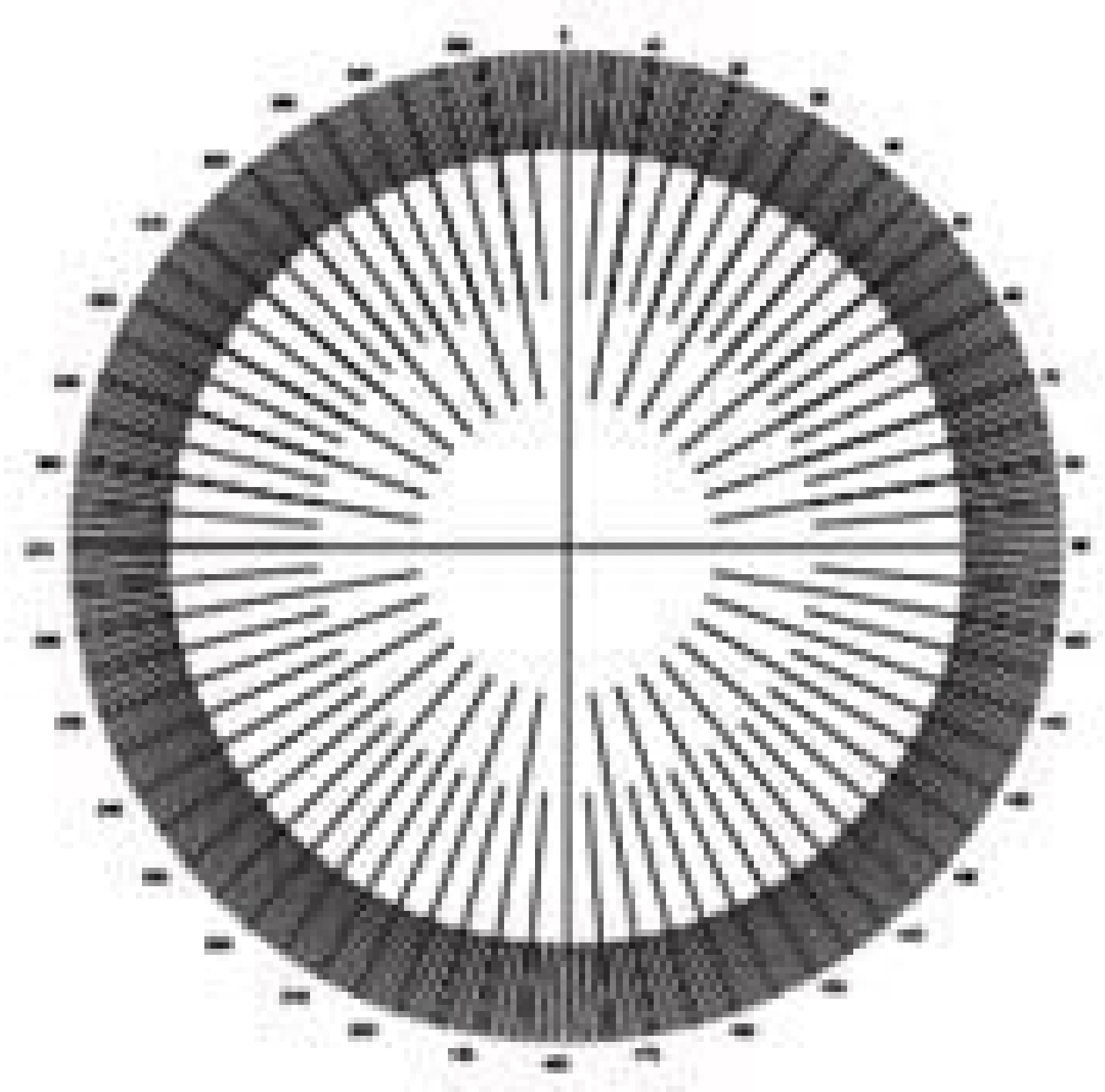

Stock #62-055 3-5 DAYS

- 1 +

A\$260.80

ADD TO CART

Qty 1-4

A\$260.80

Qty 5+

A\$249.44

Volume Pricing

[Request Quote](#)

Get Product Downloads

Diameter (mm):
19.00 +0.0/-0.1

Thickness (mm):
1.50

Thickness Tolerance (mm):
±0.1

Overall Accuracy (µm):
±3

Centering (mm): 0.1
Substrate: B270
Line Width (mm): 0.012
Line Width Tolerance (mm): ±0.003
NST Certification: No

Regulatory Compliance

RoHS 2015: Compliant
Reach 209: Compliant
Certificate of Conformance: View