


TECHSPEC[®] 4.0mm Diameter x 5.0mm Length, N-BK7 Drum Lens

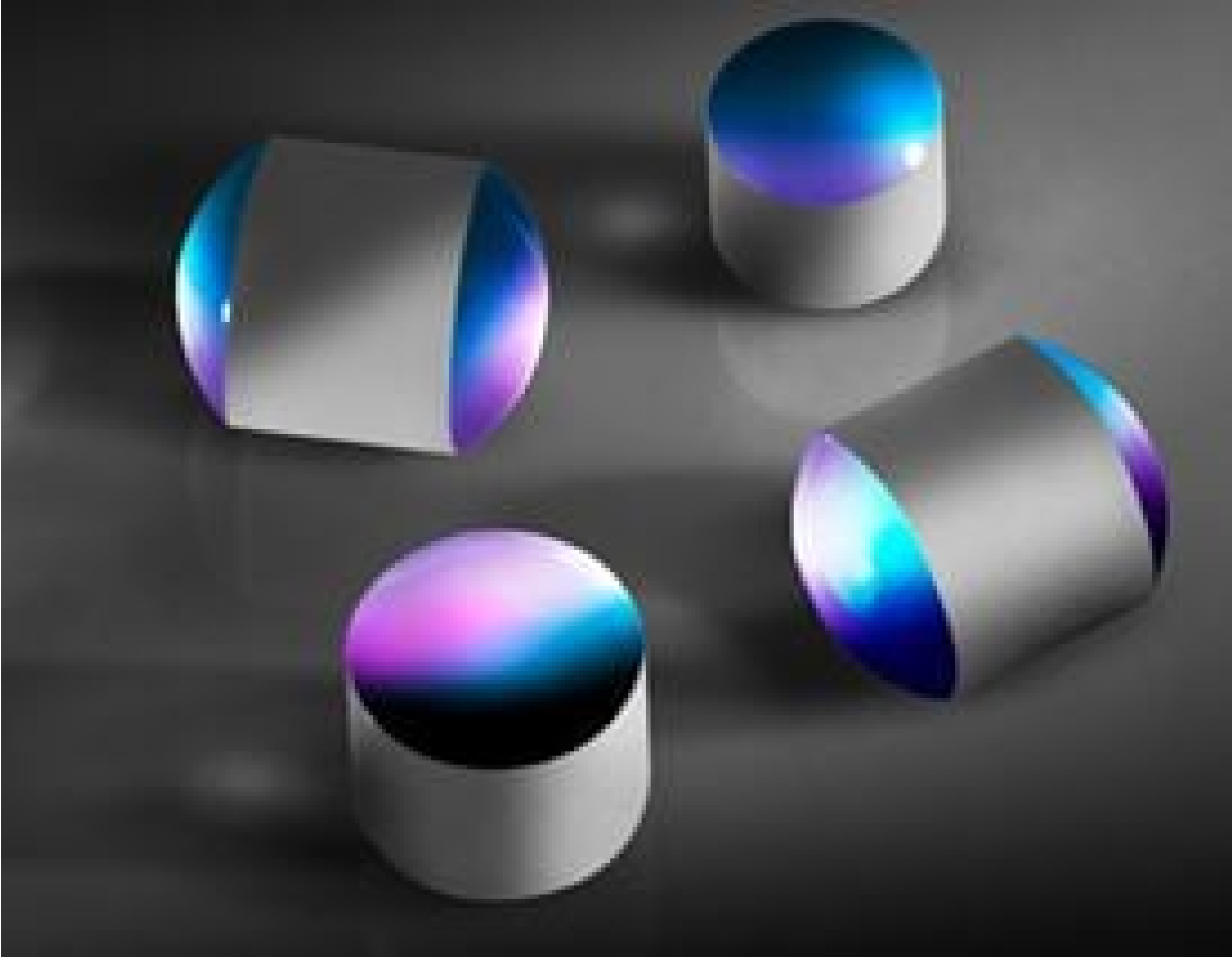

Stock #45-551 CLEARANCE 3-5 DAYS

-

1

+

A\$31.92

ADD TO CART

Qty 1+

A\$31.92

Volume Pricing

[Request Quote](#)

Get Product Downloads



Diameter (mm):
4.00

Substrate: ☐
[N-BK7](#)

Coating:
Uncoated

Type:
Drum Lens

Wavelength Range (nm):
350 - 2200

Index of Refraction n_d: 1.517
Length (mm): 5.00
Length Tolerance (μm): ± 3
Radius R (mm): 2.50
Radius Tolerance (μm): $+0/-1.5$
Surface Quality: 40-20
Diameter Tolerance (μm): $+0/-50$

Regulatory Compliance

RoHS: Compliant
Certificate of Conformance: View