

TECHSPEC[®] 40mm, Side Drive, Standard Top, English Extended Micrometer



40mm, Side Drive, Standard Top

Stock **#66-407** 2 In Stock

-

1

+

A\$736⁰⁰

ADD TO CART

Volume Pricing	
Qty 1-2	A\$736.00 each
Qty 3+	A\$642.56 each
Need More?	Request Quote

Product Downloads

General

Type:

English

Physical & Mechanical Properties

Type of Movement:

Linear (X)


Guide System:

Crossed Roller Bearing


Drive Orientation:

[illegible]


30mm Standard-Top Stages - Center Drive

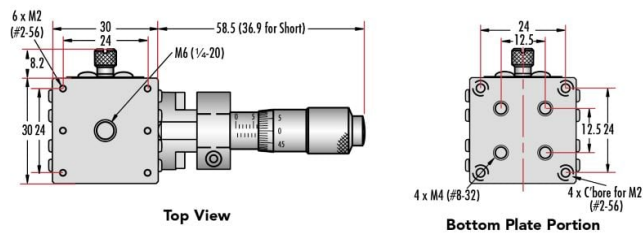


30mm Standard-Top Stages - Side Drive

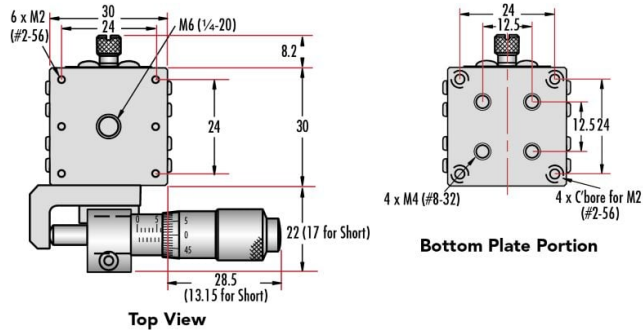


40mm Standard-Top Stages - Center Drive

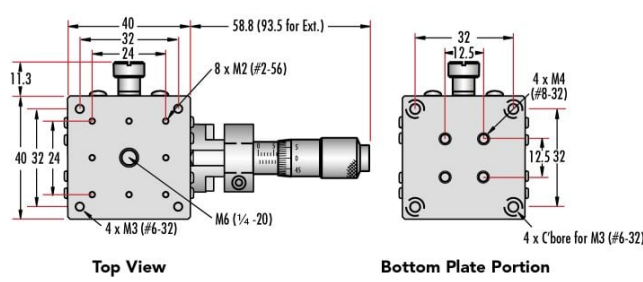


40mm Standard-Top Stages - Side Drive

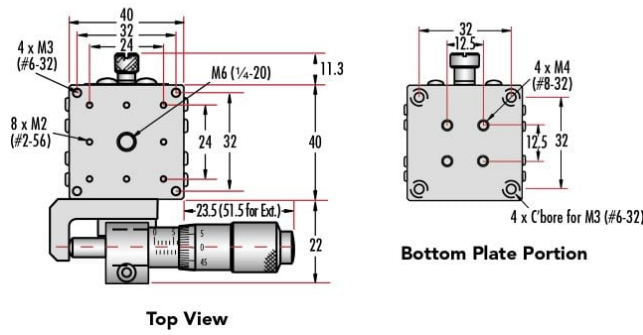


70mm Standard-Top Stages - Center Drive

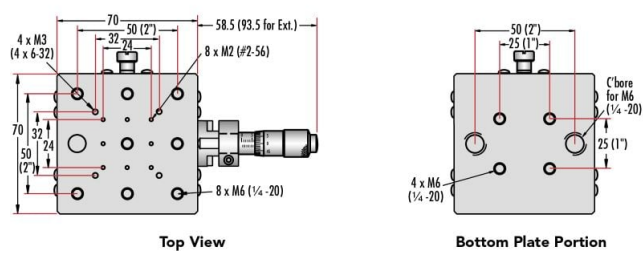

70mm Standard-Top Stages - Side Drive

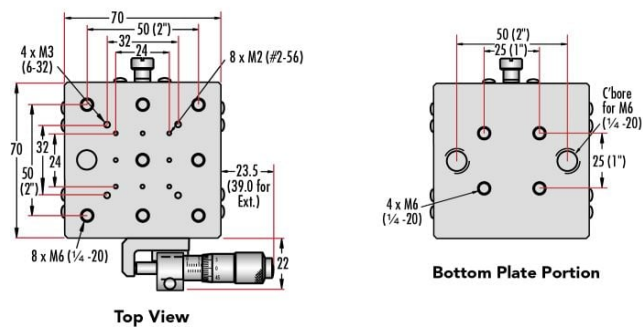

125mm Standard-Top Stages - Center Drive

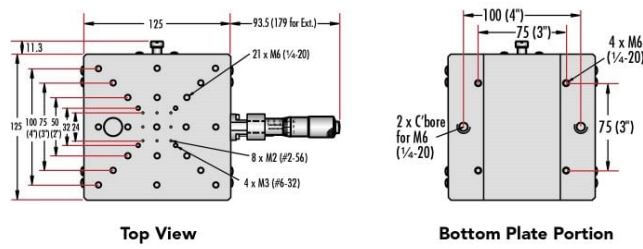

125mm Standard-Top Stages - Side Drive

