


40mm Travel, Thick Base X-Y Axis Movement

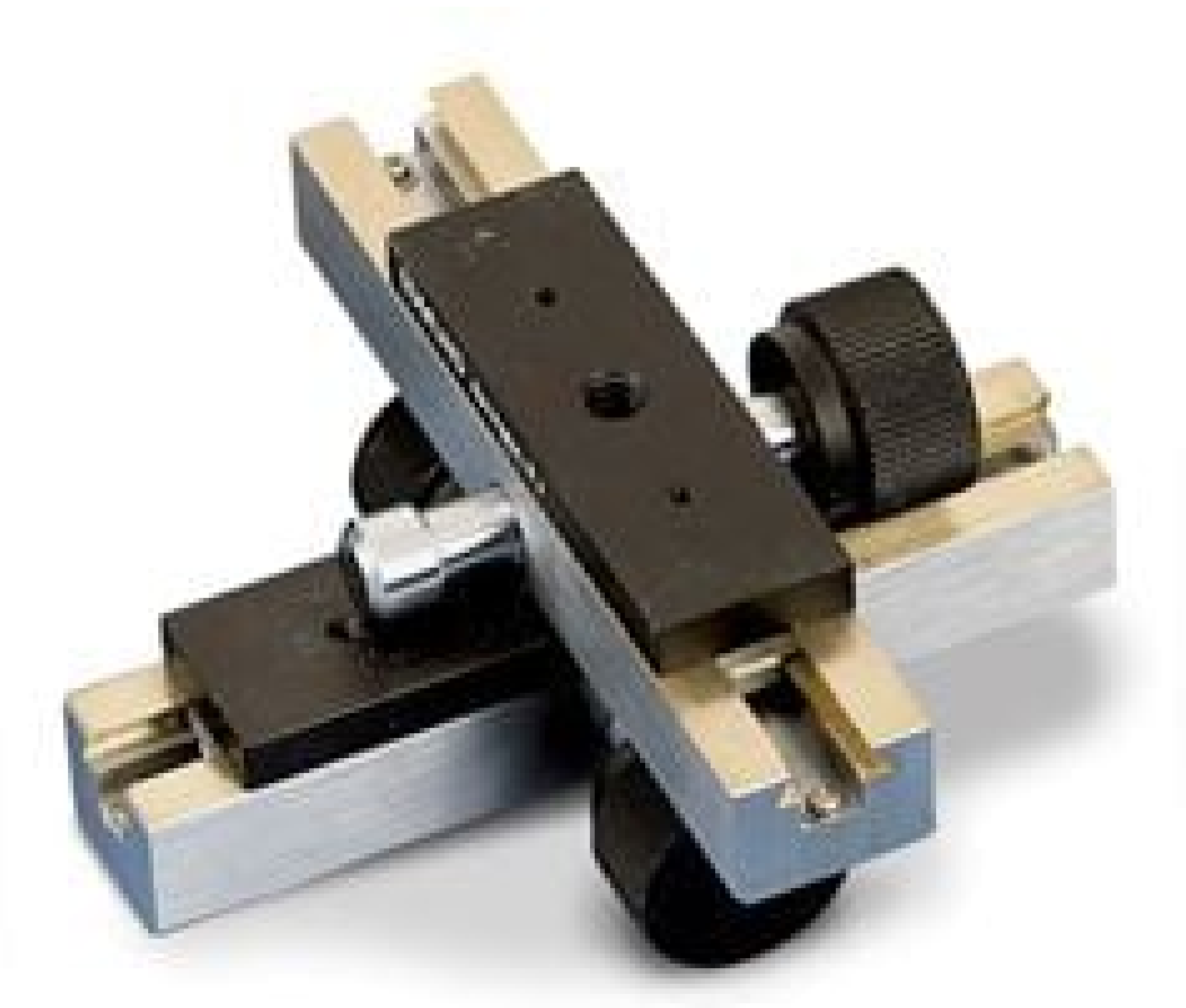

#03-683

Stock **#03-683** 3-5 DAYS



1



A\$668.80

ADD TO CART

Qty 1-9

A\$668.80

Qty 10+

A\$591.04

Volume Pricing

[Request Quote](#)

Get Product Downloads

Type of Movement:

Linear (X-Y)

Guide System:

Dovetail

Type of Drive:

Rack and Pinion

Type:

English
Stage Size (mm): 20 x 100
Travel (mm): 40 (±20)
Load Capacity (kg): 3.5 Horizontal, 2.1 Vertical
Mounting Threads: Stage: (1) ¼-20 Base: (2) ¼-20
Note: Not Lockable
Straight Line Accuracy (µm): 50
Travel Per Knob Rotation (mm): 15
Weight (g): 500
Table Size (mm): 20 x 60

Regulatory Compliance

RoHS 2015: Exempt
Reach 224: Contains SVHC(s)
Certificate of Conformance: View