


41 x 63.5mm AR Coated Float Glass Window

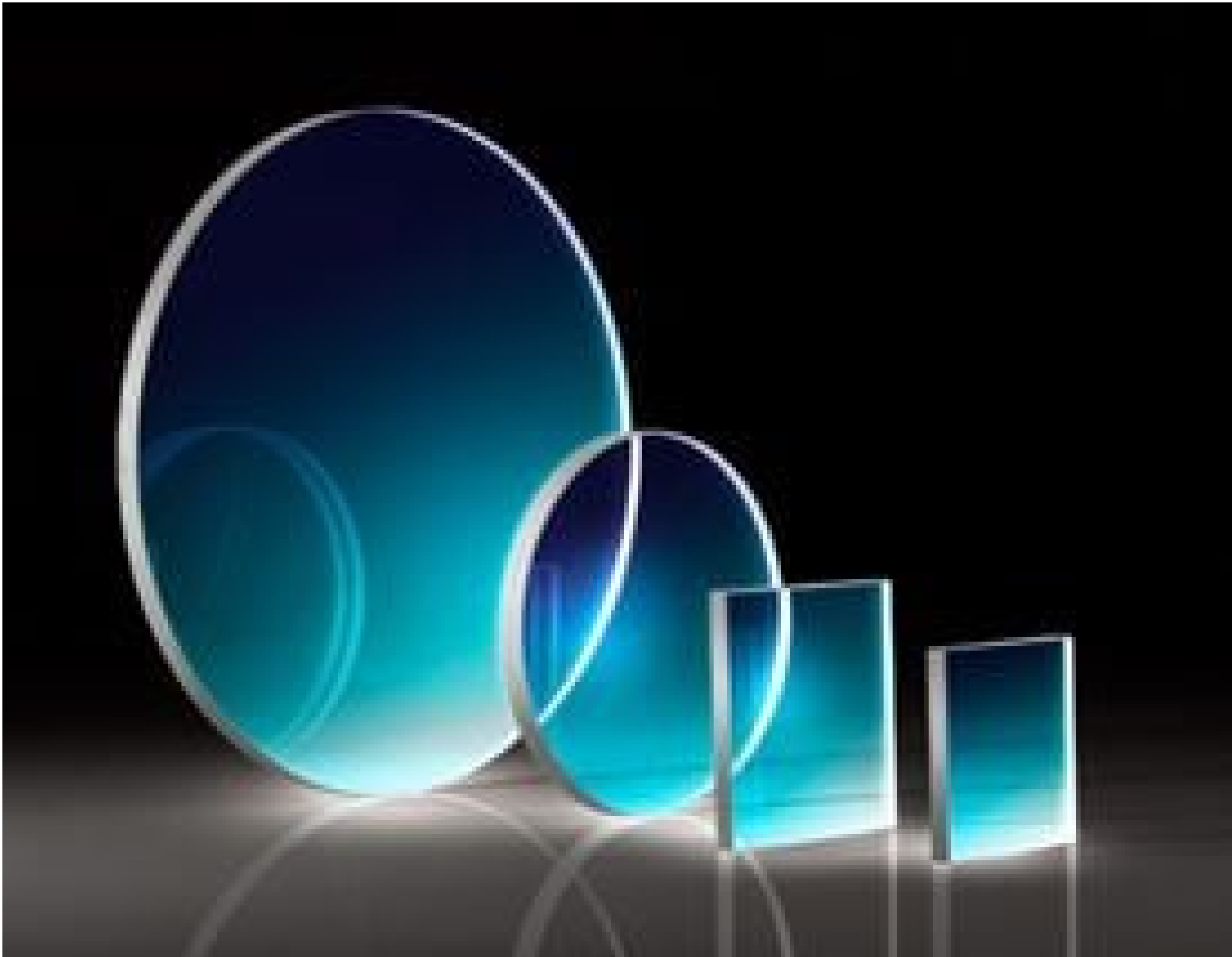

Stock #32-740 3-5 DAYS

⊖ 1 ⊕

A\$37.60

ADD TO CART

Qty 1-5
A\$37.60
Qty 6+
A\$34.00
Volume Pricing
Request Quote

Get Product Downloads

Dimensions (mm):
41.00 x 63.50

Thickness (mm):
3.00 (nominal)

Coating:
BBAR (400-700nm)

Edges:
Fine Ground

Substrate: Float Glass
Surface Flatness (P-V): 4 - 6λ
Surface Quality: 80-50
Type: Protective Window
Wavelength Range (nm): 400 - 700
Length (mm): 63.50
Width (mm): 41.00

Regulatory Compliance

RoHS 2015: Compliant
Certificate of Conformance: View
Reach 233: Compliant
